


Hexagonal headed screw, **DIN 933**

VTH

Chromed steel (Class 8.8)

- Screw conforming to DIN 933
- Full threaded
- Material:
Chromed steel (Class 8.8)
- Mechanical characteristics conform to ISO 898-1
- Supplied by the packet

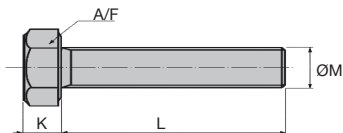

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch		K	A/F across flats	Qty per packet	Price each
		P	L				
VTH4-10/B	M4	0,70	10	2,92	7,0	500	9,78 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	10,71 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	12,70 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	14,33 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	16,90 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	19,18 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	11,97 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	13,42 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	9,90 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	10,91 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	12,73 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	14,60 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	16,90 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	19,24 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	8,62 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	9,55 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	11,06 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	12,29 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch			A/F	Qty per packet	Price each
		P	L	K			
VTH6-10/B	M6	1,00	10	4,15	10,0	500	14,54 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	15,57 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	17,58 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	20,18 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	21,66 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	10,94 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	13,36 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	15,45 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	13,87 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	16,79 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	9,69 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	12,29 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	14,12 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	16,32 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	18,18 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	23,05 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	28,49 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	16,93 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	19,63 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	11,52 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	13,06 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	14,48 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	17,73 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	17,50 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	23,34 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	27,39 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	15,48 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	16,22 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	19,24 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	21,30 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	25,50 €

Dimensions in mm

Our other products



SH3

Parallel axis helical gear, Machined plastic (delrin)



SLB

Indexing plunger, steel class 5.8



ACLDBD

Closing mechanism for aluminium profile, Dual ball catch



BOX-WM

Box set of washer - DIN125, Box set of steel washers



MC

Self-compensating shock absorber, Self-compensating - without adjust...



APB_F

Adjusting rod for clamp - Male, Threaded



UCP

Cast iron pillow block bearing, Cast iron



BDMdl

Magnetic bush for pin, Fast and light magnetic locking



BOX-TOR-D

Box set of Nitrile O-rings in nitrile, 18.00 x 2.00mm to 50.00 x 5.00



BSM

Spring plunger with internal hexagonal socket, stainless steel 303 b...



PV2R

Adjustable suction-cup support, Increased grip



KKP-AR

Linear bearing with inclined ball tracks, Heavy loads / -20° +20°

Complementary products



SHN

Hexagonal nut DIN934, Steel (Class 6[8])



BHEX

Hexagonal cap, Black technopolymer



NIN

Self-locking nut, Steel



SHW

Plain washer, Steel