


Hexagonal headed screw, **DIN 933**

VTH

Chromed steel (Class 8.8)

- Screw conforming to DIN 933
- Full threaded
- Material:
Chromed steel (Class 8.8)
- Mechanical characteristics conform to ISO 898-1
- Supplied by the packet

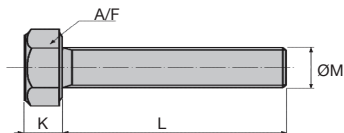

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch		K	A/F across flats	Qty per packet	Price each
		P	L				
VTH4-10/B	M4	0,70	10	2,92	7,0	500	9,78 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	10,71 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	12,70 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	14,33 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	16,90 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	19,18 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	11,97 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	13,42 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	9,90 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	10,91 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	12,73 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	14,60 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	16,90 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	19,24 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	8,62 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	9,55 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	11,06 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	12,29 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch			A/F	Qty per packet	Price each
		P	L	K			
VTH6-10/B	M6	1,00	10	4,15	10,0	500	14,54 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	15,57 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	17,58 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	20,18 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	21,66 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	10,94 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	13,36 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	15,45 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	13,87 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	16,79 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	9,69 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	12,29 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	14,12 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	16,32 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	18,18 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	23,05 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	28,49 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	16,93 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	19,63 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	11,52 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	13,06 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	14,48 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	17,73 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	17,50 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	23,34 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	27,39 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	15,48 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	16,22 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	19,24 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	21,30 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	25,50 €

Dimensions in mm

Our other products



PHTss

Pull handle, Up to 250 °C



CHMR63

Worm and wheel gear reducer, up to 196 Nm



PRES2HR

Manual workbench press, Force up to 200kg



BLHM40

Right angled gearbox, double output shafts, up to 10.3 Nm



PM3

Worm and wheel set, Hardened steel



BLHT40

Right angled gearbox, from 4 to 10.30 Nm



IBJss

Ball and socket joint, Stainless steel



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm



MEB

Moulded plastic bevel gear (nylon), 1:1



 
CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



PCH

Knob for gripping, Mushroom



GLT2-27

Telescopic drawer runners for groove mounting, Partial extension

Complementary products



SHN

Hexagonal nut DIN934, Steel (Class 6[8])



BHEX

Hexagonal cap, Black technopolymer



NIN

Self-locking nut, Steel



SHW

Plain washer, Steel