


Hexagonal headed screw, **DIN 933**

VTH

Chromed steel (Class 8.8)

- Screw conforming to DIN 933
- Full threaded
- Material:
Chromed steel (Class 8.8)
- Mechanical characteristics conform to ISO 898-1
- Supplied by the packet

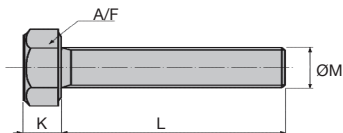

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch		K	A/F across flats	Qty per packet	Price each
		P	L				
VTH4-10/B	M4	0,70	10	2,92	7,0	500	9,78 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	10,71 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	12,70 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	14,33 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	16,90 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	19,18 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	11,97 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	13,42 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	9,90 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	10,91 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	12,73 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	14,60 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	16,90 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	19,24 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	8,62 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	9,55 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	11,06 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	12,29 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-20%	On request

Part number	ØM	Pitch			A/F	Qty per packet	Price each
		P	L	K			
VTH6-10/B	M6	1,00	10	4,15	10,0	500	14,54 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	15,57 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	17,58 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	20,18 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	21,66 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	10,94 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	13,36 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	15,45 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	13,87 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	16,79 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	9,69 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	12,29 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	14,12 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	16,32 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	18,18 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	23,05 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	28,49 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	16,93 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	19,63 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	11,52 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	13,06 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	14,48 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	17,73 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	17,50 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	23,34 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	27,39 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	15,48 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	16,22 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	19,24 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	21,30 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	25,50 €

Dimensions in mm

Our other products



Ball pin socket, Socket



HTD Heavy duty timing pulley, HTD14 Steel



Square tube connector, Fixed angle



Ring operated locking bolt, with ring



Moulded plastic bevel gear (nylon), 2:1



 
Adjustment slide-system miniature, 20



Hexagonal headed bolts, Steel class 8.8



Flanged polymer nut, Polymer (Iglidur®) - 1 thread




Single housed bearing, Bearing fitted with adhesive



Mechanical digital position indicator, 5 numbers



 Stainless steel bevel gear, 1:1



Closing system for aluminium profile, 90° bracket for spherical end...

Complementary products



Hexagonal nut DIN934, Steel (Class 6[8])



Hexagonal cap, Black technopolymer



Self-locking nut, Steel



Plain washer, Steel