


- **Ball head screws**
- Specially designed component for fixing cladding panels, Plexiglass screens etc
- Material:
  - Stainless steel 1.4404 (316L)
  - Polished finish  $RA < 0.8$

### Advantages

- The oversized flange and the thread undercut ensure a stress-free, uniform force distribution on the supported element.
- Optimised form for use in hygienic environments.
- Dirt and residue from products or cleaners are practically non-adherent, guaranteeing easy cleaning

### Accessories

- For tightening and loosening the screws without damaging them, use the **CM flat spanner** with protective cap (tome 1 p.628) in combination with the **CM-CF** accessory (tome 1 p.629)

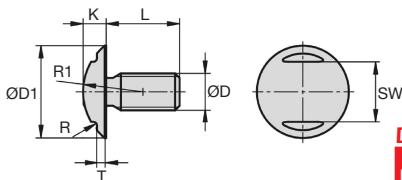

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM3-4/HDSS	M3	8	1,8	0,6	5	0,3	5,2	4	6,05 €
VTSM3-5/HDSS	M3	8	1,8	0,6	5	0,3	5,2	5	6,05 €
VTSM3-6/HDSS	M3	8	1,8	0,6	5	0,3	5,2	6	6,15 €
VTSM3-8/HDSS	M3	8	1,8	0,6	5	0,3	5,2	8	6,24 €
VTSM3-10/HDSS	M3	8	1,8	0,6	5	0,3	5,2	10	6,34 €
VTSM4-5/HDSS	M4	11	2,9	1	6	0,3	6,7	5	6,31 €
VTSM4-6/HDSS	M4	11	2,9	1	6	0,3	6,7	6	6,31 €
VTSM4-8/HDSS	M4	11	2,9	1	6	0,3	6,7	8	6,42 €
VTSM4-10/HDSS	M4	11	2,9	1	6	0,3	6,7	10	6,50 €
VTSM4-12/HDSS	M4	11	2,9	1	6	0,3	6,7	12	6,52 €

All dimensions in mm

## DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

 
Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM5-6/HDSS	M5	14	4,0	1	8	0,4	8,6	6	6,70 €
VTSM5-8/HDSS	M5	14	4,0	1	8	0,4	8,6	8	6,88 €
VTSM5-10/HDSS	M5	14	4,0	1	8	0,4	8,6	10	6,98 €
VTSM5-12/HDSS	M5	14	4,0	1	8	0,4	8,6	12	7,14 €
VTSM5-16/HDSS	M5	14	4,0	1	8	0,4	8,6	16	7,32 €
VTSM6-8/HDSS	M6	17	5,0	1,5	10	0,6	10	8	7,21 €
VTSM6-10/HDSS	M6	17	5,0	1,5	10	0,6	10	10	7,40 €
VTSM6-12/HDSS	M6	17	5,0	1,5	10	0,6	10	12	7,58 €
VTSM6-16/HDSS	M6	17	5,0	1,5	10	0,6	10	16	7,89 €
VTSM6-20/HDSS	M6	17	5,0	1,5	10	0,6	10	20	8,07 €
VTSM8-10/HDSS	M8	20	5,0	1,5	13	0,8	13	10	7,48 €
VTSM8-12/HDSS	M8	20	5,0	1,5	13	0,8	13	12	7,69 €
VTSM8-16/HDSS	M8	20	5,0	1,5	13	0,8	13	16	8,04 €
VTSM8-20/HDSS	M8	20	5,0	1,5	13	0,8	13	20	8,32 €
VTSM8-25/HDSS	M8	20	5,0	1,5	13	0,8	13	25	8,43 €
VTSM10-12/HDSS	M10	22	6,4	1,5	15	0,9	13,5	12	9,82 €
VTSM10-16/HDSS	M10	22	6,4	1,5	15	0,9	13,5	16	10,09 €
VTSM10-20/HDSS	M10	22	6,4	1,5	15	0,9	13,5	20	10,39 €
VTSM10-25/HDSS	M10	22	6,4	1,5	15	0,9	13,5	25	10,67 €
VTSM10-30/HDSS	M10	22	6,4	1,5	15	0,9	13,5	30	10,89 €
VTSM10-37/HDSS	M10	22	6,4	1,5	15	0,9	13,5	37	11,15 €
VTSM12-16/HDSS	M12	27	7,5	1,5	19	1,0	16,3	16	11,72 €
VTSM12-20/HDSS	M12	27	7,5	1,5	19	1,0	16,3	20	12,08 €
VTSM12-25/HDSS	M12	27	7,5	1,5	19	1,0	16,3	25	12,70 €
VTSM12-30/HDSS	M12	27	7,5	1,5	19	1,0	16,3	30	13,25 €
VTSM12-35/HDSS	M12	27	7,5	1,5	19	1,0	16,3	35	13,76 €
VTSM16-20/HDSS	M16	36	9,0	1,5	24	1,1	23	20	15,44 €
VTSM16-25/HDSS	M16	36	9,0	1,5	24	1,1	23	25	16,28 €
VTSM16-30/HDSS	M16	36	9,0	1,5	24	1,1	23	30	17,12 €
VTSM16-35/HDSS	M16	36	9,0	1,5	24	1,1	23	35	18,45 €
VTSM16-40/HDSS	M16	36	9,0	1,5	24	1,1	23	40	18,94 €

All dimensions in mm

## Our other products



PRF\_ER  
Joining bar for aluminium profile, joint bar



BH02  
Single housed bearing assembly, Bearing secured with circlips



CHT  
Asynchronous AC Motor 1.1 to 1.85kW, 1.1 to 1.85kW



SHS  
Shoulder screw stainless steel 303, Stainless steel 303



PGNT  
Thermoplastic T handle, With threaded spindle



RBGpl  
Swivel castor with plate, Steel - grey rubber



RHTplss  
High Temperature Castor, up to 200kg



RDS  
Safety washer Hygienic Usit®, Stainless steel



PCLA\_M  
Technopolymer clamping lever - female, Plastic



VTLF  
3 lobed handle, Polyamide - Brass



PRF-GPB  
Guide for aluminium profile, Rail for 8mm wide slots



CHMR50  
Worm and wheel gear reducer, up to 107 Nm

## Complementary products



CM  
Tools Hygienic Usit® and Hygienic Design®, Combination spanner



CM\_CO  
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...