


- **Ball head screws**
- Specially designed component for fixing cladding panels, Plexiglass screens etc
- Material:
 - Stainless steel 1.4404 (316L)
 - Polished finish Ra<0.8

Advantages

- The oversized flange and the thread undercut ensure a stress-free, uniform force distribution on the supported element.
- Optimised form for use in hygienic environments.
- Dirt and residue from products or cleaners are practically non-adherent, guaranteeing easy cleaning

Accessories

- For tightening and loosening the screws without damaging them, use the **CM** flat spanner with protective cap (**tome 1 p.628**) in combination with the **CM-CF** accessory (**tome 1 p.629**)

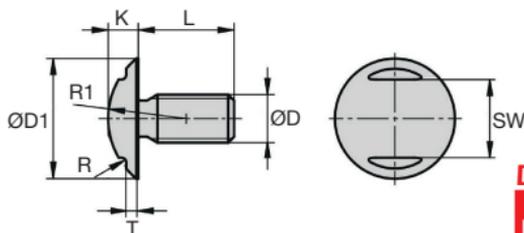

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM3-4/HDSS	M3	8	1,8	0,6	5	0,3	5,2	4	6,82 €
VTSM3-5/HDSS	M3	8	1,8	0,6	5	0,3	5,2	5	6,82 €
VTSM3-6/HDSS	M3	8	1,8	0,6	5	0,3	5,2	6	6,93 €
VTSM3-8/HDSS	M3	8	1,8	0,6	5	0,3	5,2	8	7,03 €
VTSM3-10/HDSS	M3	8	1,8	0,6	5	0,3	5,2	10	7,17 €
VTSM4-5/HDSS	M4	11	2,9	1	6	0,3	6,7	5	7,11 €
VTSM4-6/HDSS	M4	11	2,9	1	6	0,3	6,7	6	7,11 €
VTSM4-8/HDSS	M4	11	2,9	1	6	0,3	6,7	8	7,25 €
VTSM4-10/HDSS	M4	11	2,9	1	6	0,3	6,7	10	7,32 €
VTSM4-12/HDSS	M4	11	2,9	1	6	0,3	6,7	12	7,34 €

All dimensions in mm

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM5-6/HDSS	M5	14	4,0	1	8	0,4	8,6	6	7,56 €
VTSM5-8/HDSS	M5	14	4,0	1	8	0,4	8,6	8	7,75 €
VTSM5-10/HDSS	M5	14	4,0	1	8	0,4	8,6	10	7,86 €
VTSM5-12/HDSS	M5	14	4,0	1	8	0,4	8,6	12	8,06 €
VTSM5-16/HDSS	M5	14	4,0	1	8	0,4	8,6	16	8,26 €
VTSM6-8/HDSS	M6	17	5,0	1,5	10	0,6	10	8	8,14 €
VTSM6-10/HDSS	M6	17	5,0	1,5	10	0,6	10	10	8,35 €
VTSM6-12/HDSS	M6	17	5,0	1,5	10	0,6	10	12	8,54 €
VTSM6-16/HDSS	M6	17	5,0	1,5	10	0,6	10	16	8,88 €
VTSM6-20/HDSS	M6	17	5,0	1,5	10	0,6	10	20	9,10 €
VTSM8-10/HDSS	M8	20	5,0	1,5	13	0,8	13	10	8,44 €
VTSM8-12/HDSS	M8	20	5,0	1,5	13	0,8	13	12	8,69 €
VTSM8-16/HDSS	M8	20	5,0	1,5	13	0,8	13	16	9,07 €
VTSM8-20/HDSS	M8	20	5,0	1,5	13	0,8	13	20	9,38 €
VTSM8-25/HDSS	M8	20	5,0	1,5	13	0,8	13	25	9,50 €
VTSM10-12/HDSS	M10	22	6,4	1,5	15	0,9	13,5	12	11,06 €
VTSM10-16/HDSS	M10	22	6,4	1,5	15	0,9	13,5	16	11,38 €
VTSM10-20/HDSS	M10	22	6,4	1,5	15	0,9	13,5	20	11,73 €
VTSM10-25/HDSS	M10	22	6,4	1,5	15	0,9	13,5	25	12,02 €
VTSM10-30/HDSS	M10	22	6,4	1,5	15	0,9	13,5	30	12,31 €
VTSM10-37/HDSS	M10	22	6,4	1,5	15	0,9	13,5	37	13,96 €
VTSM12-16/HDSS	M12	27	7,5	1,5	19	1,0	16,3	16	13,24 €
VTSM12-20/HDSS	M12	27	7,5	1,5	19	1,0	16,3	20	13,63 €
VTSM12-25/HDSS	M12	27	7,5	1,5	19	1,0	16,3	25	14,33 €
VTSM12-30/HDSS	M12	27	7,5	1,5	19	1,0	16,3	30	14,96 €
VTSM12-35/HDSS	M12	27	7,5	1,5	19	1,0	16,3	35	15,54 €
VTSM16-20/HDSS	M16	36	9,0	1,5	24	1,1	23	20	17,42 €
VTSM16-25/HDSS	M16	36	9,0	1,5	24	1,1	23	25	18,36 €
VTSM16-30/HDSS	M16	36	9,0	1,5	24	1,1	23	30	19,30 €
VTSM16-35/HDSS	M16	36	9,0	1,5	24	1,1	23	35	20,80 €
VTSM16-40/HDSS	M16	36	9,0	1,5	24	1,1	23	40	21,36 €

All dimensions in mm