


- **Ball head screws**
- Specially designed component for fixing cladding panels, Plexiglass screens etc
- Material:
 - Stainless steel 1.4404 (316L)
 - Polished finish $RA < 0.8$

Advantages

- The oversized flange and the thread undercut ensure a stress-free, uniform force distribution on the supported element.
- Optimised form for use in hygienic environments.
- Dirt and residue from products or cleaners are practically non-adherent, guaranteeing easy cleaning

Accessories

- For tightening and loosening the screws without damaging them, use the **CM flat spanner** with protective cap (tome 1 p.628) in combination with the **CM-CF** accessory (tome 1 p.629)

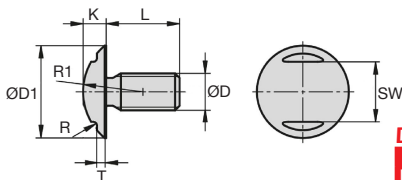

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM3-4/HDSS	M3	8	1,8	0,6	5	0,3	5,2	4	6,05 €
VTSM3-5/HDSS	M3	8	1,8	0,6	5	0,3	5,2	5	6,05 €
VTSM3-6/HDSS	M3	8	1,8	0,6	5	0,3	5,2	6	6,15 €
VTSM3-8/HDSS	M3	8	1,8	0,6	5	0,3	5,2	8	6,24 €
VTSM3-10/HDSS	M3	8	1,8	0,6	5	0,3	5,2	10	6,34 €
VTSM4-5/HDSS	M4	11	2,9	1	6	0,3	6,7	5	6,31 €
VTSM4-6/HDSS	M4	11	2,9	1	6	0,3	6,7	6	6,31 €
VTSM4-8/HDSS	M4	11	2,9	1	6	0,3	6,7	8	6,42 €
VTSM4-10/HDSS	M4	11	2,9	1	6	0,3	6,7	10	6,50 €
VTSM4-12/HDSS	M4	11	2,9	1	6	0,3	6,7	12	6,52 €

All dimensions in mm

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part number	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM5-6/HDSS	M5	14	4,0	1	8	0,4	8,6	6	6,70 €
VTSM5-8/HDSS	M5	14	4,0	1	8	0,4	8,6	8	6,88 €
VTSM5-10/HDSS	M5	14	4,0	1	8	0,4	8,6	10	6,98 €
VTSM5-12/HDSS	M5	14	4,0	1	8	0,4	8,6	12	7,14 €
VTSM5-16/HDSS	M5	14	4,0	1	8	0,4	8,6	16	7,32 €
VTSM6-8/HDSS	M6	17	5,0	1,5	10	0,6	10	8	7,21 €
VTSM6-10/HDSS	M6	17	5,0	1,5	10	0,6	10	10	7,40 €
VTSM6-12/HDSS	M6	17	5,0	1,5	10	0,6	10	12	7,58 €
VTSM6-16/HDSS	M6	17	5,0	1,5	10	0,6	10	16	7,89 €
VTSM6-20/HDSS	M6	17	5,0	1,5	10	0,6	10	20	8,07 €
VTSM8-10/HDSS	M8	20	5,0	1,5	13	0,8	13	10	7,48 €
VTSM8-12/HDSS	M8	20	5,0	1,5	13	0,8	13	12	7,69 €
VTSM8-16/HDSS	M8	20	5,0	1,5	13	0,8	13	16	8,04 €
VTSM8-20/HDSS	M8	20	5,0	1,5	13	0,8	13	20	8,32 €
VTSM8-25/HDSS	M8	20	5,0	1,5	13	0,8	13	25	8,43 €
VTSM10-12/HDSS	M10	22	6,4	1,5	15	0,9	13,5	12	9,82 €
VTSM10-16/HDSS	M10	22	6,4	1,5	15	0,9	13,5	16	10,09 €
VTSM10-20/HDSS	M10	22	6,4	1,5	15	0,9	13,5	20	10,39 €
VTSM10-25/HDSS	M10	22	6,4	1,5	15	0,9	13,5	25	10,67 €
VTSM10-30/HDSS	M10	22	6,4	1,5	15	0,9	13,5	30	10,89 €
VTSM10-37/HDSS	M10	22	6,4	1,5	15	0,9	13,5	37	11,15 €
VTSM12-16/HDSS	M12	27	7,5	1,5	19	1,0	16,3	16	11,72 €
VTSM12-20/HDSS	M12	27	7,5	1,5	19	1,0	16,3	20	12,08 €
VTSM12-25/HDSS	M12	27	7,5	1,5	19	1,0	16,3	25	12,70 €
VTSM12-30/HDSS	M12	27	7,5	1,5	19	1,0	16,3	30	13,25 €
VTSM12-35/HDSS	M12	27	7,5	1,5	19	1,0	16,3	35	13,76 €
VTSM16-20/HDSS	M16	36	9,0	1,5	24	1,1	23	20	15,44 €
VTSM16-25/HDSS	M16	36	9,0	1,5	24	1,1	23	25	16,28 €
VTSM16-30/HDSS	M16	36	9,0	1,5	24	1,1	23	30	17,12 €
VTSM16-35/HDSS	M16	36	9,0	1,5	24	1,1	23	35	18,45 €
VTSM16-40/HDSS	M16	36	9,0	1,5	24	1,1	23	40	18,94 €

All dimensions in mm

Our other products



High Temperature
Castor, up to 200kg



Strike for toggle latch,
15mm



Idler for slat top
chain, Ranges 880
and 881



Right angled gearbox,
double output shafts,
up to 30 Nm



Hexagonal spacer,
Steel



Threaded spherical
knob, Stainless steel
304



Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



Knurled torque knobs
- female, Knurled
threaded torque



Stainless steel splined
shaft, Stainless steel



Nut for aluminium
profile, Stainless steel
square nut with tab



HTD Heavy duty
timing pulley, HTD14
Steel



Crossed helical gear
crossed axis at 90°,
Steel 20NCD2

Complementary products



Tools Hygienic Usit®
and Hygienic
Design®,
Combination spanner



Tools Hygienic Usit®
and Hygienic
Design®, Protective
inserts for ...