

- Ball head screws

- Specially designed component for fixing cladding panels, Plexiglass screens etc

- Material:

Stainless steel 1.4404 (316L)


Polished finish $Ra < 0.8$

Advantages

- The oversized flange and the thread undercut ensure a stress-free, uniform force distribution on the supported element.
- Optimised form for use in hygienic environments.
- Dirt and residue from products or cleaners are practically non-adherent, guaranteeing easy cleaning

Accessory

- For tightening and loosening the screws without damaging them, use the **CM** flat spanner with protective cap (cf. page 63) in combination with the **CM-CF** accessory (cf. page 62).

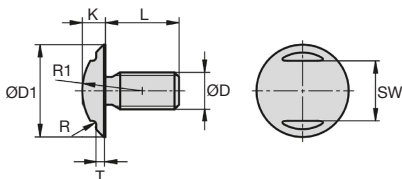

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	Net	-5%	-10%	On request

Part N°	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4.
VTSM3-4/HDSS	M3	8	1,8	0,6	5	0,3	5,2	4	5,89 €
VTSM3-5/HDSS	M3	8	1,8	0,6	5	0,3	5,2	5	5,89 €
VTSM3-6/HDSS	M3	8	1,8	0,6	5	0,3	5,2	6	5,99 €
VTSM3-8/HDSS	M3	8	1,8	0,6	5	0,3	5,2	8	6,06 €
VTSM3-10/HDSS	M3	8	1,8	0,6	5	0,3	5,2	10	6,16 €
VTSM4-5/HDSS	M4	11	2,9	1	6	0,3	6,7	5	6,13 €
VTSM4-6/HDSS	M4	11	2,9	1	6	0,3	6,7	6	6,13 €
VTSM4-8/HDSS	M4	11	2,9	1	6	0,3	6,7	8	6,24 €
VTSM4-10/HDSS	M4	11	2,9	1	6	0,3	6,7	10	6,32 €
VTSM4-12/HDSS	M4	11	2,9	1	6	0,3	6,7	12	6,34 €

All dimensions in mm

Part N°	ØD	ØD1	K	T	SW	R	R1	L	Price each.
									1 to 4
VTSM5-6/HDSS	M5	14	4,0	1	8	0,4	8,6	6	6,51 €
VTSM5-8/HDSS	M5	14	4,0	1	8	0,4	8,6	8	6,69 €
VTSM5-10/HDSS	M5	14	4,0	1	8	0,4	8,6	10	6,79 €
VTSM5-12/HDSS	M5	14	4,0	1	8	0,4	8,6	12	6,95 €
VTSM5-16/HDSS	M5	14	4,0	1	8	0,4	8,6	16	7,11 €
VTSM6-8/HDSS	M6	17	5,0	1,5	10	0,6	10	8	7,01 €
VTSM6-10/HDSS	M6	17	5,0	1,5	10	0,6	10	10	7,19 €
VTSM6-12/HDSS	M6	17	5,0	1,5	10	0,6	10	12	7,37 €
VTSM6-16/HDSS	M6	17	5,0	1,5	10	0,6	10	16	7,67 €
VTSM6-20/HDSS	M6	17	5,0	1,5	10	0,6	10	20	7,85 €
VTSM8-10/HDSS	M8	20	5,0	1,5	13	0,8	13	10	7,27 €
VTSM8-12/HDSS	M8	20	5,0	1,5	13	0,8	13	12	7,48 €
VTSM8-16/HDSS	M8	20	5,0	1,5	13	0,8	13	16	7,82 €
VTSM8-20/HDSS	M8	20	5,0	1,5	13	0,8	13	20	8,09 €
VTSM8-25/HDSS	M8	20	5,0	1,5	13	0,8	13	25	8,19 €
VTSM10-12/HDSS	M10	22	6,4	1,5	15	0,9	13,5	12	9,54 €
VTSM10-16/HDSS	M10	22	6,4	1,5	15	0,9	13,5	16	9,81 €
VTSM10-20/HDSS	M10	22	6,4	1,5	15	0,9	13,5	20	10,10 €
VTSM10-25/HDSS	M10	22	6,4	1,5	15	0,9	13,5	25	10,37 €
VTSM10-30/HDSS	M10	22	6,4	1,5	15	0,9	13,5	30	10,58 €
VTSM10-37/HDSS	M10	22	6,4	1,5	15	0,9	13,5	37	10,84 €
VTSM12-16/HDSS	M12	27	7,5	1,5	19	1,0	16,3	16	11,40 €
VTSM12-20/HDSS	M12	27	7,5	1,5	19	1,0	16,3	20	11,74 €
VTSM12-25/HDSS	M12	27	7,5	1,5	19	1,0	16,3	25	12,35 €
VTSM12-30/HDSS	M12	27	7,5	1,5	19	1,0	16,3	30	12,88 €
VTSM12-35/HDSS	M12	27	7,5	1,5	19	1,0	16,3	35	13,38 €
VTSM16-20/HDSS	M16	36	9,0	1,5	24	1,1	23	20	15,00 €
VTSM16-25/HDSS	M16	36	9,0	1,5	24	1,1	23	25	15,82 €
VTSM16-30/HDSS	M16	36	9,0	1,5	24	1,1	23	30	16,64 €
VTSM16-35/HDSS	M16	36	9,0	1,5	24	1,1	23	35	17,94 €
VTSM16-40/HDSS	M16	36	9,0	1,5	24	1,1	23	40	18,41 €


All dimensions in mm

Our other products



MO

Worm and wheel set,
Non hardened steel

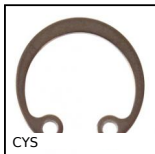

CYS

Internal circlip
DIN472, internal DIN
472



SUP

Self-centering
clamping hub steel,
Without locknut



SEH

Horizontal stirrup
toggle clamp,
Horizontal stirrup
clamp - steel



BABT

Hardened Stainless
steel ball pin,
Hardened stainless
steel



DOMI80

Accessories, Clamping
lever



 
RTT

Locking Assembly,
Medium/high torque



VELprf

Clip-on base for hook-
and-loop strip,
Polyamide



BETA

Hitch pin, Hitch




SUPCC

Self-centering
clamping hub steel,



CABPVC

PVC covered
galvanised steel

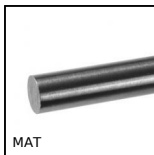

MAT

Drawn ground round
bar, 100C6 steel bar

Complementary products

transparen...



CM

Tools Hygienic Usit®
and Hygienic
Design®, Protective
inserts for ...



CM_CO

Tools Hygienic Usit®
and Hygienic
Design®, Protective
inserts for ...