



Flanged polymer nut

1 trapezoidal right-hand thread

WFRM



- Material: **iglidur®** W300

Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

Accessories

- **LFM** steel lead screw or **LSM** stainless steel lead screw

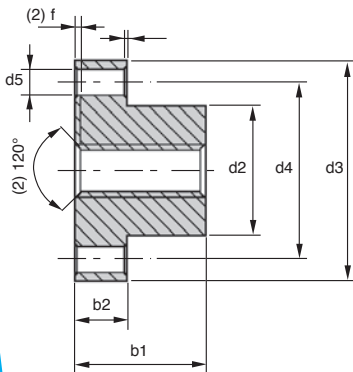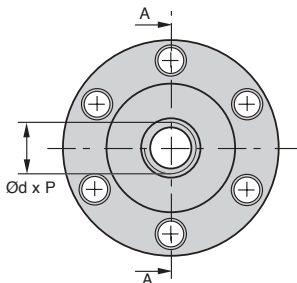

No maintenance

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	d2	d3	d4	d5	b1	b2	Stock*	Price each 1 to 5
WFRM102	10	2	25	42	34	5	25	10	✓	30,88 €
WFRM123	12	3	28	48	38	6	35	12	✓	37,72 €
WFRM164	16	4	28	48	38	6	35	12	✓	48,24 €
WFRM184	18	4	28	48	38	6	35	12	✓	57,36 €
WFRM204	20	4	32	55	45	7	44	12	✓	57,56 €
WFRM245	24	5	32	55	45	7	44	12	✓	79,83 €
WFRM306	30	6	38	62	50	7	46	14	✓	86,87 €

*Depending on availability - Dimensions in mm

Our other products



AXTR

Axle for tensioner pulley, Shaft



SSE

Stainless steel spherical bearing, Stainless steel / PTFE



PLN

Cylindrical spacer, Thermoplastic



BABTss

303 Stainless steel ball pin, 303 Stainless steel



DOMI80

Accessories, Fixing kit



BLHB20

Right angled gearbox, bored shafts, up to 1.77 Nm



 
RHTplss

High Temperature Castor, up to 200kg



CHMBR

Reaction arm, CHM and CHMR gear reducers reaction arm



M1

Worm and wheel set, Machined plastic (delrin)



 
PML

Solid foot mount for heavy loads, Ø 100, 120 or 150



NCT

Square tube connector, Fixed angle



UCF PBT


Stainless steel/Polymer flanged bearing, Polymer and stainless steel

Complementary products



LFM

Steel leadscrew, Medium carbon steel - 1 thread

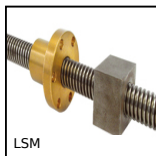


LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



LFM

Steel leadscrew, Medium carbon steel - 1 thread

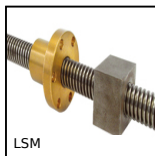

LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread