

Manually operated wing nut

WING

Steel (ANSI B18-17) or
Stainless steel (DIN315/315)

- **Wing nut**

- **Materials:**


Steel wing nut (conforms to ANSI B18-17):

chromed forged steel

Stainless steel wing nut

(conforms to DIN314/315):

A2 stainless steel

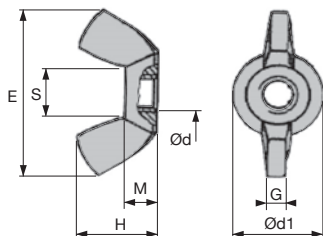

DISCOUNTS

| | | | | |
|---------------|------|-----|------|------------|
| Qty per packs | 1+ | 6+ | 20+ | 50+ |
| Discounts | List | -5% | -20% | On request |


| Part number | Ød | Ød1 | S | E | G | H | M | Qty per packs | Price each 1 to 5 |
|---------------------------|-----|------|-----|------|-----|------|-----|---------------|-------------------|
| Steel | | | | | | | | | |
| WING-M3/B | M3 | 7,5 | - | 18,5 | - | 8,8 | 3,0 | 500 | 46,18 € |
| WING-M4/B | M4 | 7,8 | - | 18,5 | - | 8,8 | 3,0 | 500 | 49,76 € |
| WING-M5/B | M5 | 9,5 | - | 22,5 | - | 10,5 | 3,8 | 500 | 51,19 € |
| WING-M6/B | M6 | 12,4 | - | 27,2 | - | 12,7 | 4,7 | 500 | 57,57 € |
| WING-M8/B | M8 | 13,5 | - | 30,0 | - | 14,6 | 5,6 | 200 | 30,05 € |
| WING-M10/B | M10 | 15,6 | - | 35,0 | - | 16,7 | 6,3 | 200 | 48,64 € |
| WING-M12/B | M12 | 20,5 | - | 47,6 | - | 22,3 | 7,5 | 100 | 53,29 € |
| A2 stainless steel | | | | | | | | | |
| WING-M3/SS/B | M3 | 6,8 | 4,5 | 15,3 | 1,2 | 7,2 | 2,4 | 100 | 13,61 € |
| WING-M4/SS/B | M4 | 8,0 | 5,2 | 17,6 | 1,6 | 8,6 | 2,9 | 100 | 12,98 € |
| WING-M5/SS/B | M5 | 10,3 | 6,7 | 22,5 | 2,1 | 11,0 | 4,1 | 100 | 14,14 € |
| WING-M6/SS/B | M6 | 12,7 | 8,4 | 27,8 | 2,5 | 13,6 | 5,1 | 100 | 20,01 € |
| WING-M8/SS/B | M8 | 13,8 | 9,1 | 30,3 | 2,8 | 14,8 | 5,6 | 100 | 28,23 € |
| WING-M10/SS/B | M10 | 16,5 | 11 | 36,2 | 3,3 | 17,7 | 6,8 | 100 | 50,21 € |
| WING-M12/SS/B | M12 | 22,5 | 15 | 49,4 | 4,5 | 24,1 | 9,0 | 50 | 53,53 € |

Dimensions in mm

Our other products



 Toggle latches,
Standard




Threaded stud -
DIN976A, Steel



Mushroom headed
button, M3 to M8



 Manual lifting tables,
20kg



Conical flexible shaft
handle Ø22, Black
PVC



Cam follower without
axial guide, With
interior ring



Moulded plastic bevel
gear (nylon), 3:1



Slat top chain
stainless steel, Large
range 805



Screw-in garnet
hinge, Screw-on



Worm and wheel gear
reducer, up to 164
Nm



Folding bracket, For
heavy loads



Pressed stainless
steel flange bearing,
Stainless steel

Complementary products



Self-locking nut, A2
Stainless steel



Hexagonal nut
DIN934, A2 Stainless
steel



Manually tightened
wing nut DIN315,
Brass DIN 315



Countersunk screw,
Stainless steel A2 -
DIN 7991