

Wing nut, hand tightened **DIN315**


Brass

WINGBR

- Wing nut conforming to DIN315
- Material:
Brass

Advantages

- Easy hand tightening

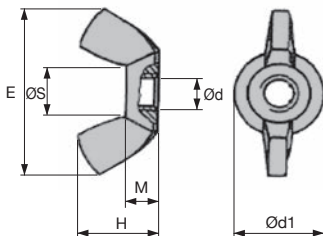

DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØD	E	H	M	ØD1	ØS	Qty/pack	Price each
								1 to 5
WING-M4/BR/B	M4	20	10,5	4,6	8	7	100	32,76 €
WING-M5/BR/B	M5	26	13	6,5	11	9	100	34,88 €
WING-M6/BR/B	M6	33	17	8	13	11	100	56,28 €
WING-M8/BR/B	M8	39	20	10	16	12,5	100	103,98 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

191

Our other products



GDR880
Straight track for slat top chain, Ranges 880 and 881



SH3
Parallel axis helical gear, Steel 20NCD2



UTKpwc
Utilitrak® 3 wheels carriage, Polymer series V wheels



CLB_T
Die cast zinc clamping lever - male, Zamak



HBM
Adjustment bushing for half-rail guide, Adjustment bushing




HLC19
Right angle spiro bevel gearbox, Up to 43Nm



M
Bellows cover, Accessory:



 BEAB
Knob star grip antibacterial, Star, anti-bacterial



QNU
Single row cylindrical roller bearing, Free inner ring



PPS
Lifting ring, Universal threaded



LRR
Catch-plate for latch, Catch-plate



CHMX_CHMDX
Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...

Complementary products



VTHbr
Hexagonal headed screw VTH - DIN933, Brass



WINGbrEcrou
Manually tightened wing nut DIN315, Brass DIN 315



SHNbr
Hexagonal nut DIN934, Brass



SHWbr
Washer - DIN125, Brass