

Wing nut, hand tightened **DIN315**


Brass

WINGBR

- Wing nut conforming to DIN315
- Material:
Brass

Advantages

- Easy hand tightening

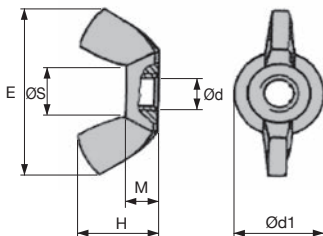

DISCOUNTS

| | | | |
|-------|-----|------|------------|
| Qty | 1+ | 6+ | 11+ |
| Disc. | Net | -10% | On request |

| Part N° | ØD | E | H | M | ØD1 | ØS | Qty/pack | Price each |
|--------------|----|----|------|-----|-----|------|----------|------------|
| | | | | | | | | 1 to 5 |
| WING-M4/BR/B | M4 | 20 | 10,5 | 4,6 | 8 | 7 | 100 | 32,76 € |
| WING-M5/BR/B | M5 | 26 | 13 | 6,5 | 11 | 9 | 100 | 34,88 € |
| WING-M6/BR/B | M6 | 33 | 17 | 8 | 13 | 11 | 100 | 56,28 € |
| WING-M8/BR/B | M8 | 39 | 20 | 10 | 16 | 12,5 | 100 | 103,98 € |

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



SH1

Parallel axis helical gear, Machined plastic (delrin)



MEB

Moulded plastic bevel gear (nylon), 1:1



BPM_LOK

Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...



BTC20_10

End cap for rectangular tube, Standard



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



GFX

Curved tooth coupling, economy range, Steel and polyamide



GE1006

Elastic ringed latch, Hooks into a slot



HCSS

Set screw with hexagonal socket, Cup point



KKB-AR

Linear bearing with inclined ball tracks,



PRES

Manual workbench press accessory for



PT880

Drive sprocket for slat top chain, Range 880



PT881

Drive sprocket for slat top chain, Range 881

Complementary products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



SHNbr

Hexagonal nut DIN934, Brass



SHWbr

Washer - DIN125, Brass