

Wing nut, hand tightened **DIN315**


Brass

WINGBR

- Wing nut conforming to DIN315
- Material:
Brass

Advantages

- Easy hand tightening

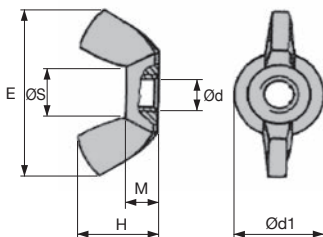

DISCOUNTS


Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØD	E	H	M	ØD1	ØS	Qty/pack	Price each
								1 to 5
WING-M4/BR/B	M4	20	10,5	4,6	8	7	100	32,76 €
WING-M5/BR/B	M5	26	13	6,5	11	9	100	34,88 €
WING-M6/BR/B	M6	33	17	8	13	11	100	56,28 €
WING-M8/BR/B	M8	39	20	10	16	12,5	100	103,98 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products

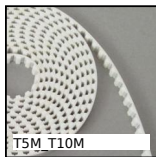

T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



SUPss

Self-centering clamping hub stainless steel, Without locknut



TCLar

Automatic chain tensioner, With wide guide



DOMI30

Accessories, Fixing kit



RAG-12-M8

Roller guide accessory, Anchoring system



TSRTC

Stem support for caster, For swivel caster with central hole



BCAss

Stainless steel splined bush, Inox



 
R205

Die spring ISO10243, Heavy



MHX

Hexagonal threaded sleeve, Hexagonal - steel



GPLac

Brush, steel



RDS

Safety washer Hygienic Usit®, Stainless steel

Complementary products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass




WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



SHNbr

Hexagonal nut DIN934, Brass

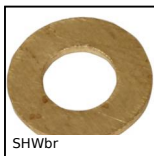

SHWbr

Washer - DIN125, Brass