

# Wing nut, hand tightened **DIN315**


Brass

**WINGBR**

- Wing nut conforming to DIN315
- Material:  
Brass

## Advantages

- Easy hand tightening

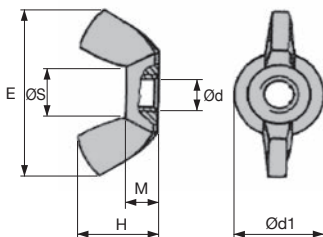

## DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØD	E	H	M	ØD1	ØS	Qty/pack	Price each
								1 to 5
WING-M4/BR/B	M4	20	10,5	4,6	8	7	100	32,76 €
WING-M5/BR/B	M5	26	13	6,5	11	9	100	34,88 €
WING-M6/BR/B	M6	33	17	8	13	11	100	56,28 €
WING-M8/BR/B	M8	39	20	10	16	12,5	100	103,98 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

## Our other products



AT5M AT10M  
AT type timing belt per metre, AT10 Steel cored polyurethane



CDC  
Conical compression spring, Conical



ZB  
Shaft for linear guides, Hardened ground stainless steel



PRS30  
Stainless steel articulated foot Ø30, Ø 30



BPHfclip  
Clip for ball transfer unit, Insert clip - Installing from above



VPSS  
Small 6 lobe threaded handle - male, Duroplast - Stainless steel




T5P\_T10P  
Connecting plate for T type timing belts, T10



LRRss  
Latch, Spring loaded latch - stainless steel



 
CHA225  
Screwed hinge with threaded insert, 225



LAT2  
2A motorised linear actuator, 2 amperes



 G3-ECO  
Eco range Spur gear, Steel C45



PO  
Pull handle - Multi-sector, Smooth hole

## Complementary products



VTHbr  
Hexagonal headed screw VTH - DIN933, Brass



WINGbrEcrou  
Manually tightened wing nut DIN315, Brass DIN 315



SHNbr  
Hexagonal nut DIN934, Brass



SHWbr  
Washer - DIN125, Brass