

Wing nut, hand tightened **DIN315**


Brass

WINGBR

- Wing nut conforming to DIN315
- Material:
Brass

Advantages

- Easy hand tightening

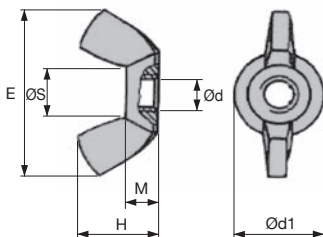

DISCOUNTS


Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØD	E	H	M	ØD1	ØS	Qty/pack	Price each
								1 to 5
WING-M4/BR/B	M4	20	10,5	4,6	8	7	100	32,76 €
WING-M5/BR/B	M5	26	13	6,5	11	9	100	34,88 €
WING-M6/BR/B	M6	33	17	8	13	11	100	56,28 €
WING-M8/BR/B	M8	39	20	10	16	12,5	100	103,98 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products

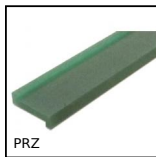

PRZ

Wear strip for slat top chain, Z profile to be clipped



SVG

Adjustable latch clamp with strike plate, Stroke from 82mm to 92mm



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Steel



PAS

Pull handle, Reinforced PA thermoplastic



TS01_TW01

Drylin® T linear slide, up to 7000 N



PO

Pull handle - Multi-sector, Smooth hole




CHAGC-AL

Screw-in garnet hinge, Screw-on



CHA35

 Hinge for aluminium profile, Hinge



LRH

Bi-directional leadscrew, Bi-



PRF_ECL

Nut for aluminium profile, Steel square



R205

Die spring ISO10243, Heavy



TOC

Short swivel head, Short

Complementary products



VTHbr

Hexagonal headed screw VTH - DIN933, Brass



WINGbrEcrou

Manually tightened wing nut DIN315, Brass DIN 315



SHNbr

Hexagonal nut DIN934, Brass



SHWbr

Washer - DIN125, Brass