

Wing nut, hand tightened **DIN315**


Brass

WINGBR

- Wing nut conforming to DIN315
- Material:
Brass

Advantages

- Easy hand tightening

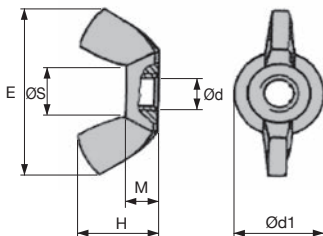

DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request

Part N°	ØD	E	H	M	ØD1	ØS	Qty/pack	Price each
								1 to 5
WING-M4/BR/B	M4	20	10,5	4,6	8	7	100	32,76 €
WING-M5/BR/B	M5	26	13	6,5	11	9	100	34,88 €
WING-M6/BR/B	M6	33	17	8	13	11	100	56,28 €
WING-M8/BR/B	M8	39	20	10	16	12,5	100	103,98 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products




BFM2
Flanged bronze nut,
Bronze - 2 threads



HRV
V-rail guidance
Simple Select®
system, Rail with
carriage



WJUM20
Drylin® W bearing
block, Slide

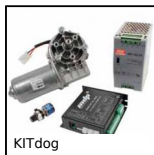

KITdog
24V DC motorisation
kit, Worm and wheel



BLHB50
Right angled gearbox,
bored shafts, up to 30
Nm



BABV
Ball lock pins lockable
, Stainless steel



GMK17_BR
Clamp for guiding
profile, Rounded only
- single



LRM2
Cylindrical bronze nut,
Bronze - 2 threads



SRG
Adjustable latch
clamp with strike



PTAF100-PAMF100
Articulated fixable
foot with pressed



SER69K
Quarter turn latch for
the food industry,



SLB
Indexing plunger,
stainless steel

Complementary products




VTHbr
Hexagonal headed
screw VTH - DIN933,
Brass



WINGbrEcrou
Manually tightened
wing nut DIN315,
Brass DIN 315



SHNbr
Hexagonal nut
DIN934, Brass

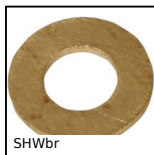

SHWbr
Washer - DIN125,
Brass