

Wing screw, hand tightened **DIN316**

WINGBR

Brass


- Wing screw conforming to DIN316

- Material

Brass

Advantages

- Easy hand tightening

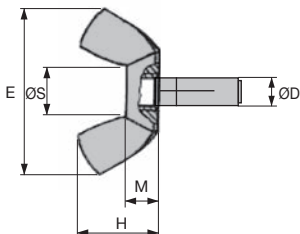

DISCOUNTS

Qty	1+	6+	11+
Disc.	Net -10%	On request	

Part N°	ØD	L	E	H	M	ØD1	ØS	Qty/pack	Price each	
									1 to 5	
WING-M4-10/BR/B	M4	10	20	10,5	4,6	8	7	100	40,03	€
WING-M4-16/BR/B	M4	16	20	10,5	4,6	8	7	100	65,78	€
WING-M4-20/BR/B	M4	20	20	10,5	4,6	8	7	100	82,43	€
WING-M5-10/BR/B	M5	10	26	13	6,5	11	9	100	83,14	€
WING-M5-16/BR/B	M5	16	26	13	6,5	11	9	100	88,64	€
WING-M5-20/BR/B	M5	20	26	13	6,5	11	9	100	99,40	€
WING-M5-25/BR/B	M5	25	26	13	6,5	11	9	100	105,13	€
WING-M5-30/BR/B	M5	30	26	13	6,5	11	9	100	116,66	€
WING-M6-16/BR/B	M6	16	33	17	8	13	11	100	97,91	€
WING-M6-20/BR/B	M6	20	33	17	8	13	11	100	114,75	€
WING-M6-25/BR/B	M6	25	33	17	8	13	11	100	122,15	€
WING-M6-30/BR/B	M6	30	33	17	8	13	11	100	129,99	€
WING-M6-40/BR/B	M6	40	33	17	8	13	11	100	153,23	€
WING-M8-10/BR/B	M8	10	39	20	10	16	12,5	50	145,45	€
WING-M8-16/BR/B	M8	16	39	20	10	16	12,5	50	163,93	€
WING-M8-20/BR/B	M8	20	39	20	10	16	12,5	50	177,81	€
WING-M8-25/BR/B	M8	25	39	20	10	16	12,5	50	190,69	€
WING-M8-30/BR/B	M8	30	39	20	10	16	12,5	50	202,99	€
WING-M8-40/BR/B	M8	40	39	20	10	16	12,5	50	243,49	€

All dimensions in mm

Our other products



PW_PWG25
Worm - precision range, Stainless steel




RPCtcss
Swivel castor with central hole, Stainless steel - Polyamide - with ...



DSF
Slip friction clutch, 4 to 2600 Nm



 AC156-157
Strike for toggle latch, 25.5mm



GPLac
Brush, steel



BLHT20
Right angled gearbox, from 0.66 to 1.77 Nm



CHAsb89
Hinge without pin, Plastic hinge



RT61
Self-centering locking Assembly, Medium/low torque



CHC
Socket headed screw, Steel class 12.19



SRG
Adjustable latch clamp with strike



PAV
Fixed anti-vibration foot mount, Vibration-



CHAfr
Adjustable friction hinges, Friction

Complementary products



 
VTHbr
Hexagonal headed screw VTH - DIN933, Brass



WINGbr
Wing screw, hand tightened DIN316, Brass DIN 316



SHNbr
Hexagonal nut DIN934, Brass



SHWbr
Washer - DIN125, Brass