

Wing screw, hand tightened **DIN316**

WINGBR

Brass


- Wing screw conforming to DIN316

- Material

Brass

Advantages

- Easy hand tightening

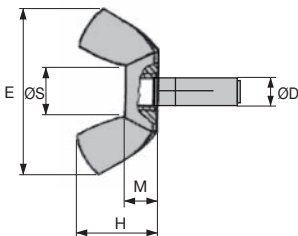

DISCOUNTS

Qty	1+	6+	11+
Disc.	Net	-10%	On request


Part N°	ØD	L	E	H	M	ØD1	ØS	Qty/pack	Price each	
									1 to 5	
WING-M4-10/BR/B	M4	10	20	10,5	4,6	8	7	100	40,03	€
WING-M4-16/BR/B	M4	16	20	10,5	4,6	8	7	100	65,78	€
WING-M4-20/BR/B	M4	20	20	10,5	4,6	8	7	100	82,43	€
WING-M5-10/BR/B	M5	10	26	13	6,5	11	9	100	83,14	€
WING-M5-16/BR/B	M5	16	26	13	6,5	11	9	100	88,64	€
WING-M5-20/BR/B	M5	20	26	13	6,5	11	9	100	99,40	€
WING-M5-25/BR/B	M5	25	26	13	6,5	11	9	100	105,13	€
WING-M5-30/BR/B	M5	30	26	13	6,5	11	9	100	116,66	€
WING-M6-16/BR/B	M6	16	33	17	8	13	11	100	97,91	€
WING-M6-20/BR/B	M6	20	33	17	8	13	11	100	114,75	€
WING-M6-25/BR/B	M6	25	33	17	8	13	11	100	122,15	€
WING-M6-30/BR/B	M6	30	33	17	8	13	11	100	129,99	€
WING-M6-40/BR/B	M6	40	33	17	8	13	11	100	153,23	€
WING-M8-10/BR/B	M8	10	39	20	10	16	12,5	50	145,45	€
WING-M8-16/BR/B	M8	16	39	20	10	16	12,5	50	163,93	€
WING-M8-20/BR/B	M8	20	39	20	10	16	12,5	50	177,81	€
WING-M8-25/BR/B	M8	25	39	20	10	16	12,5	50	190,69	€
WING-M8-30/BR/B	M8	30	39	20	10	16	12,5	50	202,99	€
WING-M8-40/BR/B	M8	40	39	20	10	16	12,5	50	243,49	€

All dimensions in mm

Our other products



 Wheel - precision range, Bronze



RPP heavy duty timing belt, RPP14



Ballscrew bearing unit, Support



Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



Worm and wheel gear reducer, up to 540 Nm



 
Multifunction display, Magnetic band



Steel spur gear, Steel 20NCD2



Fixed rubber levelling foot, Levelling support for small parts



Strike for toggle latch, 18mm



Moulded plastic bevel gear (nylon), 1.5:1



Steel spur gear, Steel 20NCD2



Long-Lok slotted spring plunger with ball tip, LONG-LOK - Stainless ...

Complementary products



Hexagonal headed screw VTH - DIN933, Brass



Wing screw, hand tightened DIN316, Brass DIN 316



Hexagonal nut DIN934, Brass



Washer - DIN125, Brass