

DryLin® W bearing block




WJUM10 Size 10 - For loads of up to 1200N




- Material:
Housing: Zamak
Liner: iglidur®J200

Advantages

- Full design flexibility using **WS10** single rails and **WJUM01-10** bearing blocks

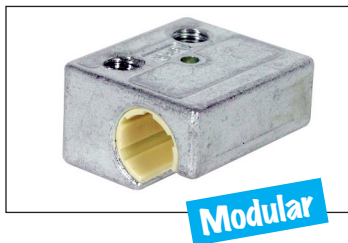

Modular

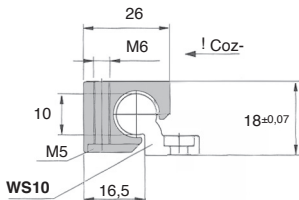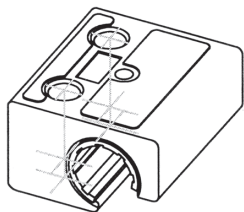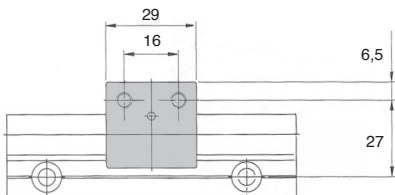

DISCOUNTS

Qty	1+	5+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	Type	Backlash (mm)	Weight (g)	Max. static load (20°C)			Stock*	Price each 1 to 4
				Coy (N)	Coz+ (N)	Coz- (N)		
WJUM01-10	Fixed	0	27	1200	1200	250	✓	9,06 €
WJUM01-10-LL	Floating	±0,2	27	1200	1200	250	✓	9,06 €

*Depending on availability - Dimensions in mm

Our other products



S_2RS

Deep groove ball bearing, Stainless steel



GALRUB

60mm rubber wheel for conveyor belt, Rubber



VQT

Quarter-turn clamp lock, Plastic or stainless steel button



GP75

Spring loaded toggle latch, Standard (GP75)



BPLE

Ball transfer unit push fit, Light



BOX-SHNA

Hexagonal nut - DIN934, Box set of steel nuts



RNAST

Cam follower without axial guide, Without interior ring



DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



FF50

Offset spur gear reducer, from 111 to 425 Nm



PSG155

Spur gear - precision range, Stainless steel 303



NKIA

Combined bearing with inner ring, Axial load in one direction



JCSs

Single stainless steel universal joint, Low duty

Complementary products



WS10

Drylin® W rail, Rail



WW10

Drylin® W slide, slide assembly



WJRM

Drylin® W hybrid bearing block, Hybrid bearings