

# Cylindrical polymer nut



## WSRM 1 trapezoidal right-hand thread

- Material: **iglidur® W300**
- Working temperature: up to 90°C


### Accessories

- LFM steel lead screw or LSM stainless steel screw

### Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

No maintenance

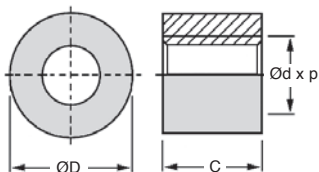

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	ØD	C	Stock*	Price each 1 to 5
WSRM102	10	2	22	15	✓	27,72 €
WSRM123	12	3	26	18	✓	33,81 €
WSRM164	16	4	30	24	✓	44,95 €
WSRM184	18	4	30	27	✓	48,24 €
WSRM204	20	4	30	25	✓	49,82 €
WSRM245	24	5	50	36	-	67,74 €
WSRM285	28	5	60	42	-	76,54 €
WSRM306	30	6	60	45	-	79,58 €

\*Depending on availability - Dimensions in mm

## Our other products




PM2

Worm and wheel set,  
Bronze



KBS\_UU

 Stainless steel closed  
precision linear  
bearing, Precision -  
stainle...



TC1rp

Automatic chain  
tensioner, With 180°  
guide



VPRA\_M

Handwheel with  
handle,  
Thermosetting plastic  
- stainless steel hub



 
AZY

Cylindrical elasto  
mount, Steel



VRM

Female swivelling  
lifting rings, Female  
swivelling



KSM

Cylindrical steel nut,  
Steel - 1 thread



CFF

Female rod ends DIN  
ISO12240-4, Steel /  
bronze



PR125rehausse

Extension for  
articulated foot Ø123,  
articulated foot PR125



INS100

Self tapping inserts-  
coarse thread, Coarse  
thread



TS01\_TW01

Drylin® T linear slide,  
up to 7000 N



BSCf


Knurled torque knobs  
- female, Knurled  
threaded torque

## Complementary products



 LFM

Steel leadscrew,  
Medium carbon steel -  
1 thread



LSM

Stainless steel 316L  
leadscrew, Stainless  
steel - 1 thread