

# Cylindrical polymer nut



## WSRM 1 trapezoidal right-hand thread

- Material: **iglidur® W300**
- Working temperature: up to 90°C


### Accessories

- LFM steel lead screw or LSM stainless steel screw

### Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

No maintenance

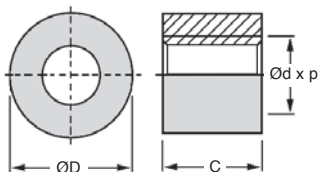

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	ØD	C	Stock*	Price each 1 to 5
WSRM102	10	2	22	15	✓	27,72 €
WSRM123	12	3	26	18	✓	33,81 €
WSRM164	16	4	30	24	✓	44,95 €
WSRM184	18	4	30	27	✓	48,24 €
WSRM204	20	4	30	25	✓	49,82 €
WSRM245	24	5	50	36	-	67,74 €
WSRM285	28	5	60	42	-	76,54 €
WSRM306	30	6	60	45	-	79,58 €

\*Depending on availability - Dimensions in mm

## Our other products



T10\_21N1F

T type timing pulley,  
Economy range - T10  
moulded plastic  
(nylon)



PTAF100-PAMF100

Articulated fixable  
foot with pressed  
base Ø100, Ø 100



 
PTKss

Foot for the food  
industry, Stainless  
steel - 3-A standard




PRF4545\_P

Stripp Aluminium  
profile with  
extendable slot, 45 x  
45 mm



M2

 Worm and wheel set,  
Bronze



RPP

Connecting plate for  
RPP type timing belts,  
RRP5



BOXbeta

Box of assorted hitch  
pins, Boxed set - hitch



LVT

Miniature motorised  
actuator 1A, 1 amper



YG1

HEAVY DUTY spur  
gear, Steel 35NCD6



T5M\_T10M

T type timing belt per  
metre, T5 Steel cored  
polyurethane



PRF\_JL6

Lip seal for panel,  
Door seal - Ø 6mm



MSP3815


Masterplate®  
glueable insert  
rectangular,  
rectangular with nut

## Complementary products



 LFM

Steel leadscrew,  
Medium carbon steel -  
1 thread



LSM

Stainless steel 316L  
leadscrew, Stainless  
steel - 1 thread