

# Cylindrical polymer nut



## WSRM 1 trapezoidal right-hand thread

- Material: **iglidur® W300**
- Working temperature: up to 90°C


### Accessories

- LFM steel lead screw or LSM stainless steel screw

### Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

No maintenance

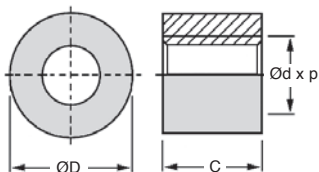

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	ØD	C	Stock*	Price each 1 to 5
WSRM102	10	2	22	15	✓	27,72 €
WSRM123	12	3	26	18	✓	33,81 €
WSRM164	16	4	30	24	✓	44,95 €
WSRM184	18	4	30	27	✓	48,24 €
WSRM204	20	4	30	25	✓	49,82 €
WSRM245	24	5	50	36	-	67,74 €
WSRM285	28	5	60	42	-	76,54 €
WSRM306	30	6	60	45	-	79,58 €


\*Depending on availability - Dimensions in mm

## Our other products



PF40

Worm and wheel gear reducer, up to 18 Nm

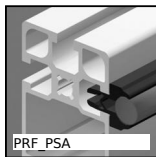

PRF\_PSA

Shaft support for aluminium profile, Shaft support



INS\_SS

Self tapping stainless steel insert, Stainless steel



PSG155

Spur gear - precision range, Stainless steel 316



T10courroie

T type timing belt, T10 Steel cored polyurethane



F7-SN

Multifunction display, Articulated support



INS\_BR

Self tapping brass insert, Brass



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



GPB

Threaded spherical knob, Moulded thread



TCXR

Automatic chain tensioner, With



SA\_SAKH

Housing for linear bearing, Closed - light



RAG


Roller guide,

## Complementary products



LFM

Steel leadscrew, Medium carbon steel - 1 thread

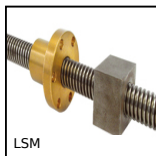

LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread