


Ball screws and trapezoidal leadscrew

What are they used for?

Ball screws and trapezoidal screws convert rotary motion into linear motion. The motion is that of a conventional screw-nut system.

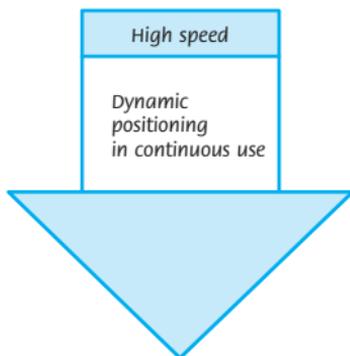


Ball screw

The balls, placed between the threads of the screw and nut, eliminate friction (similar to a ball bearing).

The efficiency is very high: nearly 98% compared to around 30% for a conventional trapezoidal thread.

Advantages: high efficiency, high travel speeds, long service life calculable, high precision (axial position, repeatability, etc.), no backlash to compensate for, easier movement control, and reduced heating.

Disadvantages: reversibility of the system; expensive, lubrication essential.

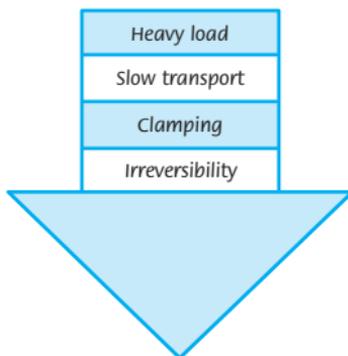

The trapezoidal leadscrew

For low-duty applications and not requiring such high precision, rolled-thread trapezoidal screws, combined with bronze, steel or plastic nuts, constitute economical drives with high load capacity.

Advantages: Trapezoidal lead screws with a helix angle of less than 2.5° can be considered irreversible (antibackdrive). Easy to install and maintain. Inexpensive.

Disadvantages: Low efficiency (approximately 30%), lower precision than ballcrews. Lubrication is essential.



- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e





Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

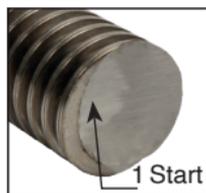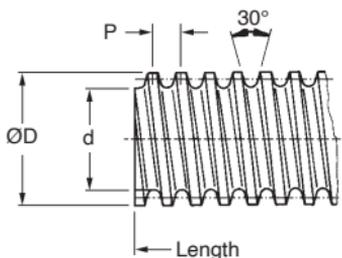

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	List	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qté	1+	5+	10+	
Rem.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	Ød mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	20 to 39**
LFM102	10	2	6,89	0,46	✓	A 9,19 €	A 5,51 €
LFM123	12	3	7,68	0,65	✓	A 13,04 €	A 7,82 €
LFM143	14	3	9,68	0,93	✓	A 16,96 €	A 10,18 €
LFM164	16	4	10,47	1,15	✓	A 20,76 €	A 12,46 €
LFM184	18	4	12,47	1,52	✓	A 25,59 €	A 15,35 €
LFM204	20	4	14,47	1,91	✓	A 30,67 €	A 18,40 €
LFM225	22	5	15,29	2,30	✓	A 36,77 €	A 22,06 €
LFM245	24	5	17,27	2,80	✓	A 42,20 €	A 25,32 €
LFM285	28	5	21,27	3,90	✓	A 58,51 €	A 35,11 €
LFM306	30	6	21,56	4,33	✓	A 64,00 €	A 38,40 €
LFM326	32	6	23,56	5,00	✓	A 74,52 €	A 44,71 €
LFM366	36	6	27,56	6,55	✓	B 58,80 €	B 55,86 €
LFM407	40	7	30,38	8,00	✓	B 73,84 €	B 70,15 €
LFM447	44	7	34,38	9,86	✓	B 97,42 €	B 92,55 €
LFM508	50	8	39,17	12,76	✓	B121,51 €	B 115,43 €
LFM609	60	9	47,98	18,65	-	B174,47 €	B 165,75 €
LFM7010	70	10	56,82	25,65	-	B238,46 €	B 226,54 €
LFM8010	80	10	66,82	34,21	-	B333,82 €	B 317,13 €
LFM9012	90	12	74,44	43,00	-	B513,29 €	B 487,63 €
LFM9516	95	16	73,71	45,60	-	B497,32 €	B 472,45 €
LFM10016	100	16	78,71	51,00	-	B559,44 €	B 531,47 €
LFM12016	120	16	98,71	76,00	-	B818,96 €	B 778,01 €

*Depending on availability - Dimensions in mm

** refer to discounts

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e





Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

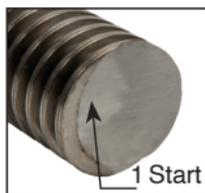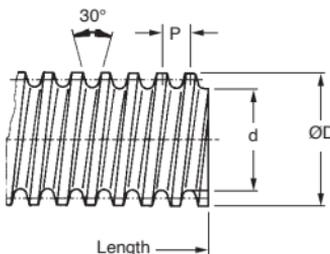

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qté	1+	5+	10+	
Rem.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	Ød mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	20 to 39**
LFM102/LH	10	2	6,89	0,46	✓	A 11,32 €	A 6,79 €
LFM123/LH	12	3	7,68	0,65	✓	A 16,13 €	A 9,68 €
LFM143/LH	14	3	9,68	0,93	✓	A 22,09 €	A 13,25 €
LFM164/LH	16	4	10,47	1,15	✓	A 25,08 €	A 15,05 €
LFM184/LH	18	4	12,47	1,52	-	A 30,81 €	A 18,49 €
LFM204/LH	20	4	14,47	1,91	✓	A 35,05 €	A 21,03 €
LFM225/LH	22	5	15,29	2,30	✓	A 43,48 €	A 26,09 €
LFM245/LH	24	5	17,27	2,80	✓	A 46,42 €	A 27,85 €
LFM285/LH	28	5	21,27	3,90	✓	A 68,68 €	A 41,21 €
LFM306/LH	30	6	21,56	4,33	✓	A 72,07 €	A 43,24 €
LFM326/LH	32	6	23,56	5,00	-	A 83,61 €	A 50,17 €
LFM366/LH	36	6	27,56	6,55	-	B 66,62 €	B 63,29 €
LFM407/LH	40	7	30,38	8,00	-	B 90,27 €	B 85,76 €
LFM447/LH	44	7	34,38	9,86	-	B 147,46 €	B 140,09 €
LFM508/LH	50	8	39,17	12,76	-	B 147,46 €	B 140,09 €
LFM609/LH	60	9	47,98	18,65	-	B 224,28 €	B 213,07 €
LFM7010/LH	70	10	56,82	25,65	-	B 306,16 €	B 290,85 €
LFM8010/LH	80	10	66,82	34,21	-	B 443,11 €	B 420,95 €
LFM8010/LH	80	10	66,82	34,21	-	B 443,11 €	B 420,95 €

* Depending on availability - Dimensions in mm

** refer to discounts

LSM

Right hand thread, 1 start

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L



Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (subject to diameter)

stainless steel

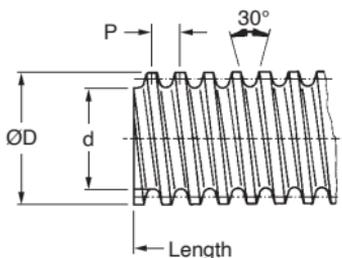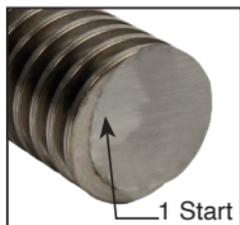

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	20 to 39**
LSM102	10	2	6,89	0,48	✓	A 67,97 €	A 40,78 €
LSM123	12	3	7,84	0,65	✓	A 53,16 €	A 31,89 €
LSM164	16	4	10,80	1,15	✓	A 84,57 €	A 50,74 €
LSM184	18	4	12,80	1,52	✓	A 105,53 €	A 63,32 €
LSM204	20	4	14,80	1,91	✓	A 127,18 €	A 76,31 €
LSM245	24	5	17,50	2,80	✓	A 172,15 €	A 103,29 €
LSM285	28	5	21,50	3,90	✓	A 244,66 €	A 146,80 €
LSM306	30	6	21,90	4,33	✓	B 169,51 €	B 161,03 €
LSM326	32	6	23,90	5,00	✓	B 197,91 €	B 188,01 €
LSM366	36	6	27,90	6,55	✓	B 250,81 €	B 238,27 €
LSM407	40	7	30,50	8,00	-	B 331,16 €	B 314,60 €
LSM508	50	8	39,17	12,76	-	B 509,48 €	B 484,01 €

*Depending on availability - Dimensions in mm

** refer to discounts

Left hand thread, 1 start

LSMLH

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Stainless steel 316L
- Thread tolerance: 7e

stainless steel





Uses

- Machine tools
- Lathe main screw

Options

- Available in lengths up to 6000mm (subject to diameter)

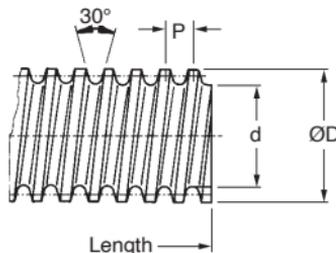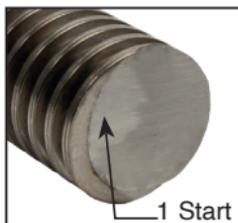

A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

B DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	5+	10+	
Disc.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	Ød mini.	Weight (kg/m)	Price each per metre
					1 to 9 20 to 39*
LSM123/LH	12	3	7,84	0,65	A 92,91 € A 55,75 €
LSM164/LH	16	4	10,80	1,15	A 120,56 € A 72,34 €
LSM184/LH	18	4	12,80	1,52	A 120,82 € A 72,49 €
LSM204/LH	20	4	14,80	1,91	A 149,24 € A 89,54 €
LSM245/LH	24	5	17,50	2,80	A 179,48 € A 107,69 €
LSM285/LH	28	5	21,50	3,90	A 269,62 € A 161,77 €
LSM306/LH	30	6	21,90	4,33	B 179,91 € B 170,92 €
LSM326/LH	32	6	23,90	5,00	B 227,83 € B 216,43 €
LSM366/LH	36	6	27,90	6,55	B 255,20 € B 242,44 €
LSM407/LH	40	7	30,50	8,00	B 371,55 € B 352,97 €

* Depending on availability - Dimensions in mm

** refer to discounts





LRH 1 right hand start, 1 left hand start

- Lead screw with 1 right hand thread and 1 left hand thread
- Machined trapezoidal thread conforming to BS 5346
- Thread tolerance: 7e
- Machined
- Material: Half-hard steel

Machined thread

Uses

- Machine tools
- Lathe main screw

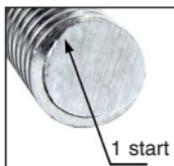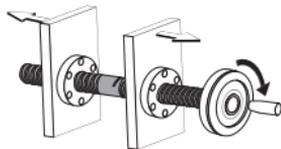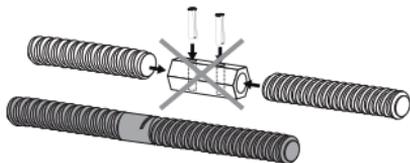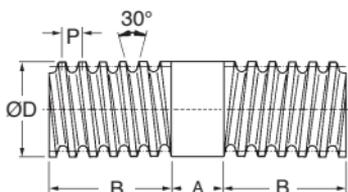

DISCOUNTS


Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	A (mm)	B (mm)	Stock*	Price each 1 to 4
Length 1000mm						
LRH164-1	16	4	20	490	✓	90,10 €
LRH184-1	18	4	20	490	✓	104,64 €
LRH204-1	20	4	20	490	✓	121,06 €
LRH245-1	24	5	20	490	✓	144,87 €
LRH285-1	28	5	20	490	-	154,21 €
LRH306-1	30	6	20	490	✓	190,20 €
LRH326-1	32	6	20	490	-	181,80 €
LRH366-1	36	6	20	490	-	230,25 €
Length 2000mm						
LRH164-2	16	4	20	990	✓	181,89 €
LRH184-2	18	4	20	990	-	211,16 €
LRH204-2	20	4	20	990	✓	244,37 €
LRH245-2	24	5	20	990	✓	278,45 €
LRH285-2	28	5	20	990	-	310,94 €
LRH306-2	30	6	20	990	✓	337,81 €
LRH326-2	32	6	20	990	-	366,54 €
LRH366-2	36	6	20	990	-	464,26 €

*Depending on availability - Dimensions in mm

1 trapezoidal right or left-hand thread VKM VKMLH

- Right or left hand thread
- Thread conforms to NFE 03.616
- Material: Steel 11SMnPb37
- Machined nut
- Thread tolerance: 7H

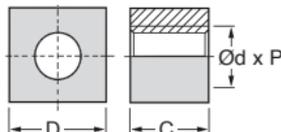

Use

- For manual operation
- For low speeds
- For clamping or locking functions
- To accommodate static loads
- The use of the steel/steel contact for motorised movements is not recommended

Accessories

- LFM steel leadscrew (tome 3 p.314-315)
- LSM stainless steel leadscrew (tome 3 p.316-317)

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qté	1+	5+	10+
Rem.	List	-5%	On request


Part number	Ød	Pitch P	D	C	Weight (kg)	Stock*	Price each	
							1 to 9	20 to 39**
Right-hand thread								
VKM102	10	2	17	15	0,027	✓	A 6,15 €	A 3,69 €
VKM123	12	3	25	18	0,076	✓	A 6,57 €	A 3,94 €
VKM143	14	3	25	20	0,079	✓	A 8,28 €	A 4,97 €
VKM164	16	4	28	24	0,119	✓	A 7,74 €	A 4,64 €
VKM184	18	4	30	28	0,154	✓	A 9,89 €	A 5,93 €
VKM204	20	4	35	30	0,259	✓	A 10,90 €	A 6,54 €
VKM225	22	5	35	33	0,240	✓	A 15,06 €	A 9,04 €
VKM245	24	5	40	36	0,354	✓	A 14,98 €	A 8,99 €
VKM285	28	5	45	42	0,506	✓	A 19,35 €	A 11,61 €
VKM306	30	6	45	45	0,513	✓	A 23,43 €	A 14,06 €
VKM326	32	6	55	48	0,891	✓	A 33,86 €	A 20,31 €
VKM366	36	6	60	54	1,163	✓	B 25,10 €	B 23,84 €
VKM407	40	7	60	60	1,216	✓	B 30,65 €	B 29,12 €
VKM447	44	7	65	66	1,538	-	B 42,58 €	B 40,45 €
Left-hand thread								
VKM102/LH	10	2	17	15	0,027	✓	A 8,00 €	A 4,80 €
VKM123/LH	12	3	25	18	0,076	✓	A 7,62 €	A 4,57 €
VKM143/LH	14	3	25	20	0,079	✓	A 10,05 €	A 6,03 €
VKM164/LH	16	4	28	24	0,119	✓	A 9,17 €	A 5,00 €
VKM184/LH	18	4	30	28	0,154	✓	A 11,91 €	A 7,14 €
VKM204/LH	20	4	35	30	0,259	✓	A 13,12 €	A 7,87 €
VKM225/LH	22	5	35	33	0,240	✓	A 16,91 €	A 10,14 €
VKM245/LH	24	5	40	36	0,354	✓	A 17,49 €	A 10,50 €
VKM285/LH	28	5	45	42	0,506	-	A 22,50 €	A 13,50 €
VKM306/LH	30	6	45	45	0,513	-	A 27,97 €	A 16,78 €
VKM326/LH	32	6	55	48	0,891	-	A 39,33 €	A 23,60 €
VKM366/LH	36	6	60	54	1,163	-	B 30,29 €	B 28,78 €
VKM407/LH	40	7	60	60	1,216	-	B 35,11 €	B 33,35 €
VKM447/LH	44	7	65	66	1,538	-	B 49,57 €	B 47,09 €

* Depending on availability - Dimensions in mm

** refer to discounts

KSM 1 trapezoidal right or left-hand thread KSM_{LH}

- Right or left-hand thread
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Steel 11SMnPb37

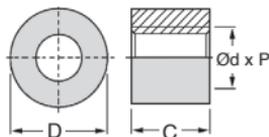

Accessories

- LFM steel leadscrew (tome 3 p.30)
- LSM stainless steel leadscrew (tome 3 p.302)

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	Pitch P	ØD	C	Weight (kg)	Stock*	Price each	
							1 to 9	20 to 39**
Right-hand thread								
KSM102	10	2	22	15	0,035	✓	A 9,76 €	A 5,85 €
KSM123	12	3	26	18	0,055	✓	A 5,77 €	A 3,46 €
KSM143	14	3	30	21	0,090	✓	A 16,03 €	A 9,62 €
KSM164	16	4	36	24	0,155	✓	A 8,20 €	A 4,92 €
KSM184	18	4	40	27	0,215	✓	A 9,50 €	A 5,70 €
KSM204	20	4	45	30	0,305	✓	A 11,31 €	A 6,79 €
KSM225	22	5	45	33	0,322	✓	A 13,08 €	A 7,85 €
KSM245	24	5	50	36	0,440	✓	A 15,82 €	A 9,49 €
KSM285	28	5	60	42	0,740	✓	A 24,10 €	A 14,46 €
KSM306	30	6	60	45	0,765	✓	A 23,81 €	A 14,28 €
KSM326	32	6	60	48	0,790	-	A 26,08 €	A 15,65 €
KSM366	36	6	75	54	1,470	-	B 28,99 €	B 27,54 €
KSM407	40	7	80	60	1,830	✓	B 33,53 €	B 31,86 €
KSM447	44	7	80	66	1,890	-	B On request	B On request
KSM508	50	8	90	75	2,695	-	B 87,90 €	B 83,51 €
KSM609	60	9	100	90	3,865	-	B 111,51 €	B 105,94 €
KSM7010	70	10	110	100	5,115	-	B 138,08 €	B 131,17 €
KSM8010	80	10	120	110	6,000	-	B 180,67 €	B 171,64 €
Left-hand thread								
KSM102/LH	10	2	22	15	0,035	-	A 14,55 €	A 8,73 €
KSM123/LH	12	3	26	18	0,055	✓	A 9,04 €	A 5,42 €
KSM143/LH	14	3	30	21	0,090	-	A 12,18 €	A 7,31 €
KSM164/LH	16	4	36	24	0,155	✓	A 11,02 €	A 6,61 €
KSM184/LH	18	4	40	27	0,215	-	A 10,65 €	A 6,39 €
KSM204/LH	20	4	45	30	0,305	✓	A 12,16 €	A 7,30 €
KSM225/LH	22	5	45	33	0,322	-	A 21,28 €	A 12,77 €
KSM245/LH	24	5	50	36	0,440	-	A 19,31 €	A 11,59 €
KSM285/LH	28	5	60	42	0,740	✓	A 29,77 €	A 17,86 €
KSM306/LH	30	6	60	45	0,765	-	A 45,71 €	A 27,43 €
KSM326/LH	32	6	60	48	0,790	-	A 34,03 €	A 20,42 €
KSM366/LH	36	6	75	54	1,470	-	B 30,95 €	B 29,40 €
KSM407/LH	40	7	80	60	1,830	-	B 36,94 €	B 35,09 €
KSM447/LH	44	7	80	66	1,890	-	B 40,58 €	B 38,55 €
KSM508/LH	50	8	90	75	2,695	-	B 149,80 €	B 142,31 €
KSM609/LH	60	9	100	90	3,865	-	B 173,73 €	B 165,04 €
KSM7010/LH	70	10	110	100	5,115	-	B 197,96 €	B 188,06 €
KSM8010/LH	80	10	120	110	6,000	-	B 230,37 €	B 218,85 €

*Depending on availability - Dimensions in mm


** refer to discounts

1 trapezoidal right or left-hand thread SKM SKMLH

- Thread conforms to NFE 03.616
- Material: Steel 11SMnPb37
- Thread tolerance: 7H

Use

- For manual operation
- For low speeds
- For clamping or locking functions
- To accommodate static loads
- The use of the steel/steel contact for motorised movements is not recommended

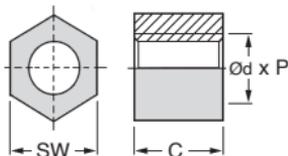

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List -30%	-40%	On request	

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List -5%	On request	

Part number	Ød	Pitch P	SW	C	Weight (kg)	Stock*	Price each	
							1 to 9	20 to 39**
Right-hand thread								
SKM102	10	2	17	15	0,022	✓	A 5,34 €	A 3,21 €
SKM123	12	3	19	18	0,032	✓	A 5,38 €	A 3,23 €
SKM143	14	3	22	21	0,049	✓	A 7,32 €	A 4,39 €
SKM164	16	4	24	24	0,065	✓	A 7,37 €	A 4,42 €
SKM184	18	4	27	27	0,091	✓	A 9,09 €	A 5,45 €
SKM204	20	4	30	30	0,124	✓	A 9,17 €	A 5,50 €
SKM225	22	5	30	33	0,125	✓	A 11,52 €	A 6,91 €
SKM245	24	5	36	36	0,219	✓	A 11,95 €	A 7,17 €
SKM285	28	5	41	42	0,318	✓	A 15,10 €	A 9,06 €
SKM306	30	6	46	45	0,445	✓	A 16,99 €	A 10,19 €
SKM326	32	6	50	48	0,567	✓	A 23,18 €	A 13,91 €
SKM366	36	6	55	54	0,708	✓	B 16,95 €	B 16,10 €
SKM407	40	7	60	60	0,893	✓	B 24,55 €	B 23,33 €
SKM447	44	7	65	66	1,538	-	B On request	B On request
SKM508	50	8	75	75	1,889	✓	B 74,04 €	B 70,34 €
SKM609	60	9	90	90	3,277	-	B 111,11 €	B 105,55 €
Left-hand thread								
SKM102/LH	10	2	17	15	0,022	-	A 8,03 €	A 4,82 €
SKM123/LH	12	3	19	18	0,032	-	A 7,44 €	A 4,47 €
SKM143/LH	14	3	22	21	0,049	-	A 11,52 €	A 6,91 €
SKM164/LH	16	4	24	24	0,065	-	A 9,54 €	A 5,73 €
SKM184/LH	18	4	27	27	0,091	-	A 13,62 €	A 8,17 €
SKM204/LH	20	4	30	30	0,124	-	A 11,53 €	A 6,92 €
SKM225/LH	22	5	30	33	0,125	-	A 16,91 €	A 10,14 €
SKM245/LH	24	5	36	36	0,219	-	A 14,26 €	A 8,56 €
SKM285/LH	28	5	41	42	0,318	-	A 19,64 €	A 11,79 €
SKM306/LH	30	6	46	45	0,445	-	A 21,79 €	A 13,07 €
SKM326/LH	32	6	50	48	0,567	-	A 27,30 €	A 16,38 €
SKM366/LH	36	6	55	54	0,708	-	B 19,94 €	B 18,94 €
SKM407/LH	40	7	60	60	0,893	-	B 29,63 €	B 28,15 €
SKM447/LH	44	7	65	66	1,538	-	B 34,00 €	B 32,30 €
SKM508/LH	50	8	75	75	1,889	-	B 118,59 €	B 112,66 €
SKM609/LH	60	9	90	90	3,277	-	B 148,44 €	B 141,02 €


*Depending on availability - Dimensions in mm

** refer to discounts

LRM LRMLH

1 start, right or left hand

- Right or left hand thread
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

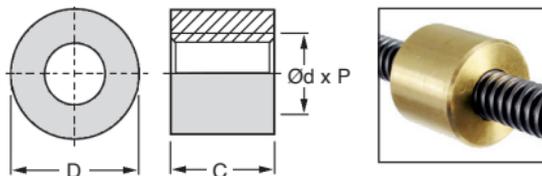

Use

- For manual operation
- For low speeds
- For clamping or locking functions
- To accommodate static loads
- The use of the steel/steel contact for motorised movements is not recommended

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	Pitch P	ØD	C	Weight (kg)	Stock*	Price each	
							1 to 9	20 to 39**
Right hand thread								
LRM102	10	2	22	20	0,053	✓	A 14,08 €	A 8,45 €
LRM123	12	3	26	24	0,083	✓	A 15,09 €	A 9,05 €
LRM143	14	3	30	28	0,135	✓	A 21,46 €	A 12,88 €
LRM164	16	4	36	32	0,232	✓	A 29,81 €	A 17,88 €
LRM184	18	4	40	36	0,320	✓	A 37,97 €	A 22,78 €
LRM204	20	4	45	40	0,455	✓	A 49,90 €	A 29,94 €
LRM225	22	5	45	44	0,480	✓	A 53,84 €	A 32,31 €
LRM245	24	5	50	48	0,656	✓	A 69,00 €	A 41,40 €
LRM285	28	5	60	56	1,102	✓	A 109,57 €	A 65,74 €
LRM306	30	6	60	60	1,140	✓	A 110,95 €	A 66,57 €
LRM326	32	6	60	64	1,177	✓	A 118,53 €	A 71,12 €
LRM366	36	6	75	72	2,189	✓	B 130,81 €	B 124,26 €
LRM407	40	7	80	80	2,725	✓	B 167,77 €	B 159,38 €
LRM447	44	7	80	88	2,815	-	B On request	B On request
LRM508	50	8	90	100	4,014	-	B 250,04 €	B 237,53 €
LRM609	60	9	100	120	5,150	-	B 331,51 €	B 314,94 €
Left hand threaded								
LRM102/LH	10	2	22	20	0,053	✓	A 18,83 €	A 11,30 €
LRM123/LH	12	3	26	24	0,083	✓	A 16,85 €	A 10,11 €
LRM143/LH	14	3	30	28	0,135	-	A On request	A On request
LRM164/LH	16	4	36	32	0,232	✓	A 31,60 €	A 18,96 €
LRM184/LH	18	4	40	36	0,320	✓	A 40,49 €	A 24,29 €
LRM204/LH	20	4	45	40	0,455	✓	A 52,44 €	A 31,46 €
LRM225/LH	22	5	45	44	0,480	✓	A 68,84 €	A 41,30 €
LRM245/LH	24	5	50	48	0,656	✓	A 70,47 €	A 42,28 €
LRM285/LH	28	5	60	56	1,102	✓	A 124,72 €	A 74,83 €
LRM306/LH	30	6	60	60	1,140	✓	A 120,79 €	A 72,47 €
LRM326/LH	32	6	60	64	1,177	✓	A 133,74 €	A 80,25 €
LRM366/LH	36	6	75	72	2,189	-	B 140,75 €	B 133,72 €
LRM407/LH	40	7	80	80	2,725	-	B 173,67 €	B 164,99 €
LRM447/LH	44	7	80	88	2,815	-	B 155,14 €	B 147,38 €
LRM508/LH	50	8	90	100	4,014	-	B 298,55 €	B 283,62 €
LRM609/LH	60	9	100	120	5,150	-	B 386,15 €	B 366,85 €

*Depending on availability - Dimensions in mm

** refer to discounts


1 start, right or left hand thread

BFM BFMLH

- Right or left-hand thread
- Toleranced flange
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

Use

- For manual or motorised operation
- For low and medium speeds
- For working under load
- Use with steel or stainless steel screws gives good results, especially if lubrication is ensured

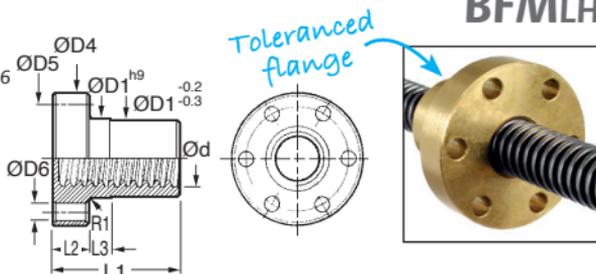

DISCOUNTS A

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

DISCOUNTS B

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Ød	ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Stock*	Price each			
										1 to 9	20 to 39**		
Right-hand thread													
BFM102	10 x 2	25	42	34	5	25	10	6	✓	A	33,35 €	A	20,01 €
BFM123	12 x 3	28	48	38	6	35	12	8	✓	A	50,68 €	A	30,41 €
BFM164	16 x 4	28	48	38	6	35	12	8	✓	A	50,43 €	A	30,26 €
BFM184	18 x 4	28	48	38	6	35	12	8	✓	A	50,18 €	A	30,11 €
BFM204	20 x 4	32	55	45	7	44	12	8	-	A	73,02 €	A	43,81 €
BFM225	22 x 5	32	55	45	7	44	12	8	✓	A	75,59 €	A	45,35 €
BFM245	24 x 5	32	55	45	7	44	12	8	✓	A	67,46 €	A	40,47 €
BFM285	28 x 5	38	62	50	7	46	14	8	✓	A	95,57 €	A	57,34 €
BFM306	30 x 6	38	62	50	7	46	14	8	✓	A	91,76 €	A	55,06 €
BFM326	32 x 6	45	70	58	7	54	16	10	✓	A	129,20 €	A	77,52 €
BFM366	36 x 6	45	70	58	7	54	16	10	✓	B	80,22 €	B	76,21 €
BFM407	40 x 7	63	95	78	9	66	16	12	✓	B	148,71 €	B	141,28 €
BFM447	44 x 7	63	95	78	9	66	16	12	-	B	173,50 €	B	164,82 €
BFM508	50 x 8	72	110	90	11	75	18	14	✓	B	252,46 €	B	239,84 €
BFM609	60 x 9	88	130	110	13	90	20	16	-	B	404,47 €	B	384,25 €
BFM7010	70 x 10	95	140	120	13	105	22	17	-	B	572,33 €	B	543,71 €
Left-hand thread													
BFM102/LH	10 x 2	25	42	34	5	25	10	6	✓	A	37,60 €	A	22,56 €
BFM123/LH	12 x 3	28	48	38	6	35	12	8	-	A	55,31 €	A	33,18 €
BFM164/LH	16 x 4	28	48	38	6	35	12	8	✓	A	55,12 €	A	33,07 €
BFM184/LH	18 x 4	28	48	38	6	35	12	8	✓	A	54,97 €	A	32,98 €
BFM204/LH	20 x 4	32	55	45	7	44	12	8	✓	A	76,17 €	A	45,70 €
BFM225/LH	22 x 5	32	55	45	7	44	12	8	-	A	87,87 €	A	52,72 €
BFM245/LH	24 x 5	32	55	45	7	44	12	8	✓	A	72,04 €	A	43,23 €
BFM285/LH	28 x 5	38	62	50	7	46	14	8	✓	A	107,54 €	A	64,53 €
BFM306/LH	30 x 6	38	62	50	7	46	14	8	✓	A	97,17 €	A	58,30 €
BFM326/LH	32 x 6	45	70	58	7	54	16	10	-	A	143,06 €	A	85,83 €
BFM366/LH	36 x 6	45	70	58	7	54	16	10	✓	B	88,11 €	B	83,71 €
BFM407/LH	40 x 7	63	95	78	9	66	16	12	-	B	151,37 €	B	143,80 €
BFM447/LH	44 x 7	63	95	78	9	66	16	12	-	B	180,11 €	B	171,11 €
BFM508/LH	50 x 8	72	110	90	11	75	18	14	-	B	270,31 €	B	256,79 €
BFM609/LH	60 x 9	88	130	110	13	90	20	16	-	B	435,05 €	B	413,30 €
BFM7010/LH	70 x 10	95	140	120	13	105	22	17	-	B	611,33 €	B	580,77 €

*Depending on availability - Dimensions in mm

** refer to discounts

Cylindrical polymer nut



WSRM 1 trapezoidal right-hand thread

- Material: **Iglidur®** W300
- Working temperature: up to 90°C

Advantages


- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

Accessories

- LFM steel leadscrew (tome 3 p.314)
- LSM stainless steel leadscrew (tome 3 p.316)



Maintenance free

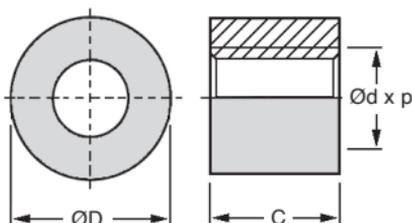

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	ØD	C	Stock*	Price each 1 to 5
WSRM102	10	2	22	15	-	37,34 €
WSRM123	12	3	26	18	-	45,56 €
WSRM164	16	4	30	24	-	60,60 €
WSRM184	18	4	30	27	-	65,05 €
WSRM204	20	4	30	25	-	67,14 €
WSRM245	24	5	50	36	-	91,35 €
WSRM285	28	5	60	42	-	112,55 €
WSRM306	30	6	60	45	-	145,70 €

*Depending on availability - Dimensions in mm



Flanged polymer nut

1 trapezoidal right-hand thread

WFRM



- Material: Iglidur® W300

Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

Accessories

- LFM steel leadscrew (tome 3 p.314)
- LSM stainless steel leadscrew (tome 3 p.316)

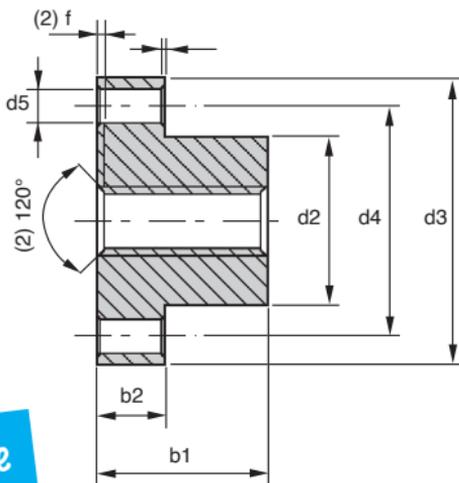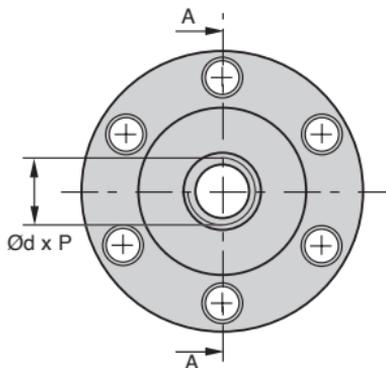

Maintenance free

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch		d2	d3	d4	d5	b1	b2	Stock*	Price each 1 to 5
		P									
WFRM102	10	2		25	42	34	5	25	10	✓	47,43 €
WFRM123	12	3		28	48	38	6	35	12	-	53,16 €
WFRM164	16	4		28	48	38	6	35	12	✓	66,61 €
WFRM184	18	4		28	48	38	6	35	12	✓	77,33 €
WFRM204	20	4		32	55	45	7	44	12	✓	81,65 €
WFRM245	24	5		32	55	45	7	44	12	✓	107,63 €
WFRM306	30	6		38	62	50	7	46	14	✓	140,85 €

*Depending on availability - Dimensions in mm

Leadscrew locking ring



BAGTR

For **single thread leadscrew**

- Single piece leadscrew locking assembly

- Material:

Anodised aluminium

Info.

- Screw head can be larger than diameter $\varnothing D$

- Overall dimension is $\varnothing D + 2 \text{ mm}$


Accessory

- LFM leadscrew (vol. 1 p.314)

Trapezoidal profile



Typical application:
fitted to a LFM leadscrew

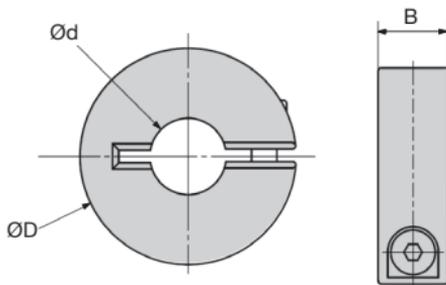

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-10%	-18%	On request

Part number	$\varnothing d$	$\varnothing D$	B	Static axial load (N)	Stock*	Price each 1 to 9
Right hand thread						
BAG1-TR10	TR10X2	24	8	1800	✓	23,87 €
BAG1-TR12	TR12X3	28	8	2096	✓	31,64 €
BAG1-TR16	TR16X4	34	11	3840	✓	45,80 €
BAG1-TR18	TR18X4	36	13	5216	✓	25,06 €
BAG1-TR20	TR20X4	45	15	6784	✓	26,17 €
BAG1-TR24	TR24X5	45	15	8096	✓	44,01 €
Left hand thread						
BAG1-TR10/LH	TR10X2	24	8	1800	-	19,80 €
BAG1-TR12/LH	TR12X3	28	8	2096	-	36,38 €
BAG1-TR16/LH	TR16X4	34	11	3840	-	45,78 €
BAG1-TR18/LH	TR18X4	36	13	5216	-	28,85 €
BAG1-TR20/LH	TR20X4	45	15	6784	-	30,06 €
BAG1-TR24/LH	TR24X5	45	15	8096	-	50,61 €

*Depending on availability - Dimensions in mm

- Cold rolled (plastic deformation)
- Conforms to DIN 103 (NFE 03-615)
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e

Uses

- Machine tools
- Lathe main screw

Options



- Available in lengths up to 6000mm (subject to diameter)

Accessories

- LRM (tome 3 p.314) and BFM (tome 3 p.315) dual thread bronze nuts



2 Starts

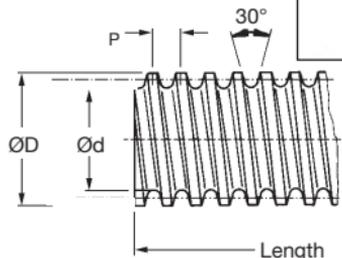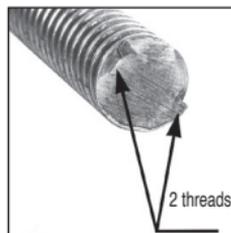

DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Long	1000	2000	3000	6000 mm
Price	Each	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d min.	Price per metre	
				1 to 9	20 to 39**
LFM126	12	6	07,68	14,83 €	8,90 €
LFM146	14	6	09,68	18,99 €	11,39 €
LFM168	16	8	10,47	24,82 €	14,89 €
LFM188	18	8	12,47	34,93 €	20,96 €
LFM208	20	8	14,47	38,00 €	22,80 €
LFM2210	22	10	15,29	44,43 €	26,66 €
LFM2410	24	10	17,27	50,16 €	30,09 €
LFM2610	26	10	19,27	73,52 €	44,11 €
LFM2810	28	10	21,27	82,77 €	49,66 €
LFM3012	30	12	21,56	69,70 €	41,82 €
LFM3212	32	12	23,56	114,00 €	68,40 €
LFM3612	36	12	27,56	113,24 €	67,94 €
LFM4014	40	14	30,38	140,49 €	84,29 €

Dimensions in mm

** refer to discounts


- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze UE

Use

- For manual or motorised operation
- For low and medium speeds
- For working under load
- Use with steel or stainless steel screws gives good results, especially if lubrication is ensured

Accessories

- LFM 2 start steel leadscrew (tome 3 p.313)

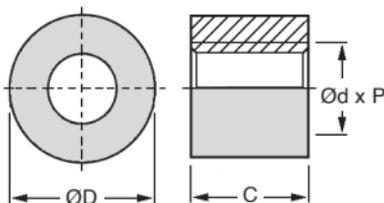

DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch P	ØD	C	Weight (kg)	Price each	
						1 to 9	20 to 39**
LRM126	12	6	26	24	0,083	20,85 €	12,51 €
LRM168	16	8	36	32	0,232	35,50 €	21,30 €
LRM188	18	8	40	36	0,320	47,41 €	28,45 €
LRM208	20	8	45	40	0,455	55,07 €	33,04 €
LRM2210	22	10	45	44	0,480	68,16 €	40,90 €
LRM2410	24	10	50	48	0,656	78,12 €	46,87 €
LRM2810	28	10	60	56	1,102	123,50 €	74,10 €
LRM3012	30	12	60	60	1,140	119,59 €	71,76 €
LRM3212	32	12	60	64	1,177	132,41 €	79,45 €
LRM3612	36	12	75	72	2,189	212,59 €	127,56 €
LRM4014	40	14	80	80	2,725	262,32 €	157,39 €

Dimensions in mm



Flanged bronze nut

2 starts, right hand thread

BFM


- Toleranced flange
- Thread conforms to NFE 03.616
- Machined nut
- Thread tolerance: 7H
- Material: Bronze CuSn8P

Use

- For manual or motorised operation
- For low and medium speeds
- For working under load
- Use with steel or stainless steel screws gives good results, especially if lubrication is ensured

Accessory

- LFM stainless steel leadscrew (tome 3 p.313)

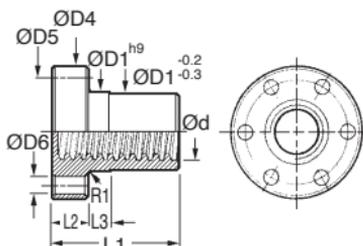

DISCOUNTS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request

Part number	Ød	Pitch			ØD1	ØD4	ØD5	ØD6	L1	L2	L3	Price each	
		P	ØD1	ØD4								1 to 9	20 to 39*
BFM126	12	6	28	48	38	6	35	12	8	47,22 €	28,33 €		
BFM168	16	8	28	48	38	6	35	12	8	47,37 €	28,42 €		
BFM188	18	8	28	48	38	6	35	12	8	47,37 €	28,42 €		
BFM208	20	8	32	55	45	7	44	12	8	64,79 €	38,87 €		
BFM2210	22	10	32	55	45	7	44	12	8	76,53 €	45,92 €		
BFM2410	24	10	32	55	45	7	44	12	8	63,14 €	37,88 €		
BFM2810	28	10	38	62	50	7	46	14	8	93,95 €	56,37 €		
BFM3012	30	12	38	62	50	7	46	14	8	84,42 €	50,65 €		
BFM3212	32	12	45	70	58	7	54	16	10	134,40 €	80,64 €		
BFM3612	36	12	45	70	58	7	54	16	10	134,15 €	80,49 €		
BFM4014	40	14	63	95	78	9	66	16	12	212,02 €	127,21 €		

Dimensions in mm

** refer to discounts