

# Cylindrical polymer nut



## WSRM 1 trapezoidal right-hand thread

- Material: **iglidur® W300**
- Working temperature: up to 90°C


### Accessories

- LFM steel lead screw or LSM stainless steel screw

### Advantages

- Dry working
- Not affected by dirt
- No maintenance required
- No corrosion
- Silent in operation

No maintenance

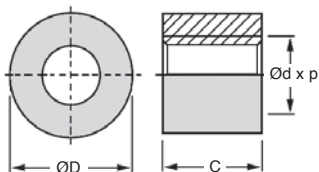

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Ød	Pitch P	ØD	C	Stock*	Price each 1 to 5
WSRM102	10	2	22	15	✓	27,72 €
WSRM123	12	3	26	18	✓	33,81 €
WSRM164	16	4	30	24	✓	44,95 €
WSRM184	18	4	30	27	✓	48,24 €
WSRM204	20	4	30	25	✓	49,82 €
WSRM245	24	5	50	36	-	67,74 €
WSRM285	28	5	60	42	-	76,54 €
WSRM306	30	6	60	45	-	79,58 €

\*Depending on availability - Dimensions in mm

## Our other products



ACL-FPA

Panel mounting block for aluminium structures, Support block



COA-COG

Surface mounting plate, Surface mounting plate for ball joint



UFX

Uneflex® elastic coupling, range



T5\_11

T type timing pulley, T5 aluminium



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



BLHM70

Right angled gearbox, up to 128 Nm



BLHT70

Right angled gearbox, from 26 to 128 Nm



SSB

Stainless steel bevel gear, 1:1



BABtss

303 Stainless steel ball pin, 303 Stainless steel



TB8

Cylindrical roller thrust bearing, Steel



RAGFLOWsupport

Floway2® Roller track accessory, Roller track support



BTSS


Universal stainless steel arm for tensioner, For use in hostile envi...

## Complementary products



LFM

Steel leadscrew, Medium carbon steel - 1 thread

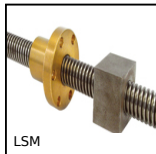

LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread