

Tightening washer

WTM

Hardened steel



- **Heavy duty clamping washer**
- Conforms to DIN 6340
- Materials :
Steel AlZnMgCu0.5F47
resistance hardened 1200-1400/mm²

Info.

- **Not sold individually, please contact us for details**



Tight
locking

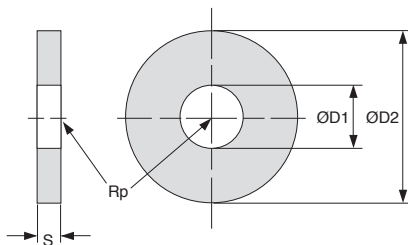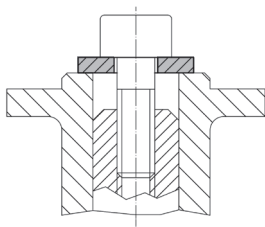

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	S	For screw	Weight (g)	Stock*	Price each 1 to 19
WTM-6	6,4	17	3	M6	3,8	✓	0,79 €
WTM-8	8,4	23	4	M8	9,8	✓	0,79 €
WTM-10	10,5	28	4	M10	14	✓	0,98 €
WTM-12	13,0	35	5	M12	28	✓	1,29 €
WTM-16	17,0	45	6	M16	55	✓	1,84 €
WTM-20	21,0	50	6	M20	71	✓	2,91 €
WTM-24	25,0	60	6	M24	122	-	4,55 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze




HLUs5

Spoked handwheel, Stainless steel 316



Q6

 Deep groove ball bearing, Steel



M1

Worm and wheel set, Bronze




DER90

Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to 1.5kW



UCP_PBT

 Stainless/polymer pillow block bearing, Polymer and stainless steel



H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SC2

2 part rigid shaft clamp, Clamping jaw



TCLar

Automatic chain tensioner, With wide guide




VELM6

Screw-on base for hook-and-loop strip, Polyamide



GBMz

 Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



RPP

Connecting plate for RPP type timing belts, RPPB

Complementary products



RCC_RCX

Spherical tilt washer - DIN6319, convex



RCC_RCX

Spherical tilt washer - DIN6319, concave