

Tightening washer

WTM

Hardened steel



- **Heavy duty clamping washer**
- Conforms to DIN 6340
- Materials :
Steel AlZnMgCu0.5F47
resistance hardened 1200-1400/mm²

Info.

- **Not sold individually, please contact us for details**



Tight
locking

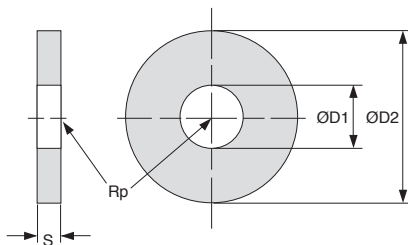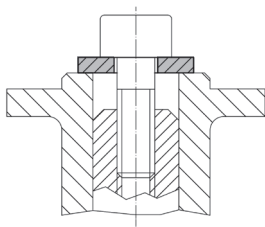

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	S	For screw	Weight (g)	Stock*	Price each 1 to 19
WTM-6	6,4	17	3	M6	3,8	✓	0,79 €
WTM-8	8,4	23	4	M8	9,8	✓	0,79 €
WTM-10	10,5	28	4	M10	14	✓	0,98 €
WTM-12	13,0	35	5	M12	28	✓	1,29 €
WTM-16	17,0	45	6	M16	55	✓	1,84 €
WTM-20	21,0	50	6	M20	71	✓	2,91 €
WTM-24	25,0	60	6	M24	122	-	4,55 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Micromet...



KB_OP

Open precision linear bearing, Precision - steel



PSG155

Spur gear - precision range, Stainless steel 303



ES

Simple support base (bipod), Plastic




KITbuh

24V DC motorisation kit, Planetary gears



SH2

Parallel axis helical gear, Machined plastic (delrin)

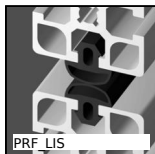

PRF LIS

Door seal for aluminium profile, Black NBR



SH1

Parallel axis helical gear, Steel 20NCD2



SLS

Bearing block for leadscrew, Floating



SF_ZZ

Deep groove ball bearing, Stainless



SSB

Stainless steel bevel gear, 1:1



SH0

Parallel axis helical gear, Steel 20NCD2

Complementary products



RCC_RCX

Spherical tilt washer - DIN6319, convex



RCC_RCX

Spherical tilt washer - DIN6319, concave