

Tightening washer

WTM

Hardened steel



- **Heavy duty clamping washer**
- Conforms to DIN 6340
- Materials :
Steel AlZnMgCu0.5F47
resistance hardened 1200-1400/mm²

Info.

- **Not sold individually, please contact us for details**



Tight
locking

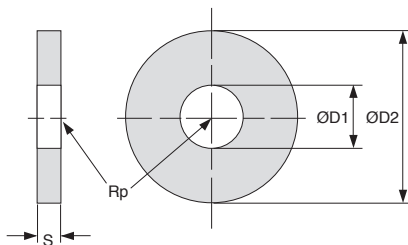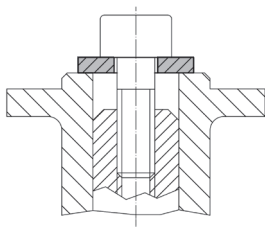

DISCOUNTS

Qty	1+	20+	50+
Disc.	List	-10%	On request

Part number	ØD1	ØD2	S	For screw	Weight (g)	Stock*	Price each 1 to 19
WTM-6	6,4	17	3	M6	3,8	✓	0,79 €
WTM-8	8,4	23	4	M8	9,8	✓	0,79 €
WTM-10	10,5	28	4	M10	14	✓	0,98 €
WTM-12	13,0	35	5	M12	28	✓	1,29 €
WTM-16	17,0	45	6	M16	55	✓	1,84 €
WTM-20	21,0	50	6	M20	71	✓	2,91 €
WTM-24	25,0	60	6	M24	122	-	4,55 €

*Subject to availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



UGAC_UGET

Connection for threaded actuator rod, Connection for threaded actuat...



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Steel



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



FP30

Worm and wheel gear reducer, up to 8.80 Nm



CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



PSG3

Spur gear - precision range, Pre-hardened Steel 35NCD6



FB_ECO

Eco. range steel bevel gear, 4:1



MEFC

Flanged sintered ferrous bush, Self-lubricating FP20



AZY

Cylindrical elasto mount, Steel



PSG08

Spur gear - precision range, Pre-hardened Steel 35NCD6



ZG0

Plastic spur gear, Machined plastic (delrin)

Complementary products



RCC_RCX

Spherical tilt washer - DIN6319, convex



RCC_RCX

Spherical tilt washer - DIN6319, concave