


Tightening washer

New


WTM

Hardened steel

- **Heavy duty clamping washer**
- Conforms to DIN 6340
- Materials :
Steel AlZnMgCu0.5F47
resistance hardened 1200-1400/mm²

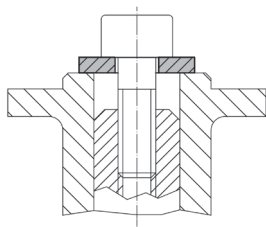

Tight locking

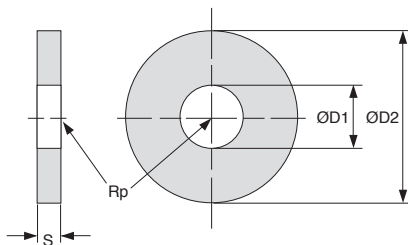

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØD1	ØD2	S	For screw	Weight (g)	Stock*	Price each 1 to 5
WTM-6	6,4	17	3	M6	3,8	✓	0,77 €
WTM-8	8,4	23	4	M8	9,8	✓	0,77 €
WTM-10	10,5	28	4	M10	14	✓	0,95 €
WTM-12	13,0	35	5	M12	28	✓	1,25 €
WTM-16	17,0	45	6	M16	55	✓	1,78 €
WTM-20	21,0	50	6	M20	71	-	2,80 €
WTM-24	25,0	60	6	M24	122	-	4,38 €

*Subject to availability - Dimensions in mm

Our other products



PNA
PERIFLEX elastic coupling, Complete coupling




PSG15S
Spur gear - precision range, Stainless steel 303



LRX
Linear roller slide, Rail - from 9410 N to 101000 N



 ACL-PR
Connecting/joining, Right angled connection



AT10courroie
Closed belt, AT10 Steel cored polyurethane



GAC
Latch clamp with lock, Strike plate



GLB
Small 6 lobe threaded handle, Technopolymer - Brass



PCS75K
Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)



METC
Bushing, Self-lubricating sintered bronze



PTA50
Levelling foot with pressed base, Ø 50



WING
Manually tightened wing nut, Steel (ANSI B18-17)



PSG2
Spur gear - precision range, Case hardened steel 20NCD2

Complementary products



RCC_RCX
Spherical tilt washer - DIN 6319, convex



RCC_RCX
Spherical tilt washer - DIN 6319, concave