




Ratio 1:1

Delrin

- **Module 3 to 6**
- Machined parts
- Pressure angle 20°
- Teeth Gleason
- Material:
Delrin plastic
- Working temp -50° to +80°C
- Two identical gears must be ordered to make a pair

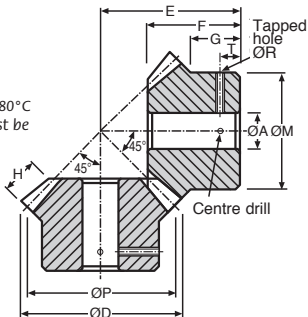

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm			
	3.0 MOD	4.0 MOD	5.0 MOD	6.0 MOD
Torque (Nm)	1.93	2.84	5	8
Power (kW)	0.20	0.83	0.54	0.85

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Teeth											Price each		
Part number	Z	Module	ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	1 to 5
ZB3-16	16	3	48	44,0	52,24	15	40,0	29,08	16,00	11	M5	8	On request
ZB3-19	19		57	49,0	61,24	16	50,0	31,01	17,02	13	M5	9	
ZB3-26	26		78	65,0	82,24	18	64,0	40,03	19,03	18	M6	10	
ZB3-30	30	90	68,5	94,24	20	76,0	39,65	16,51	21	M6	8		
ZB4-16	16	4	64	55,5	69,66	15	50,0	35,81	16,49	15	M5	8	
ZB4-19	19		76	65,0	81,66	18	62,5	41,43	20,24	18	M6	10	
ZB4-26	26		104	82,0	109,66	22	85,0	48,69	20,50	24	M6	10	
ZB4-30	30	120	90,0	125,66	25	102,0	51,51	21,00	28	M8	11		
ZB5-16	16	5	80	70,0	87,10	18	60,0	46,13	20,00	20	M8	11	
ZB5-20	20		100	80,0	107,10	20	80,0	49,04	21,50	24	M8	12	
ZB5-25	25		125	100,0	132,10	25	80,0	59,47	24,00	28	M10	14	
ZB5-30	30	150	114,0	157,10	30	100,0	65,87	26,00	35	M10	15		
ZB6-16	16	6	96	80,0	104,52	25	75,0	50,10	22,00	22	M10	12	
ZB6-20	20		120	90,0	128,52	30	96,0	52,32	18,50	28	M10	12	
ZB6-25	25		150	115,0	158,52	35	100,0	67,29	24,00	35	M10	14	
ZB6-30	30	180	130,0	188,52	35	120,0	72,24	28,00	42	M10	16		

Dimensions in mm

Our other products



AT5M AT10M
AT type timing belt per metre, AT5 Steel cored polyurethane



SSDB
Stainless steel bevel gear, 2:1



VTLF
3 lobed handle, Polyamide - Brass



CHA38_SS
Stainless steel face frame hinge, Surface mount



PTAF80-PAMF80
Articulated fixable foot with pressed base Ø80, Ø 80



BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + stainless...



PRF4532
Standard aluminium profile, 45 x 32 mm



FBL4004_K7
Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 -...



PLM-C
Cylindrical holding magnets, Cylindrical holding magnet



MSP3815
Masterplate® glueable insert rectangular, rectangular with nut



LVT
Miniature motorised actuator 2A, 2 amperes



UCP_PBT
Stainless/Polymer pillow block bearing, Polymer and stainless steel

Complementary products



MEB
Moulded plastic bevel gear (nylon), 1:1



SSB
Stainless steel bevel gear, 1:1