




Ratio

Delrin

1:1

- **Module 3 to 6**
- Machined parts
- Pressure angle 20°
- Teeth Gleason
- Material:
Delrin plastic
- Working temp -50° to +80°C
- Two identical gears must be ordered to make a pair

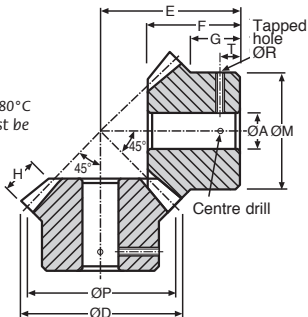

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm			
	3.0 MOD	4.0 MOD	5.0 MOD	6.0 MOD
Torque (Nm)	1.93	2.84	5	8
Power (kW)	0.20	0.83	0.54	0.85

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Teeth											Price each			
Part number	Z	Module	ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	1 to 5	
ZB3-16	16	3	48	44,0	52,24	15	40,0	29,08	16,00	11	M5	8	On request	
ZB3-19	19		57	49,0	61,24	16	50,0	31,01	17,02	13	M5	9		
ZB3-26	26		78	65,0	82,24	18	64,0	40,03	19,03	18	M6	10		
ZB3-30	30	90	68,5	94,24	20	76,0	39,65	16,51	21	M6	8			
ZB4-16	16	4	64	55,5	69,66	15	50,0	35,81	16,49	15	M5	8		
ZB4-19	19		76	65,0	81,66	18	62,5	41,43	20,24	18	M6	10		
ZB4-26	26		104	82,0	109,66	22	85,0	48,69	20,50	24	M6	10		
ZB4-30	30	120	90,0	125,66	25	102,0	51,51	21,00	28	M8	11			
ZB5-16	16	5	80	70,0	87,10	18	60,0	46,13	20,00	20	M8	11		
ZB5-20	20		100	80,0	107,10	20	80,0	49,04	21,50	24	M8	12		
ZB5-25	25		125	100,0	132,10	25	80,0	59,47	24,00	28	M10	14		
ZB5-30	30	150	114,0	157,10	30	100,0	65,87	26,00	35	M10	15			
ZB6-16	16	6	96	80,0	104,52	25	75,0	50,10	22,00	22	M10	12		
ZB6-20	20		120	90,0	128,52	30	96,0	52,32	18,50	28	M10	12		
ZB6-25	25		150	115,0	158,52	35	100,0	67,29	24,00	35	M10	14		
ZB6-30	30		180	130,0	188,52	35	120,0	72,24	28,00	42	M10	16		

Dimensions in mm

Our other products



BPFss
Pressed stainless steel flange bearing, Stainless steel



M0
Worm, Hardened steel



VDSCB
Sliding lock adjustment system, Blocking wedge for sliding lock for ...



CHTRP
Single and dual output gearboxes, Up to 28,8 Nm



M1
Worm, Hardened steel



PGT
Sliding profile, Sliding panel support



VB
Small 6-lobe threaded handle - female, Duroplast - Stainless steel



PPS
Lifting ring, Universal threaded




CHARcav
Spring hinge, to install



HG6
Steel spur gear, Steel 20NCD2



LWH
High rigidity linear slide, Rail - from 9320

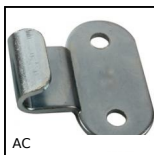

AC
Strike for toggle latch, 20mm

Complementary products



MEB
Moulded plastic bevel gear (nylon), 1:1



SSB
Stainless steel bevel gear, 1:1