




Ratio 1:1

Delrin

- **Module 3 to 6**
- Machined parts
- Pressure angle 20°
- Teeth Gleason
- Material:
Delrin plastic
- Working temp -50° to +80°C
- Two identical gears must be ordered to make a pair

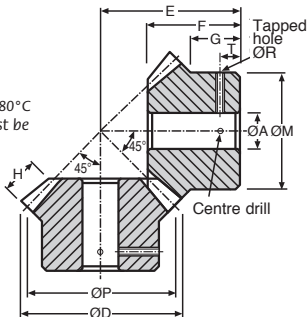

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm			
	3.0 MOD	4.0 MOD	5.0 MOD	6.0 MOD
Torque (Nm)	1.93	2.84	5	8
Power (kW)	0.20	0.83	0.54	0.85


DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Teeth											Price each		
Part number	Z	Module	ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	1 to 5
ZB3-16	16	3	48	44,0	52,24	15	40,0	29,08	16,00	11	M5	8	On request
ZB3-19	19		57	49,0	61,24	16	50,0	31,01	17,02	13	M5	9	
ZB3-26	26		78	65,0	82,24	18	64,0	40,03	19,03	18	M6	10	
ZB3-30	30	90	68,5	94,24	20	76,0	39,65	16,51	21	M6	8		
ZB4-16	16	4	64	55,5	69,66	15	50,0	35,81	16,49	15	M5	8	
ZB4-19	19		76	65,0	81,66	18	62,5	41,43	20,24	18	M6	10	
ZB4-26	26		104	82,0	109,66	22	85,0	48,69	20,50	24	M6	10	
ZB4-30	30	120	90,0	125,66	25	102,0	51,51	21,00	28	M8	11		
ZB5-16	16	5	80	70,0	87,10	18	60,0	46,13	20,00	20	M8	11	
ZB5-20	20		100	80,0	107,10	20	80,0	49,04	21,50	24	M8	12	
ZB5-25	25		125	100,0	132,10	25	80,0	59,47	24,00	28	M10	14	
ZB5-30	30	150	114,0	157,10	30	100,0	65,87	26,00	35	M10	15		
ZB6-16	16	6	96	80,0	104,52	25	75,0	50,10	22,00	22	M10	12	
ZB6-20	20		120	90,0	128,52	30	96,0	52,32	18,50	28	M10	12	
ZB6-25	25		150	115,0	158,52	35	100,0	67,29	24,00	35	M10	14	
ZB6-30	30		180	130,0	188,52	35	120,0	72,24	28,00	42	M10	16	

Dimensions in mm

 Our other products



M1

Worm, Machined plastic (delrin)



ACLERP

Roller block for aluminium profile, Without guide rail



BOX-TOR-INCH

Box set of Nitrile O-rings in inch NBR90Sh A, For fasteners and fitt...



AKD

Bellows coupling Gerwah®, from 22 to 600Nm



RJA00_02

Sealing strip, Clipping



BPPss

Pressed stainless steel pillow block, Stainless steel



PTA80

Articulated levelling foot, pressed base Ø80, 10000N



ZHBRA

Plastic bevel gear, 1,25:1 2:1 3:1



F7-E

Multifunction display, With external sensor



UFX

Spare tyre UNEFLEX® coupling, range



AT10courroie

AT type timing belt, AT10 Steel cored



BDP1R

 
Adjustable support arm, Single clamp

Complementary products



SSB

Stainless steel bevel gear, 1:1



B

Steel bevel gear, 1:1