

# Plastic spur gear




## MODULE 0.4

## Machined Delrin



- Machined parts
- Quality standard 9
- Pressure angle 20°
- Working temp.: -50°C to +80°C

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	<b>0.04</b>

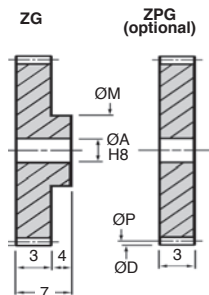

### DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						ZG	ZPG	ZG	ZPG
ZG0.4-10	10	4,40	5,20	5,20	1,50	0,0002	0,0001	7,22 €	On request
ZG0.4-11	11	4,80	5,60	5,60	1,50	0,0002	0,0001	7,23 €	
ZG0.4-12	12	4,80	5,60	5,60	1,50	0,0002	0,0001	7,24 €	
ZG0.4-13	13	5,20	6,00	6,00	1,50	0,0002	0,0001	7,26 €	
ZG0.4-14	14	5,60	6,40	6,40	2,00	0,0002	0,0001	7,28 €	
ZG0.4-15	15	6,00	6,80	6,80	2,00	0,0002	0,0001	7,31 €	
ZG0.4-16	16	6,40	7,20	7,00	2,00	0,0002	0,0001	7,33 €	
ZG0.4-17	17	6,80	7,60	7,00	2,00	0,0002	0,0001	7,36 €	
ZG0.4-18	18	7,20	8,00	7,00	2,00	0,0003	0,0001	8,22 €	
ZG0.4-19	19	7,60	8,40	7,00	2,00	0,0003	0,0002	8,22 €	
ZG0.4-20	20	8,00	8,80	7,00	2,00	0,0004	0,0002	8,22 €	
ZG0.4-21	21	8,40	9,20	7,00	2,00	0,0004	0,0002	8,22 €	
ZG0.4-22	22	8,80	9,60	7,00	2,00	0,0004	0,0002	8,14 €	
ZG0.4-23	23	9,20	10,00	9,00	2,00	0,0006	0,0002	8,14 €	
ZG0.4-24	24	9,60	10,40	9,00	2,00	0,0006	0,0003	8,14 €	
ZG0.4-25	25	10,00	10,80	9,00	2,00	0,0006	0,0003	8,22 €	
ZG0.4-26	26	10,40	11,20	9,00	2,00	0,0006	0,0003	8,22 €	
ZG0.4-27	27	10,80	11,60	9,00	2,00	0,0007	0,0003	8,32 €	
ZG0.4-28	28	11,20	12,00	11,00	3,00	0,0008	0,0004	8,32 €	
ZG0.4-29	29	11,60	12,40	11,00	3,00	0,0008	0,0004	8,32 €	
ZG0.4-30	30	12,00	12,80	11,00	3,00	0,0009	0,0004	8,32 €	
ZG0.4-31	31	12,40	13,20	11,00	3,00	0,0009	0,0004	8,36 €	
ZG0.4-32	32	12,80	13,60	11,00	3,00	0,0009	0,0005	8,36 €	

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg) ZG ZPG		Price each 1 to 5 ZG ZPG
ZG0.4-33	33	13,20	14,00	11	3,00	0,0010	0,0005	8,36 €
ZG0.4-34	34	13,60	14,40	11	3,00	0,0010	0,0005	8,48 €
ZG0.4-35	35	14,00	14,80	11	3,00	0,0010	0,0006	8,48 €
ZG0.4-36	36	14,40	15,20	11	3,00	0,0011	0,0006	8,48 €
ZG0.4-37	37	14,80	15,60	11	3,00	0,0011	0,0006	8,58 €
ZG0.4-38	38	15,20	16,00	11	3,00	0,0011	0,0007	8,71 €
ZG0.4-39	39	15,60	16,40	11	3,00	0,0012	0,0007	8,71 €
ZG0.4-40	40	16,00	16,80	11	3,00	0,0012	0,0007	8,77 €
ZG0.4-41	41	16,40	17,20	11	3,00	0,0012	0,0008	8,77 €
ZG0.4-42	42	16,80	17,60	11	3,00	0,0013	0,0008	8,83 €
ZG0.4-43	43	17,20	18,00	11	3,00	0,0013	0,0009	8,93 €
ZG0.4-44	44	17,60	18,40	11	3,00	0,0014	0,0009	8,97 €
ZG0.4-45	45	18,00	18,80	11	3,00	0,0014	0,0010	8,97 €
ZG0.4-46	46	18,40	19,20	11	3,00	0,0015	0,0010	9,13 €
ZG0.4-47	47	18,80	19,60	11	3,00	0,0015	0,0010	9,20 €
ZG0.4-48	48	19,20	20,00	11	3,00	0,0015	0,0011	9,20 €
ZG0.4-49	49	19,60	20,40	14	4,00	0,0018	0,0011	9,27 €
ZG0.4-50	50	20,00	20,80	14	4,00	0,0019	0,0012	9,30 €
ZG0.4-51	51	20,40	21,20	14	4,00	0,0019	0,0012	9,38 €
ZG0.4-52	52	20,80	21,60	14	4,00	0,0020	0,0013	9,38 €
ZG0.4-53	53	21,20	22,00	14	4,00	0,0020	0,0013	9,53 €
ZG0.4-54	54	21,60	22,40	14	4,00	0,0021	0,0014	9,56 €
ZG0.4-55	55	22,00	22,80	14	4,00	0,0021	0,0014	9,56 €
ZG0.4-56	56	22,40	23,20	14	4,00	0,0022	0,0015	9,70 €
ZG0.4-57	57	22,80	23,60	14	4,00	0,0023	0,0015	9,80 €
ZG0.4-58	58	23,20	24,00	14	4,00	0,0023	0,0016	9,88 €
ZG0.4-59	59	23,60	24,40	14	4,00	0,0024	0,0016	9,95 €
ZG0.4-60	60	24,00	24,80	14	4,00	0,0024	0,0017	10,01 €
ZG0.4-61	61	24,40	25,20	14	4,00	0,0025	0,0018	10,13 €
ZG0.4-62	62	24,80	25,60	14	4,00	0,0025	0,0018	10,18 €
ZG0.4-63	63	25,20	26,00	14	4,00	0,0026	0,0019	10,33 €
ZG0.4-64	64	25,60	26,40	14	4,00	0,0027	0,0019	10,37 €
ZG0.4-65	65	26,00	26,80	14	4,00	0,0027	0,0020	10,53 €
ZG0.4-68	68	27,20	28,00	14	4,00	0,0029	0,0022	10,61 €
ZG0.4-70	70	28,00	28,80	14	4,00	0,0031	0,0023	10,72 €
ZG0.4-72	72	28,80	29,60	14	4,00	0,0032	0,0025	10,72 €
ZG0.4-75	75	30,00	30,80	14	4,00	0,0034	0,0027	11,86 €
ZG0.4-77	77	30,80	31,60	14	4,00	0,0036	0,0028	11,98 €
ZG0.4-80	80	32,00	32,80	14	4,00	0,0038	0,0031	11,98 €
ZG0.4-84	84	33,60	34,40	14	4,00	0,0041	0,0034	12,19 €
ZG0.4-86	86	34,40	35,20	14	4,00	0,0043	0,0035	12,30 €
ZG0.4-88	88	35,20	36,00	14	4,00	0,0044	0,0037	12,44 €
ZG0.4-90	90	36,00	36,80	14	4,00	0,0046	0,0039	12,63 €
ZG0.4-96	96	38,40	39,20	14	4,00	0,0051	0,0044	12,92 €
ZG0.4-100	100	40,00	40,80	14	4,00	0,0055	0,0048	14,95 €
ZG0.4-120	120	48,00	48,80	14	4,00	0,0077	0,0069	15,19 €
ZG0.4-140	140	56,00	56,80	14	4,00	0,0102	0,0095	16,90 €
ZG0.4-150	150	60,00	60,80	20	6,00	0,0116	0,0109	18,89 €
ZG0.4-180	180	72,00	72,80	20	6,00	0,0164	0,0157	20,89 €

On request

↓ **Gears available up to this size** ↓

<b>ZG0.4-348</b>	<b>348</b>	<b>139,20</b>	<b>140,00</b>	<b>Dimensions: contact us</b>	<b>On request</b>
------------------	------------	---------------	---------------	-------------------------------	-------------------

*Dimensions in mm*

## Our other products



HTD8M\_30

HTD Heavy duty timing pulley, HTD8 Cast



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - stainless steel



RFV40

Stainless steel worm and wheel gearbox, up to 47 Nm



HSE-HSB

Hexagonal spacer, Brass



BOXdhx

Boxed set of threaded dowel pins DIN7979D, Boxed set - extractable D...



NSU

Universal 90° support clamp, Universal 90° support clamp



S20

Short housing for open linear bearing, Opened - slim



UGH40

H Type Guide units, For Ø40 actuators



LSM

Stainless steel 316L leadscrew, Stainless steel - 1 thread



BOX-TOR-DRING

Box set of Nitrile D-rings NBR90Sh A, Flange seals



NT121

Spur gear coaxial gearbox, from 20 to 68 Nm - Inline



PPJ

Indexing plunger with flange, With horizontal mounting flange and pu...

## Complementary products



G0

Steel spur gear, Steel 20NCD2



ZG0

Plastic spur gear, Machined plastic (delrin)