

# Plastic spur gear




## MODULE 0.4

## Machined Delrin



- Machined parts
- Quality standard 9
- Pressure angle 20°
- Working temp.: -50°C to +80°C

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	<b>0.04</b>

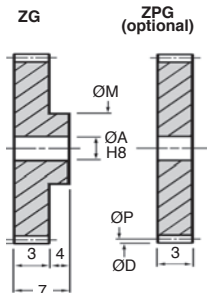

### DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)	Price each	
							ZG	ZPG
ZG0.4-10	10	4,40	5,20	5,20	1,50	0,0002	0,0001	7,22 €
ZG0.4-11	11	4,80	5,60	5,60	1,50	0,0002	0,0001	7,23 €
ZG0.4-12	12	4,80	5,60	5,60	1,50	0,0002	0,0001	7,24 €
ZG0.4-13	13	5,20	6,00	6,00	1,50	0,0002	0,0001	7,26 €
ZG0.4-14	14	5,60	6,40	6,40	2,00	0,0002	0,0001	7,28 €
ZG0.4-15	15	6,00	6,80	6,80	2,00	0,0002	0,0001	7,31 €
ZG0.4-16	16	6,40	7,20	7,00	2,00	0,0002	0,0001	7,33 €
ZG0.4-17	17	6,80	7,60	7,00	2,00	0,0002	0,0001	7,36 €
ZG0.4-18	18	7,20	8,00	7,00	2,00	0,0003	0,0001	8,22 €
ZG0.4-19	19	7,60	8,40	7,00	2,00	0,0003	0,0002	8,22 €
ZG0.4-20	20	8,00	8,80	7,00	2,00	0,0004	0,0002	8,22 €
ZG0.4-21	21	8,40	9,20	7,00	2,00	0,0004	0,0002	8,22 €
ZG0.4-22	22	8,80	9,60	7,00	2,00	0,0004	0,0002	8,14 €
ZG0.4-23	23	9,20	10,00	9,00	2,00	0,0006	0,0002	8,14 €
ZG0.4-24	24	9,60	10,40	9,00	2,00	0,0006	0,0003	8,14 €
ZG0.4-25	25	10,00	10,80	9,00	2,00	0,0006	0,0003	8,22 €
ZG0.4-26	26	10,40	11,20	9,00	2,00	0,0006	0,0003	8,22 €
ZG0.4-27	27	10,80	11,60	9,00	2,00	0,0007	0,0003	8,32 €
ZG0.4-28	28	11,20	12,00	11,00	3,00	0,0008	0,0004	8,32 €
ZG0.4-29	29	11,60	12,40	11,00	3,00	0,0008	0,0004	8,32 €
ZG0.4-30	30	12,00	12,80	11,00	3,00	0,0009	0,0004	8,32 €
ZG0.4-31	31	12,40	13,20	11,00	3,00	0,0009	0,0004	8,36 €
ZG0.4-32	32	12,80	13,60	11,00	3,00	0,0009	0,0005	8,36 €

On request

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg) ZG ZPG		Price each 1 to 5 ZG ZPG
ZG0.4-33	33	13,20	14,00	11	3,00	0,0010	0,0005	8,36 €
ZG0.4-34	34	13,60	14,40	11	3,00	0,0010	0,0005	8,48 €
ZG0.4-35	35	14,00	14,80	11	3,00	0,0010	0,0006	8,48 €
ZG0.4-36	36	14,40	15,20	11	3,00	0,0011	0,0006	8,48 €
ZG0.4-37	37	14,80	15,60	11	3,00	0,0011	0,0006	8,58 €
ZG0.4-38	38	15,20	16,00	11	3,00	0,0011	0,0007	8,71 €
ZG0.4-39	39	15,60	16,40	11	3,00	0,0012	0,0007	8,71 €
ZG0.4-40	40	16,00	16,80	11	3,00	0,0012	0,0007	8,77 €
ZG0.4-41	41	16,40	17,20	11	3,00	0,0012	0,0008	8,77 €
ZG0.4-42	42	16,80	17,60	11	3,00	0,0013	0,0008	8,83 €
ZG0.4-43	43	17,20	18,00	11	3,00	0,0013	0,0009	8,93 €
ZG0.4-44	44	17,60	18,40	11	3,00	0,0014	0,0009	8,97 €
ZG0.4-45	45	18,00	18,80	11	3,00	0,0014	0,0010	8,97 €
ZG0.4-46	46	18,40	19,20	11	3,00	0,0015	0,0010	9,13 €
ZG0.4-47	47	18,80	19,60	11	3,00	0,0015	0,0010	9,20 €
ZG0.4-48	48	19,20	20,00	11	3,00	0,0015	0,0011	9,20 €
ZG0.4-49	49	19,60	20,40	14	4,00	0,0018	0,0011	9,27 €
ZG0.4-50	50	20,00	20,80	14	4,00	0,0019	0,0012	9,30 €
ZG0.4-51	51	20,40	21,20	14	4,00	0,0019	0,0012	9,38 €
ZG0.4-52	52	20,80	21,60	14	4,00	0,0020	0,0013	9,38 €
ZG0.4-53	53	21,20	22,00	14	4,00	0,0020	0,0013	9,53 €
ZG0.4-54	54	21,60	22,40	14	4,00	0,0021	0,0014	9,56 €
ZG0.4-55	55	22,00	22,80	14	4,00	0,0021	0,0014	9,56 €
ZG0.4-56	56	22,40	23,20	14	4,00	0,0022	0,0015	9,70 €
ZG0.4-57	57	22,80	23,60	14	4,00	0,0023	0,0015	9,80 €
ZG0.4-58	58	23,20	24,00	14	4,00	0,0023	0,0016	9,88 €
ZG0.4-59	59	23,60	24,40	14	4,00	0,0024	0,0016	9,95 €
ZG0.4-60	60	24,00	24,80	14	4,00	0,0024	0,0017	10,01 €
ZG0.4-61	61	24,40	25,20	14	4,00	0,0025	0,0018	10,13 €
ZG0.4-62	62	24,80	25,60	14	4,00	0,0025	0,0018	10,18 €
ZG0.4-63	63	25,20	26,00	14	4,00	0,0026	0,0019	10,33 €
ZG0.4-64	64	25,60	26,40	14	4,00	0,0027	0,0019	10,37 €
ZG0.4-65	65	26,00	26,80	14	4,00	0,0027	0,0020	10,53 €
ZG0.4-68	68	27,20	28,00	14	4,00	0,0029	0,0022	10,61 €
ZG0.4-70	70	28,00	28,80	14	4,00	0,0031	0,0023	10,72 €
ZG0.4-72	72	28,80	29,60	14	4,00	0,0032	0,0025	10,72 €
ZG0.4-75	75	30,00	30,80	14	4,00	0,0034	0,0027	11,86 €
ZG0.4-77	77	30,80	31,60	14	4,00	0,0036	0,0028	11,98 €
ZG0.4-80	80	32,00	32,80	14	4,00	0,0038	0,0031	11,98 €
ZG0.4-84	84	33,60	34,40	14	4,00	0,0041	0,0034	12,19 €
ZG0.4-86	86	34,40	35,20	14	4,00	0,0043	0,0035	12,30 €
ZG0.4-88	88	35,20	36,00	14	4,00	0,0044	0,0037	12,44 €
ZG0.4-90	90	36,00	36,80	14	4,00	0,0046	0,0039	12,63 €
ZG0.4-96	96	38,40	39,20	14	4,00	0,0051	0,0044	12,92 €
ZG0.4-100	100	40,00	40,80	14	4,00	0,0055	0,0048	14,95 €
ZG0.4-120	120	48,00	48,80	14	4,00	0,0077	0,0069	15,19 €
ZG0.4-140	140	56,00	56,80	14	4,00	0,0102	0,0095	16,90 €
ZG0.4-150	150	60,00	60,80	20	6,00	0,0116	0,0109	18,89 €
ZG0.4-180	180	72,00	72,80	20	6,00	0,0164	0,0157	20,89 €

On request

↓ **Gears available up to this size** ↓

<b>ZG0.4-348</b>	<b>348</b>	<b>139,20</b>	<b>140,00</b>	<b>Dimensions: contact us</b>	<b>On request</b>
------------------	------------	---------------	---------------	-------------------------------	-------------------

*Dimensions in mm*

## Our other products



ACLAPA

Magnetic stop for aluminium profile,  
Magnetic stop



AT5courroie

AT type timing belt,  
AT5 Steel cored polyurethane



 
BABPass

Hardened stainless steel ball pin with ring,  
With grip ring



SA\_SAKH

Housing for linear bearing, Closed - light load



MF

Shock Absorber -universal flange,  
Universal fixing



BH01

Single housed bearing, Bearing fitted with adhesive



MDR

Dee shackle with eye bolt, Steel




DER80

Stainless steel AC asynchronous motor  
0.55 - 0.75kW, 0.55 to 0.75kW



VLBG

 Lifting ring, Rotating



IN2

Internal gear, Machined plastic



WJUM10


Drylin® W bearing block, Slide



GARBAB

Lock pin for clamping, Ball lock pin

## Complementary products

 

G0

Steel spur gear, Steel 20NCD2



ZG0

Plastic spur gear, Machined plastic (delrin)