

Plastic spur gear




Module 1.5

Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

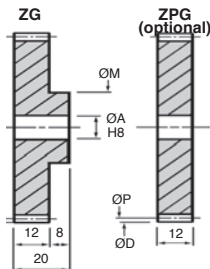

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	2.4

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG1.5-9	9	15,00	18,00	18	6	0,005	0,002	✓	11,04 €	On request
ZG1.5-10	10	16,50	19,50	18	6	0,005	0,003	✓	11,04 €	
ZG1.5-11	11	18,00	21,00	18	6	0,006	0,003	-	11,04 €	
ZG1.5-12	12	18,00	21,00	18	6	0,006	0,003	✓	11,04 €	
ZG1.5-13	13	19,50	22,50	18	6	0,006	0,004	-	11,60 €	
ZG1.5-14	14	21,00	24,00	20	8	0,007	0,005	-	11,84 €	
ZG1.5-15	15	22,50	25,50	20	8	0,008	0,005	✓	12,00 €	
ZG1.5-16	16	24,00	27,00	20	8	0,009	0,006	✓	12,39 €	
ZG1.5-17	17	25,50	28,50	20	8	0,010	0,007	-	12,78 €	
ZG1.5-18	18	27,00	30,00	24	8	0,012	0,008	✓	13,07 €	
ZG1.5-19	19	28,50	31,50	25	8	0,014	0,009	-	14,27 €	
ZG1.5-20	20	30,00	33,00	25	8	0,015	0,010	✓	15,01 €	
ZG1.5-21	21	31,50	34,50	25	8	0,016	0,011	-	15,09 €	
ZG1.5-22	22	33,00	36,00	25	8	0,017	0,012	-	15,26 €	
ZG1.5-23	23	34,50	37,50	25	8	0,018	0,014	-	15,57 €	
ZG1.5-24	24	36,00	39,00	25	8	0,019	0,015	✓	15,69 €	
ZG1.5-25	25	37,50	40,50	25	8	0,021	0,016	✓	16,59 €	
ZG1.5-26	26	39,00	42,00	25	8	0,022	0,017	-	17,31 €	
ZG1.5-27	27	40,50	43,50	25	8	0,024	0,019	-	20,30 €	
ZG1.5-28	28	42,00	45,00	25	8	0,025	0,020	✓	20,87 €	
ZG1.5-29	29	43,50	46,50	25	8	0,027	0,022	-	21,33 €	
ZG1.5-30	30	45,00	48,00	25	8	0,028	0,024	✓	21,90 €	
ZG1.5-31	31	46,50	49,50	28	10	0,031	0,025	-	22,29 €	
ZG1.5-32	32	48,00	51,00	28	10	0,032	0,026	-	22,69 €	

*Depending on availability - Dimensions in mm



Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	Bore ØA	Weight (kg) ZG	ZPG	Stock*	Price each 1 to 5 ZG	ZPG
ZG1.5-33	33	49,50	52,50	28	10	0,034	0,028	✓	22,85 €	
ZG1.5-34	34	51,00	54,00	28	10	0,036	0,030	✓	27,76 €	
ZG1.5-35	35	52,50	55,50	28	10	0,038	0,032	✓	27,99 €	
ZG1.5-36	36	54,00	57,00	28	10	0,040	0,034	✓	29,41 €	
ZG1.5-37	37	55,50	58,50	28	10	0,042	0,036	-	30,12 €	
ZG1.5-38	38	57,00	60,00	28	10	0,044	0,038	-	34,90 €	
ZG1.5-39	39	58,50	61,50	28	10	0,046	0,040	-	35,60 €	
ZG1.5-40	40	60,00	63,00	30	12	0,048	0,041	✓	36,40 €	
ZG1.5-41	41	61,50	64,50	30	12	0,050	0,044	-	36,46 €	
ZG1.5-42	42	63,00	66,00	30	12	0,052	0,046	-	36,57 €	
ZG1.5-43	43	64,50	67,50	30	12	0,055	0,048	-	36,64 €	
ZG1.5-44	44	66,00	69,00	30	12	0,057	0,051	-	36,87 €	
ZG1.5-45	45	67,50	70,50	30	12	0,060	0,053	-	37,12 €	
ZG1.5-46	46	69,00	72,00	30	12	0,062	0,055	-	37,84 €	
ZG1.5-47	47	70,50	73,50	30	12	0,065	0,058	-	38,95 €	
ZG1.5-48	48	72,00	75,00	30	12	0,067	0,060	-	39,72 €	
ZG1.5-49	49	73,50	76,50	30	12	0,070	0,063	-	43,96 €	
ZG1.5-50	50	75,00	78,00	30	12	0,073	0,066	✓	47,07 €	
ZG1.5-51	51	76,50	79,50	36	12	0,078	0,068	✓	48,42 €	
ZG1.5-52	52	78,00	81,00	36	12	0,081	0,071	-	49,44 €	
ZG1.5-53	53	79,50	82,50	36	12	0,084	0,074	-	50,16 €	
ZG1.5-54	54	81,00	84,00	36	12	0,087	0,077	-	50,60 €	
ZG1.5-55	55	82,50	85,50	36	12	0,090	0,080	-	51,04 €	
ZG1.5-56	56	84,00	87,00	36	12	0,093	0,083	-	51,39 €	
ZG1.5-57	57	85,50	88,50	36	12	0,096	0,086	-	51,62 €	
ZG1.5-58	58	87,00	90,00	36	12	0,099	0,089	-	51,83 €	
ZG1.5-59	59	88,50	91,50	36	12	0,102	0,092	-	57,88 €	
ZG1.5-60	60	90,00	93,00	36	12	0,106	0,095	✓	58,19 €	
ZG1.5-62	62	93,00	96,00	36	12	0,112	0,102	✓	59,29 €	
ZG1.5-64	64	96,00	99,00	36	12	0,119	0,109	-	59,99 €	
ZG1.5-65	65	97,50	100,50	36	12	0,123	0,112	-	67,67 €	
ZG1.5-66	66	99,00	102,00	48	12	0,134	0,116	-	70,14 €	
ZG1.5-68	68	102,00	105,00	48	12	0,142	0,123	-	71,74 €	
ZG1.5-70	70	105,00	108,00	48	12	0,149	0,131	✓	74,36 €	
ZG1.5-71	71	106,50	109,50	48	12	0,153	0,134	-	76,36 €	
ZG1.5-72	72	108,00	111,00	48	12	0,157	0,138	✓	69,70 €	
ZG1.5-73	73	109,50	112,50	48	12	0,161	0,142	-	71,40 €	
ZG1.5-74	74	111,00	114,00	48	12	0,165	0,146	-	73,95 €	
ZG1.5-75	75	112,50	115,50	48	12	0,169	0,150	-	83,81 €	
ZG1.5-76	76	114,00	117,00	48	12	0,173	0,154	-	88,22 €	
ZG1.5-78	78	117,00	120,00	48	12	0,182	0,163	-	88,27 €	
ZG1.5-80	80	120,00	123,00	48	12	0,190	0,171	✓	88,65 €	
ZG1.5-86	86	129,00	132,00	48	12	0,217	0,198	-	107,37 €	
ZG1.5-90	90	135,00	138,00	48	12	0,237	0,217	✓	102,15 €	
ZG1.5-96	96	144,00	147,00	48	12	0,267	0,247	-	132,90 €	
ZG1.5-100	100	150,00	153,00	48	15	0,288	0,268	-	136,16 €	

On request

↓ **Gears available up to this size** ↓

ZG1.5-298 298 447,00 450,00 Dimensions: contact us on request

*Depending on availability - Dimensions in mm

Our other products



DCG

Suction cup, 2.5 bellows, natural rubber



M0

Worm and wheel set, Hardened steel



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303 St...



SH4

Parallel axis helical gear, Steel 20NCD2



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting



BIM

Indexing plunger mini, miniature



J51

Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - In-line



NCT

Square tube connector, Fixed angle



LVT

Miniature motorised actuator 2A, 2 amperes



GE1006

Elastic ringed latch, Hooks into a slot



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



AT10-25ECO


AT type timing pulley, Economy range - AT10 aluminium

Complementary products



CLG1

 Moulded plastic spur gear, Moulded plastic (nylon)



ZR

Plastic rack, Delrin