

Plastic spur gear




Module 2.0

Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

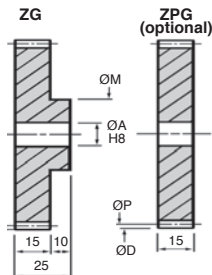

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	6

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-9	9	20,00	24,00	24	10	0,009	0,005	✓	14,43 €	
ZG2-10	10	22,00	26,00	24	10	0,011	0,006	-	14,43 €	
ZG2-11	11	24,00	28,00	24	10	0,012	0,007	-	14,43 €	
ZG2-12	12	24,00	28,00	24	10	0,012	0,007	✓	14,43 €	
ZG2-13	13	26,00	30,00	24	10	0,014	0,009	-	15,25 €	
ZG2-14	14	28,00	32,00	24	10	0,015	0,010	✓	16,11 €	
ZG2-15	15	30,00	34,00	25	12	0,016	0,011	✓	17,01 €	
ZG2-16	16	32,00	36,00	27	12	0,019	0,013	✓	18,30 €	
ZG2-17	17	34,00	38,00	30	12	0,023	0,015	-	18,89 €	
ZG2-18	18	36,00	40,00	30	12	0,025	0,017	✓	19,74 €	
ZG2-19	19	38,00	42,00	30	12	0,027	0,020	✓	20,46 €	
ZG2-20	20	40,00	44,00	30	12	0,030	0,022	✓	21,04 €	
ZG2-21	21	42,00	46,00	30	12	0,032	0,025	✓	25,18 €	
ZG2-22	22	44,00	48,00	35	12	0,038	0,027	✓	25,61 €	
ZG2-23	23	46,00	50,00	35	12	0,041	0,030	-	26,17 €	
ZG2-24	24	48,00	52,00	35	12	0,044	0,033	✓	26,70 €	
ZG2-25	25	50,00	54,00	35	12	0,047	0,036	✓	33,88 €	
ZG2-26	26	52,00	56,00	35	12	0,050	0,039	-	34,93 €	
ZG2-27	27	54,00	58,00	35	12	0,053	0,042	✓	36,23 €	
ZG2-28	28	56,00	60,00	35	12	0,056	0,045	-	37,01 €	
ZG2-29	29	58,00	62,00	35	12	0,060	0,049	-	37,92 €	
ZG2-30	30	60,00	64,00	35	12	0,063	0,052	✓	43,94 €	
ZG2-31	31	62,00	66,00	35	12	0,067	0,056	-	45,64 €	
ZG2-32	32	64,00	68,00	35	12	0,071	0,060	-	47,78 €	
ZG2-33	33	66,00	70,00	35	12	0,075	0,064	✓	48,65 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	ØA Alésage	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-34	34	68,00	72,00	35	12	0,079	0,068	✓	51,04 €	
ZG2-35	35	70,00	74,00	35	12	0,083	0,072	✓	52,68 €	
ZG2-36	36	72,00	76,00	45	15	0,093	0,075	✓	55,65 €	
ZG2-37	37	74,00	78,00	45	15	0,098	0,080	-	59,75 €	
ZG2-38	38	76,00	80,00	45	15	0,102	0,084	-	61,25 €	
ZG2-39	39	78,00	82,00	45	15	0,107	0,089	✓	62,62 €	
ZG2-40	40	80,00	84,00	45	15	0,112	0,094	✓	63,83 €	
ZG2-41	41	82,00	86,00	45	15	0,117	0,098	-	65,08 €	
ZG2-42	42	84,00	88,00	45	15	0,122	0,103	-	65,77 €	
ZG2-43	43	86,00	90,00	45	15	0,127	0,109	-	66,61 €	
ZG2-44	44	88,00	92,00	45	15	0,132	0,114	-	75,14 €	
ZG2-45	45	90,00	94,00	45	15	0,137	0,119	✓	76,36 €	
ZG2-46	46	92,00	96,00	45	15	0,143	0,125	-	77,99 €	
ZG2-47	47	94,00	98,00	45	15	0,149	0,130	-	79,92 €	
ZG2-48	48	96,00	100,00	45	15	0,154	0,136	✓	80,19 €	
ZG2-49	49	98,00	102,00	45	15	0,160	0,142	-	82,72 €	
ZG2-50	50	100,00	104,00	45	15	0,166	0,148	✓	85,96 €	
ZG2-51	51	102,00	106,00	45	15	0,172	0,154	-	87,69 €	
ZG2-52	52	104,00	108,00	45	15	0,179	0,160	-	89,13 €	
ZG2-53	53	106,00	110,00	45	15	0,185	0,167	-	90,12 €	
ZG2-54	54	108,00	112,00	45	15	0,191	0,173	✓	91,64 €	
ZG2-55	55	110,00	114,00	45	15	0,198	0,180	-	95,04 €	
ZG2-56	56	112,00	116,00	45	15	0,205	0,187	-	102,84 €	
ZG2-57	57	114,00	118,00	45	15	0,212	0,193	✓	104,80 €	
ZG2-58	58	116,00	120,00	45	15	0,219	0,200	-	116,57 €	
ZG2-59	59	118,00	122,00	60	15	0,242	0,208	-	116,97 €	
ZG2-60	60	120,00	124,00	60	15	0,249	0,215	✓	116,97 €	
ZG2-62	62	124,00	128,00	60	15	0,264	0,230	-	116,97 €	
ZG2-64	64	128,00	132,00	60	15	0,279	0,245	-	125,26 €	
ZG2-65	65	130,00	134,00	60	15	0,287	0,253	-	131,20 €	
ZG2-66	66	132,00	136,00	60	15	0,295	0,261	✓	133,49 €	
ZG2-68	68	136,00	140,00	60	15	0,311	0,277	-	138,92 €	
ZG2-70	70	140,00	144,00	60	15	0,328	0,294	✓	150,48 €	
ZG2-71	71	142,00	146,00	60	15	0,336	0,302	-	158,95 €	
ZG2-72	72	144,00	148,00	60	15	0,345	0,311	✓	168,60 €	
ZG2-73	73	146,00	150,00	60	15	0,354	0,320	-	171,09 €	
ZG2-74	74	148,00	152,00	60	15	0,363	0,328	-	171,09 €	
ZG2-75	75	150,00	154,00	60	15	0,372	0,337	✓	171,09 €	
ZG2-76	76	152,00	156,00	60	15	0,381	0,347	-	195,42 €	
ZG2-78	78	156,00	160,00	60	15	0,399	0,365	-	207,66 €	
ZG2-80	80	160,00	164,00	60	15	0,419	0,384	-	207,66 €	
ZG2-86	86	172,00	176,00	60	15	0,479	0,445	-	241,31 €	
ZG2-90	90	180,00	184,00	60	15	0,522	0,487	-	299,82 €	
ZG2-96	96	192,00	196,00	60	15	0,589	0,555	-	299,82 €	

On request

↓
↓
Gears available up to this size

ZG2-290	290	580,00	584,00	Dimensions: contact us	on request
----------------	------------	---------------	---------------	-------------------------------	-------------------

*Depending on availability - Dimensions in mm

Our other products



gt64r

Rotating bent lever with spring, increased fitting tolerances



DIA

Ring operated locking bolt, with ring



RVM25

Manually operated gearbox, Bevel



MCL

Cylindrical threaded sleeve, cylindrical stainless steel



NPTR_M

Adjustable cross clamp, adjustable



PRES2HR

Manual workbench press, force up to 200kg



HTD3M_09

HTD Heavy duty timing pulley, HTD3 Aluminium



M1

Worm and wheel set, hardened steel



DOMI80

Accessories, Plate



CLASS

Stainless steel indexing handle -



SDC_{SS}

Positioning sleeve for indexing pin, for pin



BABA


Ball pin lifting ring, steel

Complementary products




CLG2

 Moulded plastic spur gear, moulded plastic (nylon)



ZR

 Plastic rack, Delrin



CRM

Moulded nylon rack, nylon