

Plastic spur gear




Module 2.0

Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

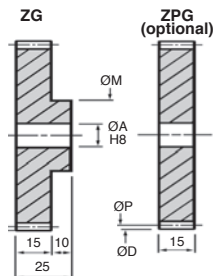

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	6

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-9	9	20,00	24,00	24	10	0,009	0,005	✓	14,43 €	
ZG2-10	10	22,00	26,00	24	10	0,011	0,006	-	14,43 €	
ZG2-11	11	24,00	28,00	24	10	0,012	0,007	-	14,43 €	
ZG2-12	12	24,00	28,00	24	10	0,012	0,007	✓	14,43 €	
ZG2-13	13	26,00	30,00	24	10	0,014	0,009	-	15,25 €	
ZG2-14	14	28,00	32,00	24	10	0,015	0,010	✓	16,11 €	
ZG2-15	15	30,00	34,00	25	12	0,016	0,011	✓	17,01 €	
ZG2-16	16	32,00	36,00	27	12	0,019	0,013	✓	18,30 €	
ZG2-17	17	34,00	38,00	30	12	0,023	0,015	-	18,89 €	
ZG2-18	18	36,00	40,00	30	12	0,025	0,017	✓	19,74 €	
ZG2-19	19	38,00	42,00	30	12	0,027	0,020	✓	20,46 €	
ZG2-20	20	40,00	44,00	30	12	0,030	0,022	✓	21,04 €	
ZG2-21	21	42,00	46,00	30	12	0,032	0,025	✓	25,18 €	
ZG2-22	22	44,00	48,00	35	12	0,038	0,027	✓	25,61 €	
ZG2-23	23	46,00	50,00	35	12	0,041	0,030	-	26,17 €	
ZG2-24	24	48,00	52,00	35	12	0,044	0,033	✓	26,70 €	
ZG2-25	25	50,00	54,00	35	12	0,047	0,036	✓	33,88 €	
ZG2-26	26	52,00	56,00	35	12	0,050	0,039	-	34,93 €	
ZG2-27	27	54,00	58,00	35	12	0,053	0,042	✓	36,23 €	
ZG2-28	28	56,00	60,00	35	12	0,056	0,045	-	37,01 €	
ZG2-29	29	58,00	62,00	35	12	0,060	0,049	-	37,92 €	
ZG2-30	30	60,00	64,00	35	12	0,063	0,052	✓	43,94 €	
ZG2-31	31	62,00	66,00	35	12	0,067	0,056	-	45,64 €	
ZG2-32	32	64,00	68,00	35	12	0,071	0,060	-	47,78 €	
ZG2-33	33	66,00	70,00	35	12	0,075	0,064	✓	48,65 €	

On request

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	ØA Alésage	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-34	34	68,00	72,00	35	12	0,079	0,068	✓	51,04 €	
ZG2-35	35	70,00	74,00	35	12	0,083	0,072	✓	52,68 €	
ZG2-36	36	72,00	76,00	45	15	0,093	0,075	✓	55,65 €	
ZG2-37	37	74,00	78,00	45	15	0,098	0,080	-	59,75 €	
ZG2-38	38	76,00	80,00	45	15	0,102	0,084	-	61,25 €	
ZG2-39	39	78,00	82,00	45	15	0,107	0,089	✓	62,62 €	
ZG2-40	40	80,00	84,00	45	15	0,112	0,094	✓	63,83 €	
ZG2-41	41	82,00	86,00	45	15	0,117	0,098	-	65,08 €	
ZG2-42	42	84,00	88,00	45	15	0,122	0,103	-	65,77 €	
ZG2-43	43	86,00	90,00	45	15	0,127	0,109	-	66,61 €	
ZG2-44	44	88,00	92,00	45	15	0,132	0,114	-	75,14 €	
ZG2-45	45	90,00	94,00	45	15	0,137	0,119	✓	76,36 €	
ZG2-46	46	92,00	96,00	45	15	0,143	0,125	-	77,99 €	
ZG2-47	47	94,00	98,00	45	15	0,149	0,130	-	79,92 €	
ZG2-48	48	96,00	100,00	45	15	0,154	0,136	✓	80,19 €	
ZG2-49	49	98,00	102,00	45	15	0,160	0,142	-	82,72 €	
ZG2-50	50	100,00	104,00	45	15	0,166	0,148	✓	85,96 €	
ZG2-51	51	102,00	106,00	45	15	0,172	0,154	-	87,69 €	
ZG2-52	52	104,00	108,00	45	15	0,179	0,160	-	89,13 €	
ZG2-53	53	106,00	110,00	45	15	0,185	0,167	-	90,12 €	
ZG2-54	54	108,00	112,00	45	15	0,191	0,173	✓	91,64 €	
ZG2-55	55	110,00	114,00	45	15	0,198	0,180	-	95,04 €	
ZG2-56	56	112,00	116,00	45	15	0,205	0,187	-	102,84 €	
ZG2-57	57	114,00	118,00	45	15	0,212	0,193	✓	104,80 €	
ZG2-58	58	116,00	120,00	45	15	0,219	0,200	-	116,57 €	
ZG2-59	59	118,00	122,00	60	15	0,242	0,208	-	116,97 €	
ZG2-60	60	120,00	124,00	60	15	0,249	0,215	✓	116,97 €	
ZG2-62	62	124,00	128,00	60	15	0,264	0,230	-	116,97 €	
ZG2-64	64	128,00	132,00	60	15	0,279	0,245	-	125,26 €	
ZG2-65	65	130,00	134,00	60	15	0,287	0,253	-	131,20 €	
ZG2-66	66	132,00	136,00	60	15	0,295	0,261	✓	133,49 €	
ZG2-68	68	136,00	140,00	60	15	0,311	0,277	-	138,92 €	
ZG2-70	70	140,00	144,00	60	15	0,328	0,294	✓	150,48 €	
ZG2-71	71	142,00	146,00	60	15	0,336	0,302	-	158,95 €	
ZG2-72	72	144,00	148,00	60	15	0,345	0,311	✓	168,60 €	
ZG2-73	73	146,00	150,00	60	15	0,354	0,320	-	171,09 €	
ZG2-74	74	148,00	152,00	60	15	0,363	0,328	-	171,09 €	
ZG2-75	75	150,00	154,00	60	15	0,372	0,337	✓	171,09 €	
ZG2-76	76	152,00	156,00	60	15	0,381	0,347	-	195,42 €	
ZG2-78	78	156,00	160,00	60	15	0,399	0,365	-	207,66 €	
ZG2-80	80	160,00	164,00	60	15	0,419	0,384	-	207,66 €	
ZG2-86	86	172,00	176,00	60	15	0,479	0,445	-	241,31 €	
ZG2-90	90	180,00	184,00	60	15	0,522	0,487	-	299,82 €	
ZG2-96	96	192,00	196,00	60	15	0,589	0,555	-	299,82 €	

On request

↓
Gears available up to this size
↓

ZG2-290 290 580,00 584,00 Dimensions: contact us
on request

*Depending on availability - Dimensions in mm

Our other products




GLT2-17

Telescopic drawer runners for groove mounting, Partial extension



ACL-FPA

 Panel mounting block for aluminium structures, Angular connector



CT

Telescopic universal joint, Normal duty



M0

Worm and wheel set, Bronze



PO

Pull handle - Multi-sector, Smooth hole



MFBS

Stainless steel flexible bellows coupling, Stainless steel - with seal...



SCR

Suction cup threaded insert, Adaptor for insert



ZDB

Machined plastic bevel gear, 2:1



DOMI120

Accessories, Turntable



GMK17_BR

Clamp for guiding profile, Rounded only



VRSF

Male swivelling lifting ring, Male swivelling



YG2


HEAVY DUTY spur gear, Steel 35NCD6

Complementary products




CLG2

 Moulded plastic spur gear, Moulded plastic nylon



ZR

 Plastic rack, Delrin



CRM

Moulded nylon rack, Nylon