

Plastic spur gear




Module 2.0

Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

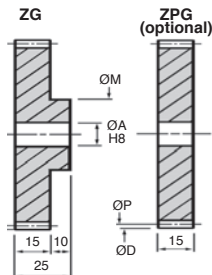

Torque indication	
For 50 teeth at 1000 rpm	
Delrin	
Nm	6

✓ IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	Bore ØA	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-9	9	20,00	24,00	24	10	0,009	0,005	✓	14,43 €	On request
ZG2-10	10	22,00	26,00	24	10	0,011	0,006	-	14,43 €	
ZG2-11	11	24,00	28,00	24	10	0,012	0,007	-	14,43 €	
ZG2-12	12	24,00	28,00	24	10	0,012	0,007	✓	14,43 €	
ZG2-13	13	26,00	30,00	24	10	0,014	0,009	-	15,25 €	
ZG2-14	14	28,00	32,00	24	10	0,015	0,010	✓	16,11 €	
ZG2-15	15	30,00	34,00	25	12	0,016	0,011	✓	17,01 €	
ZG2-16	16	32,00	36,00	27	12	0,019	0,013	✓	18,30 €	
ZG2-17	17	34,00	38,00	30	12	0,023	0,015	-	18,89 €	
ZG2-18	18	36,00	40,00	30	12	0,025	0,017	✓	19,74 €	
ZG2-19	19	38,00	42,00	30	12	0,027	0,020	✓	20,46 €	
ZG2-20	20	40,00	44,00	30	12	0,030	0,022	✓	21,04 €	
ZG2-21	21	42,00	46,00	30	12	0,032	0,025	✓	25,18 €	
ZG2-22	22	44,00	48,00	35	12	0,038	0,027	✓	25,61 €	
ZG2-23	23	46,00	50,00	35	12	0,041	0,030	-	26,17 €	
ZG2-24	24	48,00	52,00	35	12	0,044	0,033	✓	26,70 €	
ZG2-25	25	50,00	54,00	35	12	0,047	0,036	✓	33,88 €	
ZG2-26	26	52,00	56,00	35	12	0,050	0,039	-	34,93 €	
ZG2-27	27	54,00	58,00	35	12	0,053	0,042	✓	36,23 €	
ZG2-28	28	56,00	60,00	35	12	0,056	0,045	-	37,01 €	
ZG2-29	29	58,00	62,00	35	12	0,060	0,049	-	37,92 €	
ZG2-30	30	60,00	64,00	35	12	0,063	0,052	✓	43,94 €	
ZG2-31	31	62,00	66,00	35	12	0,067	0,056	-	45,64 €	
ZG2-32	32	64,00	68,00	35	12	0,071	0,060	-	47,78 €	
ZG2-33	33	66,00	70,00	35	12	0,075	0,064	✓	48,65 €	

*Depending on availability - Dimensions in mm

Part number	Teeth Z	PCD ØP	outside ØD	Boss ØM	ØA Alésage	Weight (kg)		Stock*	Price each 1 to 5	
						ZG	ZPG		ZG	ZPG
ZG2-34	34	68,00	72,00	35	12	0,079	0,068	✓	51,04	€
ZG2-35	35	70,00	74,00	35	12	0,083	0,072	✓	52,68	€
ZG2-36	36	72,00	76,00	45	15	0,093	0,075	✓	55,65	€
ZG2-37	37	74,00	78,00	45	15	0,098	0,080	-	59,75	€
ZG2-38	38	76,00	80,00	45	15	0,102	0,084	-	61,25	€
ZG2-39	39	78,00	82,00	45	15	0,107	0,089	✓	62,62	€
ZG2-40	40	80,00	84,00	45	15	0,112	0,094	✓	63,83	€
ZG2-41	41	82,00	86,00	45	15	0,117	0,098	-	65,08	€
ZG2-42	42	84,00	88,00	45	15	0,122	0,103	-	65,77	€
ZG2-43	43	86,00	90,00	45	15	0,127	0,109	-	66,61	€
ZG2-44	44	88,00	92,00	45	15	0,132	0,114	-	75,14	€
ZG2-45	45	90,00	94,00	45	15	0,137	0,119	✓	76,36	€
ZG2-46	46	92,00	96,00	45	15	0,143	0,125	-	77,99	€
ZG2-47	47	94,00	98,00	45	15	0,149	0,130	-	79,92	€
ZG2-48	48	96,00	100,00	45	15	0,154	0,136	✓	80,19	€
ZG2-49	49	98,00	102,00	45	15	0,160	0,142	-	82,72	€
ZG2-50	50	100,00	104,00	45	15	0,166	0,148	✓	85,96	€
ZG2-51	51	102,00	106,00	45	15	0,172	0,154	-	87,69	€
ZG2-52	52	104,00	108,00	45	15	0,179	0,160	-	89,13	€
ZG2-53	53	106,00	110,00	45	15	0,185	0,167	-	90,12	€
ZG2-54	54	108,00	112,00	45	15	0,191	0,173	✓	91,64	€
ZG2-55	55	110,00	114,00	45	15	0,198	0,180	-	95,04	€
ZG2-56	56	112,00	116,00	45	15	0,205	0,187	-	102,84	€
ZG2-57	57	114,00	118,00	45	15	0,212	0,193	✓	104,80	€
ZG2-58	58	116,00	120,00	45	15	0,219	0,200	-	116,57	€
ZG2-59	59	118,00	122,00	60	15	0,242	0,208	-	116,97	€
ZG2-60	60	120,00	124,00	60	15	0,249	0,215	✓	116,97	€
ZG2-62	62	124,00	128,00	60	15	0,264	0,230	-	116,97	€
ZG2-64	64	128,00	132,00	60	15	0,279	0,245	-	125,26	€
ZG2-65	65	130,00	134,00	60	15	0,287	0,253	-	131,20	€
ZG2-66	66	132,00	136,00	60	15	0,295	0,261	✓	133,49	€
ZG2-68	68	136,00	140,00	60	15	0,311	0,277	-	138,92	€
ZG2-70	70	140,00	144,00	60	15	0,328	0,294	✓	150,48	€
ZG2-71	71	142,00	146,00	60	15	0,336	0,302	-	158,95	€
ZG2-72	72	144,00	148,00	60	15	0,345	0,311	✓	168,60	€
ZG2-73	73	146,00	150,00	60	15	0,354	0,320	-	171,09	€
ZG2-74	74	148,00	152,00	60	15	0,363	0,328	-	171,09	€
ZG2-75	75	150,00	154,00	60	15	0,372	0,337	✓	171,09	€
ZG2-76	76	152,00	156,00	60	15	0,381	0,347	-	195,42	€
ZG2-78	78	156,00	160,00	60	15	0,399	0,365	-	207,66	€
ZG2-80	80	160,00	164,00	60	15	0,419	0,384	-	207,66	€
ZG2-86	86	172,00	176,00	60	15	0,479	0,445	-	241,31	€
ZG2-90	90	180,00	184,00	60	15	0,522	0,487	-	299,82	€
ZG2-96	96	192,00	196,00	60	15	0,589	0,555	-	299,82	€

On request

↓
Gears available up to this size
↓

ZG2-290
290
580,00
584,00
Dimensions: contact us
on request

*Depending on availability - Dimensions in mm

Our other products



P15
Worm and wheel gear reducer, up to 3,75 Nm



ESSB
Bipod support base, Bipod support base



GTC
Belt tensioner, For standard applications



BLHM60
Right angled gearbox, double output shafts, up to 70 Nm



PGM86-M5
Pull handle, Thermoplastic



ACA
Steel splined shaft, Steel



RCX-6
Spherical tilt washer - DIN6319, concave



SSB
Stainless steel bevel gear, 1:1



BPL
Ball transfer unit light duty, Light



INStool
Insertion tool for self tapping inserts, Insertion tool



DB
Steel bevel gear, 2:1




SLV
Vertical toggle clamp, Vertical Lever Clamp - stainless steel


Complementary products



 CLG2
Moulded plastic spur gear, Moulded plastic (nylon)



ZR
Plastic rack, Delrin

 

CRM
Moulded nylon rack, Nylon