

Plastic spur gear




Module 4.0

Machined Delrin



- **Machined parts**
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

Torque indication	
For 50 teeth at 1000 rpm	
	Delrin
Nm	55

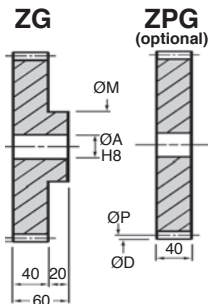

DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	On request	

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5 ZG	ZPG
ZG4-9	9	40,00	48,00	30	20	21,56 €	
ZG4-10	10	44,00	52,00	34	20	21,56 €	
ZG4-11	11	48,00	56,00	38	25	21,56 €	
ZG4-12	12	48,00	56,00	38	25	21,56 €	
ZG4-13	13	52,00	60,00	38	25	23,31 €	
ZG4-14	14	56,00	64,00	40	25	24,94 €	
ZG4-15	15	60,00	68,00	40	25	28,35 €	
ZG4-16	16	64,00	72,00	50	25	31,45 €	
ZG4-17	17	68,00	76,00	50	25	33,18 €	
ZG4-18	18	72,00	80,00	50	25	34,77 €	
ZG4-19	19	76,00	84,00	50	25	36,14 €	
ZG4-20	20	80,00	88,00	50	25	37,26 €	
ZG4-21	21	84,00	92,00	50	25	39,24 €	
ZG4-22	22	88,00	96,00	50	25	41,32 €	
ZG4-23	23	92,00	100,00	50	25	42,60 €	
ZG4-24	24	96,00	104,00	50	25	50,32 €	
ZG4-25	25	100,00	108,00	80	30	50,32 €	
ZG4-26	26	104,00	112,00	80	30	50,32 €	
ZG4-27	27	108,00	116,00	80	30	61,96 €	
ZG4-28	28	112,00	120,00	80	30	61,96 €	
ZG4-29	29	116,00	124,00	80	30	52,20 €	
ZG4-30	30	120,00	128,00	80	30	61,96 €	

On request

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5 ZG
ZG4-31	31	124,00	132,00	80	30	73,56 €
ZG4-32	32	128,00	136,00	80	30	115,64 €
ZG4-33	33	132,00	140,00	80	30	123,91 €
ZG4-34	34	136,00	144,00	80	30	132,38 €
ZG4-35	35	140,00	148,00	80	30	143,58 €
ZG4-36	36	144,00	152,00	80	30	152,00 €
ZG4-37	37	148,00	156,00	80	30	161,20 €
ZG4-38	38	152,00	160,00	80	30	163,65 €
ZG4-39	39	156,00	164,00	80	30	172,83 €
ZG4-40	40	160,00	168,00	80	30	178,55 €
ZG4-41	41	164,00	172,00	80	30	185,31 €
ZG4-42	42	168,00	176,00	80	30	202,14 €
ZG4-43	43	172,00	180,00	80	30	205,60 €
ZG4-44	44	176,00	184,00	80	30	209,09 €
ZG4-45	45	180,00	188,00	80	30	212,47 €
ZG4-46	46	184,00	192,00	80	30	214,92 €
ZG4-47	47	188,00	196,00	80	30	217,39 €
ZG4-48	48	192,00	200,00	80	30	444,80 €
ZG4-49	49	196,00	204,00	80	30	476,55 €
ZG4-50	50	200,00	208,00	80	30	486,92 €
ZG4-51	51	204,00	212,00	120	30	498,87 €
ZG4-52	52	208,00	216,00	120	30	510,21 €
ZG4-53	53	212,00	220,00	120	30	524,87 €
ZG4-54	54	216,00	224,00	120	30	546,58 €
ZG4-55	55	220,00	228,00	120	30	593,45 €
ZG4-56	56	224,00	232,00	120	30	628,44 €
ZG4-57	57	228,00	236,00	120	30	642,94 €
ZG4-58	58	232,00	240,00	120	30	651,27 €
ZG4-59	59	236,00	244,00	120	30	677,86 €
ZG4-60	60	240,00	248,00	120	30	695,01 €
ZG4-61	61	244,00	252,00	120	30	795,34 €
ZG4-62	62	248,00	256,00	120	30	795,34 €
ZG4-63	63	252,00	260,00	120	30	795,34 €
ZG4-64	64	256,00	264,00	120	30	795,34 €
ZG4-65	65	260,00	268,00	150	38	795,34 €
ZG4-66	66	264,00	272,00	150	38	795,34 €
ZG4-67	67	268,00	276,00	150	38	946,55 €
ZG4-68	68	272,00	280,00	150	38	946,55 €
ZG4-69	69	276,00	284,00	150	38	946,55 €
ZG4-70	70	280,00	288,00	150	38	946,55 €
ZG4-71	71	284,00	292,00	150	38	946,55 €
ZG4-72	72	288,00	296,00	150	38	946,55 €

On request

↓ **Gears available up to this size** ↓

ZG4-145	145	580,00	588,00	Dimensions: contact us	On request
----------------	------------	---------------	---------------	-------------------------------	-------------------

Dimensions in mm

Our other products



BCM_MPBT

Modular cylindrical brush, PBT polyester bristles



DBL880

Idler for slat top chain, Ranges 880 and 881



SUPTOOL

Installation tools for clamping hub, For hexagonal clamping hub



R204

Die spring ISO10243, Average



AC

Strike for toggle latch, 20mm



INS_BR

Self tapping brass insert, Brass



CHAGC-AL

Screw-in garnet hinge, Screw-on



BSM_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



GCA

Linch pin, Linch



J66

Spur gear coaxial gearbox, from 0.90 to 2.80 Nm - Inline



RPCpl

Swivel castor with plate, Steel - Polyamide



BSM

Spring plunger with internal hexagonal socket, stainless steel 303 b...

Complementary products



YG4

HEAVY DUTY spur gear, Steel 35NCD6




G4

Steel spur gear, Steel 20NCD2



G4-ECO

Eco range Spur gear, Steel C45

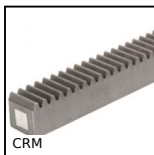

CRM

Moulded nylon rack, Nylon