

# Plastic spur gear




## Module 4.0

**Machined** Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

Torque indication	
For 50 teeth at 1000 rpm	
	<b>Delrin</b>
Nm	<b>55</b>

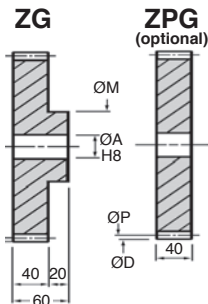

### DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	On request	

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5 ZG	ZPG
ZG4-9	9	40,00	48,00	30	20	21,56 €	
ZG4-10	10	44,00	52,00	34	20	21,56 €	
ZG4-11	11	48,00	56,00	38	25	21,56 €	
ZG4-12	12	48,00	56,00	38	25	21,56 €	
ZG4-13	13	52,00	60,00	38	25	23,31 €	
ZG4-14	14	56,00	64,00	40	25	24,94 €	
ZG4-15	15	60,00	68,00	40	25	28,35 €	
ZG4-16	16	64,00	72,00	50	25	31,45 €	
ZG4-17	17	68,00	76,00	50	25	33,18 €	
ZG4-18	18	72,00	80,00	50	25	34,77 €	
ZG4-19	19	76,00	84,00	50	25	36,14 €	
ZG4-20	20	80,00	88,00	50	25	37,26 €	
ZG4-21	21	84,00	92,00	50	25	39,24 €	
ZG4-22	22	88,00	96,00	50	25	41,32 €	
ZG4-23	23	92,00	100,00	50	25	42,60 €	
ZG4-24	24	96,00	104,00	50	25	50,32 €	
ZG4-25	25	100,00	108,00	80	30	50,32 €	
ZG4-26	26	104,00	112,00	80	30	50,32 €	
ZG4-27	27	108,00	116,00	80	30	61,96 €	
ZG4-28	28	112,00	120,00	80	30	61,96 €	
ZG4-29	29	116,00	124,00	80	30	52,20 €	
ZG4-30	30	120,00	128,00	80	30	61,96 €	

**On request**

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 5 ZG
ZG4-31	31	124,00	132,00	80	30	73,56 €
ZG4-32	32	128,00	136,00	80	30	115,64 €
ZG4-33	33	132,00	140,00	80	30	123,91 €
ZG4-34	34	136,00	144,00	80	30	132,38 €
ZG4-35	35	140,00	148,00	80	30	143,58 €
ZG4-36	36	144,00	152,00	80	30	152,00 €
ZG4-37	37	148,00	156,00	80	30	161,20 €
ZG4-38	38	152,00	160,00	80	30	163,65 €
ZG4-39	39	156,00	164,00	80	30	172,83 €
ZG4-40	40	160,00	168,00	80	30	178,55 €
ZG4-41	41	164,00	172,00	80	30	185,31 €
ZG4-42	42	168,00	176,00	80	30	202,14 €
ZG4-43	43	172,00	180,00	80	30	205,60 €
ZG4-44	44	176,00	184,00	80	30	209,09 €
ZG4-45	45	180,00	188,00	80	30	212,47 €
ZG4-46	46	184,00	192,00	80	30	214,92 €
ZG4-47	47	188,00	196,00	80	30	217,39 €
ZG4-48	48	192,00	200,00	80	30	444,80 €
ZG4-49	49	196,00	204,00	80	30	476,55 €
ZG4-50	50	200,00	208,00	80	30	486,92 €
ZG4-51	51	204,00	212,00	120	30	498,87 €
ZG4-52	52	208,00	216,00	120	30	510,21 €
ZG4-53	53	212,00	220,00	120	30	524,87 €
ZG4-54	54	216,00	224,00	120	30	546,58 €
ZG4-55	55	220,00	228,00	120	30	593,45 €
ZG4-56	56	224,00	232,00	120	30	628,44 €
ZG4-57	57	228,00	236,00	120	30	642,94 €
ZG4-58	58	232,00	240,00	120	30	651,27 €
ZG4-59	59	236,00	244,00	120	30	677,86 €
ZG4-60	60	240,00	248,00	120	30	695,01 €
ZG4-61	61	244,00	252,00	120	30	795,34 €
ZG4-62	62	248,00	256,00	120	30	795,34 €
ZG4-63	63	252,00	260,00	120	30	795,34 €
ZG4-64	64	256,00	264,00	120	30	795,34 €
ZG4-65	65	260,00	268,00	150	38	795,34 €
ZG4-66	66	264,00	272,00	150	38	795,34 €
ZG4-67	67	268,00	276,00	150	38	946,55 €
ZG4-68	68	272,00	280,00	150	38	946,55 €
ZG4-69	69	276,00	284,00	150	38	946,55 €
ZG4-70	70	280,00	288,00	150	38	946,55 €
ZG4-71	71	284,00	292,00	150	38	946,55 €
ZG4-72	72	288,00	296,00	150	38	946,55 €

On request

↓ **Gears available up to this size** ↓

<b>ZG4-145</b>	<b>145</b>	<b>580,00</b>	<b>588,00</b>	<b>Dimensions: contact us</b>	<b>On request</b>
----------------	------------	---------------	---------------	-------------------------------	-------------------

Dimensions in mm

## Our other products



ZBconique

Machined plastic  
bevel gear, 1:1



 
SHSS

Shoulder screw  
stainless steel 416,  
Pre-treated 416  
stainless steel



HW\_HT

Half-rail guide, Rail



CT

Telescopic universal  
joint, Normal duty



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



SSBRA

Stainless steel bevel  
gear, 1:1



CHAR6035

Spring hinge,  
screwed/welded



BDPR

Holding arm, Rigid



ZDB

Machined plastic  
bevel gear, 2:1



BLHB60

Right angled gearbox,  
bored shafts, up to 70  
Nm



VMS

Stainless steel knurled  
thumb screw, Knurled



PSG055

Spur gear - precision  
range, Stainless steel  
316

## Complementary products



YG4

HEAVY DUTY spur  
gear, Steel 35NCD6



 
G4

Steel spur gear, Steel  
20NCD2



G4-ECO

Eco range Spur gear,  
Steel C45



CRM

Moulded nylon rack,  
Nylon