

# Plastic spur gear



## Module 5.0


## Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

### Option

- Different number of teeth: a datasheet is available in PDF on [www.hpceurope.com](http://www.hpceurope.com)

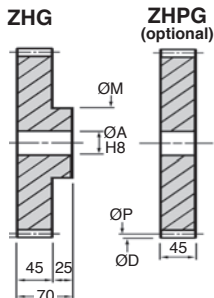

Torque indication	
For 50 teeth 1000 rpm	
	Delrin
Nm	90



### DISCOUNTS

Qty	1+	4+	20+
Disc.	List -5%	On request	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3	
						ZHG	ZHPG
ZHG5-12	12	60,00	70,00	40	20	On request	On request
ZHG5-14	14	70,00	80,00	50	25	On request	
ZHG5-15	15	75,00	85,00	50	25	On request	
ZHG5-18	18	90,00	100,00	70	30	92,30 €	
ZHG5-19	19	95,00	105,00	70	30	On request	
ZHG5-20	20	100,00	110,00	80	30	102,24 €	
ZHG5-21	21	105,00	115,00	80	30	On request	
ZHG5-22	22	110,00	120,00	80	30	On request	
ZHG5-23	23	115,00	125,00	85	30	113,49 €	
ZHG5-24	24	120,00	130,00	85	30	On request	
ZHG5-25	25	125,00	135,00	85	30	126,13 €	
ZHG5-30	30	150,00	160,00	100	30	191,17 €	
ZHG5-35	35	175,00	185,00	100	30	241,28 €	
ZHG5-38	38	190,00	200,00	100	38	On request	
ZHG5-40	40	200,00	210,00	150	38	On request	
ZHG5-42	42	210,00	220,00	150	38	On request	
ZHG5-45	45	225,00	235,00	150	38	On request	
ZHG5-50	50	250,00	260,00	150	38	On request	
ZHG5-52	52	260,00	270,00	150	38	On request	
ZHG5-55	55	275,00	285,00	150	38	On request	
↓ Gears available up to this size ↓							
ZHG5-115	115	575,00	585,00	Dimensions: contact us		On request	

Dimensions in mm

## Our other products



VBFP

Small 6 lobe threaded handle - female, Duroplast - Brass



 
CHTRP

Single and dual output gearboxes, Up to 87,3Nm




ACL-FPA

Panel mounting block for aluminium structures, Support block



PRT

 Rotary table iglidur®, aluminium and stainless steel



BETA

Hitch pin, Hitch



RNAST

Cam follower without axial guide, Without interior ring



SLB

Indexing plunger, stainless steel



SHS

Shoulder screw stainless steel 303, Stainless steel 303



 
PCLA\_T

Technopolymer clamping lever - male,



AT10courroie

AT type timing belt, AT10 Steel cored



T5M T10M

T type timing belt per metre, T5 Steel cored



GG2

Ground spur gear, Heat treated steel

## Complementary products




HG5

Steel spur gear, Steel 20NC2



HG5-ECO

 Eco range Spur gear, Steel C45



MR\_MMR

Metric section rack, Steel