

# Plastic spur gear



## Module 5.0


## Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

### Option

- Different number of teeth: a datasheet is available in PDF on [www.hpceurope.com](http://www.hpceurope.com)

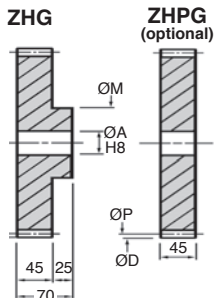

Torque indication	
For 50 teeth 1000 rpm	
Delrin	
Nm	90




### DISCOUNTS

 Qty	1+	4+	20+
Disc.	List -5%	On request	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Price each 1 to 3	
						ZHG	ZHPG
ZHG5-12	12	60,00	70,00	40	20	On request	On request
ZHG5-14	14	70,00	80,00	50	25	On request	
ZHG5-15	15	75,00	85,00	50	25	On request	
ZHG5-18	18	90,00	100,00	70	30	92,30 €	
ZHG5-19	19	95,00	105,00	70	30	On request	
ZHG5-20	20	100,00	110,00	80	30	102,24 €	
ZHG5-21	21	105,00	115,00	80	30	On request	
ZHG5-22	22	110,00	120,00	80	30	On request	
ZHG5-23	23	115,00	125,00	85	30	113,49 €	
ZHG5-24	24	120,00	130,00	85	30	On request	
ZHG5-25	25	125,00	135,00	85	30	126,13 €	
ZHG5-30	30	150,00	160,00	100	30	191,17 €	
ZHG5-35	35	175,00	185,00	100	30	241,28 €	
ZHG5-38	38	190,00	200,00	100	38	On request	
ZHG5-40	40	200,00	210,00	150	38	On request	
ZHG5-42	42	210,00	220,00	150	38	On request	
ZHG5-45	45	225,00	235,00	150	38	On request	
ZHG5-50	50	250,00	260,00	150	38	On request	
ZHG5-52	52	260,00	270,00	150	38	On request	
ZHG5-55	55	275,00	285,00	150	38	On request	
↓ Gears available up to this size ↓							
ZHG5-115	115	575,00	585,00	Dimensions: contact us		On request	


Dimensions in mm

## Our other products



PO

 Pull handle - Multi-sector, Tapped recessed insert



PM3

Worm and wheel set, Machined plastic (delrin)



SRG

Adjustable latch clamp with strike plate, Stroke from 117,4mm to 128mm



BLM

Spring loaded plunger with ball tip, Plastic body



S\_2RS

Deep groove ball bearing, Stainless steel



DB

Steel bevel gear, 2:1



AZY\_SS

Stainless steel cylindrical elastomount, Stainless steel



PTA50

Articulated levelling foot, pressed base Ø50, Ø 50




DIA

Ring operated locking bolt, with ring



DBL820

Idler for slat top chain, Ranges 820

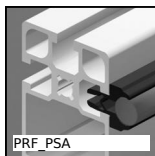

PRF\_PSA

Shaft support for aluminium profile, Ø 50



DH

Dowel pin, Solid DIN 6325

## Complementary products




HG5

Steel spur gear, Steel 20NCD2



HG5-ECO

 Eco range Spur gear, Steel C45



MR\_MMR

Metric section rack, Steel