 
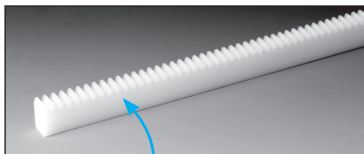


- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:  
delrin plastic

**Option**

- Other lengths available for quantities of 10 or more(max length 400mm)

**DISCOUNTS**

<b>Qty</b>	1+	6+	10+
<b>Disc. List</b>		-5%	On request

Part number	Module	P (mm)	W (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
ZR0.5-400	0,5	11,50	6	12	400	✓	47,87 €
ZR0.8-400	0,8	11,20	6	12	400	✓	51,04 €
ZR1-400	1,0	14,00	8	15	400	✓	52,76 €
ZRR1.5-400	1,5	16,50	12	18	400	✓	59,54 €
ZRR2-400	2,0	18,00	15	20	400	✓	66,40 €

\*Depending on availability - Dimensions in mm

## Our other products



PRT-TO

iglidur® slewing ring,  
With external teeth-  
Iglidur®, aluminium &  
S...



IBJ

180° ball and socket  
joints, Steel



PGMSS

Stainless steel pull  
handle, Stainless steel



CM\_CO

Tools Hygienic Usit®  
and Hygienic  
Design®, Protective  
inserts for ...



TM\_CTM\_CTF

Suction cup threaded  
insert, Insert for  
suction cup - Tread  
click-in




YG3

HEAVY DUTY spur  
gear, Steel 35NCD6



BABS303

 303 Stainless steel  
compact ball pin,  
Stainless steel 303



RPPM

RPP type belt per  
metre, RPP8 Steel  
cored polyurethane



EMR

Fast-locking knurled  
nut, Knurled



PTA100

Articulated levelling  
foot, pressed base



E40

Right angle helical  
reducers, from 2.30 to



EFTC

Fixing support,  
Stainless steel

## Complementary products



ZG1

Plastic spur gear,  
Machined plastic  
(delrin)



ZG2

Plastic spur gear,  
Machined plastic  
(delrin)



ZG1

Plastic spur gear,  
Machined plastic  
(delrin)