


 
- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:
delrin plastic

Option

- Other lengths available for quantities of 10 or more(max length 400mm)

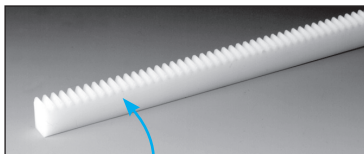

Spur rack

**DISCOUNTS**

| | | | |
|-------------------|----|-----|------------|
| Qty | 1+ | 6+ | 10+ |
| Disc. List | | -5% | On request |

| Part number | Module | P (mm) | W (mm) | H (mm) | L (mm) | Stock* | Price each 1 to 5 |
|-------------|--------|--------|--------|--------|--------|--------|-------------------|
| ZR0.5-400 | 0,5 | 11,50 | 6 | 12 | 400 | ✓ | 47,87 € |
| ZR0.8-400 | 0,8 | 11,20 | 6 | 12 | 400 | ✓ | 51,04 € |
| ZR1-400 | 1,0 | 14,00 | 8 | 15 | 400 | ✓ | 52,76 € |
| ZRR1.5-400 | 1,5 | 16,50 | 12 | 18 | 400 | ✓ | 59,54 € |
| ZRR2-400 | 2,0 | 18,00 | 15 | 20 | 400 | ✓ | 66,40 € |

*Depending on availability - Dimensions in mm

Our other products



RAS

90°ball and socket joints DIN71802, Steel



PRF JL6

Lip seal for panel, Door seal - Ø 6mm



CDP

Flanged drill bushing, Steel



 
CHT

Asynchronous AC Motor, 0.55 to 1.1kW



MEP

Revolving handle for handwheel, Fixed



PRF PSA

Shaft support for aluminium profile, Shaft support



BLHT30

Right angled gearbox, from 1.65 to 4.40 Nm



MBF

Threaded blocking clamp, Threaded locking clamp



SH0

Parallel axis helical gear, Steel 20NCD2



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



T5-10ECO

T type timing pulley, Economy range - T5 aluminium



FBL4004_K7

Brush strip per meter PA6 fibres Ø0.3 to Ø0.5, Black polyamide 6 ...

Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)



ZG2

Plastic spur gear, Machined plastic (delrin)



ZG1

Plastic spur gear, Machined plastic (delrin)