 
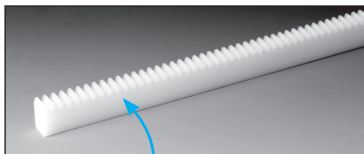


- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:
delrin plastic

Option

- Other lengths available for quantities of 10 or more(max length 400mm)

**DISCOUNTS**

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	W (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
ZR0.5-400	0,5	11,50	6	12	400	✓	47,87 €
ZR0.8-400	0,8	11,20	6	12	400	✓	51,04 €
ZR1-400	1,0	14,00	8	15	400	✓	52,76 €
ZRR1.5-400	1,5	16,50	12	18	400	✓	59,54 €
ZRR2-400	2,0	18,00	15	20	400	✓	66,40 €

*Depending on availability - Dimensions in mm

Our other products



PTA40

Articulated foot with solid base foot Ø 40, 30000N



ADL_F

Female eye bolt conforms to DIN582, Steel



M2

Worm and wheel set, Hardened steel



NK40

Drylin®N miniature guiding system, Width 40 mm



RJUM05

Drylin R® linear bearing housing, Closed - Long




ACL-APB

Closing system for aluminium profile, Magnetic door stop



CDR

Retaining cable for ball pin, Retaining cable

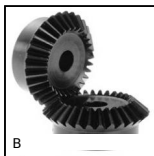

B

Steel bevel gear, 1:1



M0

Worm and wheel set, Non hardened steel



VQTplqp

Quarter-turn clamp lock - Clamping plate, Wall mounting



LRRss

Latch, Spring loaded latch - stainless steel



BOXsap

Boxed set of spring pins ISO8752, Boxed set - Split ISO 8752

Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)



ZG2

Plastic spur gear, Machined plastic (delrin)



ZG1

Plastic spur gear, Machined plastic (delrin)