 



- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:
delrin plastic

Option

- Other lengths available for quantities of 10 or more(max length 400mm)

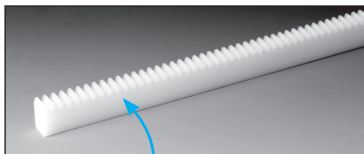

DISCOUNTS

Qty	1+	6+	10+
Disc. List		-5%	On request

Part number	Module	P (mm)	W (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
ZR0.5-400	0,5	11,50	6	12	400	✓	47,87 €
ZR0.8-400	0,8	11,20	6	12	400	✓	51,04 €
ZR1-400	1,0	14,00	8	15	400	✓	52,76 €
ZRR1.5-400	1,5	16,50	12	18	400	✓	59,54 €
ZRR2-400	2,0	18,00	15	20	400	✓	66,40 €

*Depending on availability - Dimensions in mm

Our other products



UTKswr

Utilitak® V rail, V rail



BH02

Single housed bearing assembly, Bearing secured with circlips



BSCf

Knurled torque knobs - female, Knurled threaded torque



DOMI80

Connecting kits, XY linking kit



RPP

Connecting plate for RPP type timing belts, RRP5



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



PPCcs

Pad eye on mounting plate squarred, Stainless steel



BEAS

Star shaped anti-static handle, Star, anti-static



AZY

Cylindrical elasto mount, Steel



BUH77

Motor-gearbox 12V and 24V DC, from 0.1



M0

Worm and wheel set, Hardened steel



PFL

P-FLEX Coupling, Set screw

Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)



ZG2

Plastic spur gear, Machined plastic (delrin)



ZG1

Plastic spur gear, Machined plastic (delrin)