 
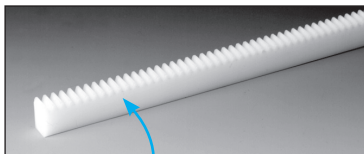


- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:
delrin plastic

Option

- Other lengths available for quantities of 10 or more(max length 400mm)

**DISCOUNTS**

Qty	1+	6+	10+
Disc. List		-5%	On request

Part number	Module	P (mm)	W (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
ZR0.5-400	0,5	11,50	6	12	400	✓	47,87 €
ZR0.8-400	0,8	11,20	6	12	400	✓	51,04 €
ZR1-400	1,0	14,00	8	15	400	✓	52,76 €
ZRR1.5-400	1,5	16,50	12	18	400	✓	59,54 €
ZRR2-400	2,0	18,00	15	20	400	✓	66,40 €

*Depending on availability - Dimensions in mm

Our other products



CHA_D65P
Hinge (stainless steel), Face frame for close-fitting door



SLVVIok
Toggle clamp, Vertical toggle clamp / vertical foot



BLHT60
Right angled gearbox, from 26 to 70 Nm



 
FB_ECO
Bevel gear - Steel C43, 4:1



T5-BAR
Toothed bar stock, T5



RPCpl
Wheel fixed with plate, Steel - Polyamide



T5courroie
Closed belt, T5 Steel cored polyurethane



PAT85
Articulated foot with pressed base, Ø 85




PO
Housing handle - Multi-sector, Smooth hole



G4
Spur gear, Steel 20NCD2



 CLG1-ALI
Spur gear, Moulded blue plastic (nylon)



PF30
Worm and wheel gearbox, up to 8.80 Nm

Complementary products



ZG2
Spur gear, Machined plastic (delrin)



ZG1
Spur gear, Machined plastic (delrin)



ZG1
Spur gear, Machined plastic (delrin)