 



- **Machined parts**
- Pressure angle 20°
- Max. length 400mm
- Max. pitch error 1mm/300mm
- Material:
delrin plastic

Option

- Other lengths available for quantities of 10 or more(max length 400mm)

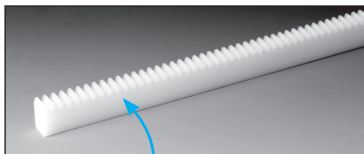

DISCOUNTS

Qty	1+	6+	10+
Disc. List		-5%	On request

Part number	Module	P (mm)	W (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
ZR0.5-400	0,5	11,50	6	12	400	✓	47,87 €
ZR0.8-400	0,8	11,20	6	12	400	✓	51,04 €
ZR1-400	1,0	14,00	8	15	400	✓	52,76 €
ZRR1.5-400	1,5	16,50	12	18	400	✓	59,54 €
ZRR2-400	2,0	18,00	15	20	400	✓	66,40 €

*Depending on availability - Dimensions in mm

Our other products



DBC

Panamech, Multi-Beam, Aluminium - with clamping jaw



PF45

Worm and wheel gear reducer, up to 40 Nm



CHM63-MOT

Asynchronous AC motorgearboxes 0.37 to 1.5kW, 0.37 to 1.5kW



TRM

Spur round rack, Steel - module 1-6



M0

Worm and wheel set, Non hardened steel



ALIDRP240

24V DC power supply, 10 A



CAP805

Slat top chain stainless steel, Large range 805



EKN

Bellows coupling Gerwah®, from 0.5 to 12Nm



 
PRF-GUM

Aluminium profile anodising polisher, Polishing block



MPB

Hexagonal spacer, Brass



GLT2-27

Telescopic drawer runners for groove mounting, Partial



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm

Complementary products



ZG1

Plastic spur gear, Machined plastic (delrin)



ZG2

Plastic spur gear, Machined plastic (delrin)



ZG1

Plastic spur gear, Machined plastic (delrin)