

D-ZYBLU

Male mounting

- Rubber buffer suitable for use in the food industry
- FDA compliant
- Materials:
 - Frame: 316 stainless steel
 - Cylinder: FDA-compliant blue silicon
- Medium hardness, Shore 55A
- Temperature range: -30 °C to +180 °C

For foodstuff industry


NEW!



stainless steel

Applications

- End stop
- Supporting foot

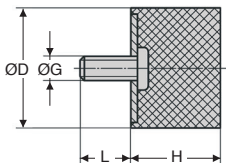

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List		10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-ZY3-8-8/SS/BLU	M3	8	8	6	30	22	
D-ZY4-10-10/SS/BLU	M4	10	10	10	71	66	
D-ZY4-10-15/SS/BLU	M4	10	15	10	42	60	
D-ZY4-15-6/SS/BLU	M4	15	6	10	250	130	
D-ZY4-15-8/SS/BLU	M4	15	8	10	133	96	
D-ZY4-15-10/SS/BLU	M4	15	10	10	120	110	
D-ZY4-15-15/SS/BLU	M4	15	15	10	58	82	
D-ZY6-20-5/SS/BLU	M6	20	5	18	300	120	
D-ZY6-20-8/SS/BLU	M6	20	8	18	180	126	
D-ZY6-20-10/SS/BLU	M6	20	10	18	155	139	
D-ZY6-20-15/SS/BLU	M6	20	15	18	114	160	
D-ZY6-20-20/SS/BLU	M6	20	20	18	84	160	
D-ZY6-20-25/SS/BLU	M6	20	25	18	54	129	
D-ZY6-25-8/SS/BLU	M6	25	8	18	750	525	
D-ZY6-25-10/SS/BLU	M6	25	10	18	375	338	
D-ZY6-25-15/SS/BLU	M6	25	15	18	193	271	
D-ZY6-25-20/SS/BLU	M6	25	20	18	122	231	
D-ZY6-25-25/SS/BLU	M6	25	25	18	90	215	
D-ZY8-30-15/SS/BLU	M8	30	15	20	113	152	
D-ZY8-30-20/SS/BLU	M8	30	20	20	80	147	
D-ZY8-30-30/SS/BLU	M8	30	30	20	49	139	
D-ZY8-40-15/SS/BLU	M8	40	15	23	705	952	
D-ZY8-40-20/SS/BLU	M8	40	20	23	355	657	
D-ZY8-40-30/SS/BLU	M8	40	30	23	200	570	
D-ZY10-50-20/SS/BLU	M10	50	20	28	750	1350	
D-ZY10-50-30/SS/BLU	M10	50	30	28	364	1018	

Dimensions in mm

- Large degree of deformation accepted
thus absorbing large amounts of energy

- Materials:

Frame: 316 stainless steel

Cylinder: Grey natural rubber

- Medium hardness, Shore 55A

- Temperature range: -30 °C to +80 °C

Applications


- End stop

- Supporting foot



NEW!

stainless steel

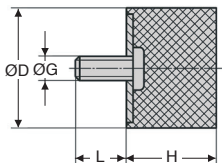

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-ZY3-8-8/SS/GREY	M3	8	8	6	40	40	
D-ZY4-10-10/SS/GREY	M4	10	10	10	35	35	
D-ZY4-10-15/SS/GREY	M4	10	15	10	26	40	
D-ZY4-15-8/SS/GREY	M4	15	8	10	187	187	
D-ZY4-15-10/SS/GREY	M4	15	10	10	100	100	
D-ZY6-20-8/SS/GREY	M6	20	8	18	250	250	
D-ZY6-20-10/SS/GREY	M6	20	10	18	240	240	
D-ZY6-20-15/SS/GREY	M6	20	15	18	110	220	
D-ZY6-20-20/SS/GREY	M6	20	20	18	75	225	
D-ZY6-25-8/SS/GREY	M6	25	8	18	850	850	
D-ZY6-25-10/SS/GREY	M6	25	10	18	400	400	
D-ZY6-25-15/SS/GREY	M6	25	15	18	210	420	
D-ZY6-25-20/SS/GREY	M6	25	20	18	140	420	
D-ZY6-25-25/SS/GREY	M6	25	25	18	100	350	
D-ZY8-30-15/SS/GREY	M8	30	15	23	270	540	
D-ZY8-30-20/SS/GREY	M8	30	20	23	238	714	
D-ZY8-30-30/SS/GREY	M8	30	30	23	127	508	
D-ZY8-30-40/SS/GREY	M8	30	40	23	88	528	
D-ZY8-40-15/SS/GREY	M8	40	15	23	710	1420	
D-ZY8-40-20/SS/GREY	M8	40	20	23	365	1095	
D-ZY8-40-30/SS/GREY	M8	40	30	23	205	820	
D-ZY10-50-20/SS/GREY	M10	50	20	28	646	1938	
D-ZY10-50-30/SS/GREY	M10	50	30	28	354	1416	
D-ZY10-50-40/SS/GREY	M10	50	40	28	230	1380	

 
Dimensions in mm

Our other products



COA-COG

Surface mounting plate, Surface mounting plate for clevis



TC1rp

Automatic chain tensioner, With 180° guide



HLC24

Right angle spiro bevel gearbox, Up to 78Nm



PRES2HR

Manual workbench press, Force up to 200kg



DOMI120

Domino 120 adjustable slide, Slide DOMILINE 120



PGR

Folding revolving handle for handwheel, Folding



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



 
BGC

Oldham coupling, Clamp



ACLBTS

Closing system for aluminium profile,




RPP5

RPP heavy duty timing belt, RPP5



SLBE

 Indexing plunger - Spacer, Spacer for



PRF-GPA

Guide for aluminium profile, Parallel rails

Complementary products