

D-ZYBLU

Male mounting

- Rubber buffer suitable for use in the food industry

- FDA compliant

- Materials:

Frame: 316 stainless steel

Cylinder: FDA-compliant blue silicon


- Medium hardness, Shore 55A

- Temperature range: -30 °C to +180 °C

Applications

- End stop

- Supporting foot

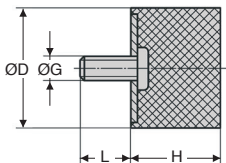

For foodstuff industry

NEW!



stainless steel

DISCOUNTS

Qty	1+	6+	20+	40+
Disc. List		10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-ZY3-8-8/SS/BLU	M3	8	8	6	30	22	
D-ZY4-10-10/SS/BLU	M4	10	10	10	71	66	
D-ZY4-10-15/SS/BLU	M4	10	15	10	42	60	
D-ZY4-15-6/SS/BLU	M4	15	6	10	250	130	
D-ZY4-15-8/SS/BLU	M4	15	8	10	133	96	
D-ZY4-15-10/SS/BLU	M4	15	10	10	120	110	
D-ZY4-15-15/SS/BLU	M4	15	15	10	58	82	
D-ZY6-20-5/SS/BLU	M6	20	5	18	300	120	
D-ZY6-20-8/SS/BLU	M6	20	8	18	180	126	
D-ZY6-20-10/SS/BLU	M6	20	10	18	155	139	
D-ZY6-20-15/SS/BLU	M6	20	15	18	114	160	
D-ZY6-20-20/SS/BLU	M6	20	20	18	84	160	
D-ZY6-20-25/SS/BLU	M6	20	25	18	54	129	
D-ZY6-25-8/SS/BLU	M6	25	8	18	750	525	
D-ZY6-25-10/SS/BLU	M6	25	10	18	375	338	
D-ZY6-25-15/SS/BLU	M6	25	15	18	193	271	
D-ZY6-25-20/SS/BLU	M6	25	20	18	122	231	
D-ZY6-25-25/SS/BLU	M6	25	25	18	90	215	
D-ZY8-30-15/SS/BLU	M8	30	15	20	113	152	
D-ZY8-30-20/SS/BLU	M8	30	20	20	80	147	
D-ZY8-30-30/SS/BLU	M8	30	30	20	49	139	
D-ZY8-40-15/SS/BLU	M8	40	15	23	705	952	
D-ZY8-40-20/SS/BLU	M8	40	20	23	355	657	
D-ZY8-40-30/SS/BLU	M8	40	30	23	200	570	
D-ZY10-50-20/SS/BLU	M10	50	20	28	750	1350	
D-ZY10-50-30/SS/BLU	M10	50	30	28	364	1018	

Dimensions in mm

- Large degree of deformation accepted
thus absorbing large amounts of energy

- Materials:

Frame: 316 stainless steel

Cylinder: Grey natural rubber

- Medium hardness, Shore 55A

- Temperature range: -30 °C to +80 °C

Applications


- End stop

- Supporting foot



NEW!

stainless steel

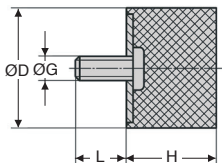

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-ZY3-8-8/SS/GREY	M3	8	8	6	40	40	
D-ZY4-10-10/SS/GREY	M4	10	10	10	35	35	
D-ZY4-10-15/SS/GREY	M4	10	15	10	26	40	
D-ZY4-15-8/SS/GREY	M4	15	8	10	187	187	
D-ZY4-15-10/SS/GREY	M4	15	10	10	100	100	
D-ZY6-20-8/SS/GREY	M6	20	8	18	250	250	
D-ZY6-20-10/SS/GREY	M6	20	10	18	240	240	
D-ZY6-20-15/SS/GREY	M6	20	15	18	110	220	
D-ZY6-20-20/SS/GREY	M6	20	20	18	75	225	
D-ZY6-25-8/SS/GREY	M6	25	8	18	850	850	
D-ZY6-25-10/SS/GREY	M6	25	10	18	400	400	
D-ZY6-25-15/SS/GREY	M6	25	15	18	210	420	
D-ZY6-25-20/SS/GREY	M6	25	20	18	140	420	
D-ZY6-25-25/SS/GREY	M6	25	25	18	100	350	
D-ZY8-30-15/SS/GREY	M8	30	15	23	270	540	
D-ZY8-30-20/SS/GREY	M8	30	20	23	238	714	
D-ZY8-30-30/SS/GREY	M8	30	30	23	127	508	
D-ZY8-30-40/SS/GREY	M8	30	40	23	88	528	
D-ZY8-40-15/SS/GREY	M8	40	15	23	710	1420	
D-ZY8-40-20/SS/GREY	M8	40	20	23	365	1095	
D-ZY8-40-30/SS/GREY	M8	40	30	23	205	820	
D-ZY10-50-20/SS/GREY	M10	50	20	28	646	1938	
D-ZY10-50-30/SS/GREY	M10	50	30	28	354	1416	
D-ZY10-50-40/SS/GREY	M10	50	40	28	230	1380	

Dimensions in mm

Our other products



AT10-25ECO

AT type timing pulley,
Economy range -
AT10 aluminium



HTD8M-BAR

HTD type tooth bar
stock, HTD8



LRM

Trapezoidal bronze
nut, Bronze - 1 thread



CHINV2

Invisible hinge,
Invisible - Opening up to
125°



PRF1945

Standard aluminium
profile, 19 x 45 mm



M2

Wormwheel, Bronze



SSDB

Stainless steel bevel
gear, 2:1



GLT3-46A

Telescopic drawer
with damper,



UGPC

Actuator guide kit,
Short bearing



GAL21

Conveyor wheel,
Plastic



SEV

Vertical stirrup toggle
clamp, Vertical Latch
Clamp - steel



CQA20

Accessory for
adjustment slide-
system, 20

Complementary products



DPAK_DKON

Conical elasto buffer,
Steel



D-PAR_SS

Stainless steel elasto
mount, stainless steel



DKONSL

Silicone conical elasto
buffer, Male mounting



DPAK_DKON

Progressive stop,
Steel